

Handles / Hinges / Knobs / Slide Rails / LED Lighting / Signal Towers

Handles



Round Bar Handles
P.1369



Round Bar With Rubber Handles
P.1370



Round Bar Welded Type Handles
P.1371



Angled Type Handles
P.1372

P.1367



Aluminum Handles Barrel Grinding
P.1373



Aluminum Handles With Tap
P.1374



Handles Side Mount Type
P.1375



Casting Handles Stainless Steel
P.1375



Handles Square Shape Stainless Steel
P.1376



Foldable Handles Carbon Steel
P.1377



Embedded Handles Flat Type
P.1378



Embedded Handles Flat Type Slim
P.1379



Embedded Handles Arch Type
P.1380



ABS Plastic Handles With Counterbored
P.1381



Phenole Plastic Handle With Tapped
P.1382

Hinges (Steel / Stainless Steel)



Flat Hinges HHSN
P.1385



Flat Hinges Mounting Pitch Fixed Type
P.1386



Stainless Steel Hinges Tapered Hole
P.1387



Stainless Steel Hinges
P.1388

P.1383



Stainless Steel Hinges With Slotted Holes
P.1389



Hinges For Heavy Load, Stainless Steel / Steel
P.1390



Heavy Load Hinges, Weld-Mounting
P.1391



Heavy Load Hinges With Bearing
P.1392

**Hinges
(Aluminum)**

P.1383



Short Type
P.1393



Ultra Low Head Bolt Hole Type
P.1394



Slotted Hole Type
P.1395



Tapered Hole Type
P.1396



Tapered Hole Asymmetric Type
P.1397

Heavy Load



Heavy Load Tapered Hole Asymmetric Type
P.1398



Heavy Load Tapered Hole Type
P.1399

**Concealed
Hinges**

P.1400

**New
Products**



Round Hole Type
P.1400

**New
Products**



Waist Hole / Round Hole Type
P.1400

**New
Products**



Limit Type
P.1401

**New
Products**



Quick Detach Type
P.1401

**Detachable
Hinges**

P.1402

**New
Products**



With Spring Type
P.1402

**New
Products**



Low Dust Heavy Load Type
P.1403

**New
Products**



Low Dust Aluminum Alloy Type
P.1404

**Magnetic
Catches**

P.1405

**New
Products**



Metal Vertical Fixed Type
P.1405

**New
Products**



Metal Parallel Fixed Type
P.1406

**New
Products**



Resin Two-Way Fixed Type
P.1407

**New
Products**



Resin Standard Embedded Type
P.1408

**New
Products**



Resin Vertical Fixed Small Type
P.1409

**New
Products**



Resin Round Embedded Type
P.1410

**New
Products**



Resin Parallel Fixed Type
P.1411

**New
Products**



Resin Vertical Fixed Type
P.1412

Handles / Hinges / Knobs / Slide Rails / LED Lighting / Signal Towers

Magnetic Catches

New Products



New Products



P.1405

Resin Small Embedded Type
P.1413

Resin Strong Force Type
P.1413

Cylindrical Locks · Knob Locks

New Products



New Products



New Products



New Products



P.1414

Cylindrical Locks Standard Type
P.1416

Cylindrical Locks Stainless Steel Standard Type
P.1417

Cylindrical Locks Locking Type
P.1418

Cylindrical Locks Stainless Steel Locking Type
P.1419

New Products



New Products



New Products



New Products



Cylindrical Locks Dustproof Type
P.1420

Cylindrical Locks Butterfly Type
P.1421

Knob Locks T-Shaped
P.1422

Knob Locks L-Shaped
P.1423

Flat Locks · Panel Locks

New Products



New Products



New Products



New Products



P.1424

Flat Locks Push Button Type
P.1424

Flat Locks Push Dot Push Button Type
P.1425

Flat Locks Slim Push Button Type
P.1426

Flat Locks Slim Pull-Up Type Stainless Steel
P.1427

New Products



New Products



New Products



Flat Locks Slim Pull-Up Type
P.1428

Flat Locks Compression Lever Type
P.1429

Panel Locks Stainless Steel
P.1430

Knobs

P.1431



Knurled Knobs Stepped Type
P.1432



Knurled Knobs
P.1433



Knurled Knobs / Small Diameter
P.1434



Knurled Knobs / Drop-Proof
P.1435



Knurled Knobs Phenolic
P.1436



Straight Grained Knobs
P.1437



Disc Knobs
P.1438



T Knobs Female Thread
P.1439



Triangular Arch Knobs Female Thread
P.1440



Triangular Arch Knobs
P.1441



Pentagonal Knobs
P.1442



Six Lobed Knobs
P.1443



Heptagonal Knobs
P.1444



Heptagonal Knobs Female Thread
P.1445



Star Knobs
P.1446



Octagonal Knobs
P.1447

Linear Slide Rails

P.1448



2 Step Slide Light Load Type
(Steel / SUS)
P.1449~P.1452



3 Step Slide Light Load Type
(Steel / SUS)
P.1453~P.1456



2 Step Slide Light Load Type
(Steel / SUS)
P.1457~P.1458



3 Step Slide Light Load Type
(Steel / SUS)
P.1459~P.1460



2 Step Slide Medium Load Type
(Steel / SUS)
P.1461~P.1462



3 Step Slide Medium Load Type
(Steel / SUS)
P.1463~P.1464



3 Step Slide Heavy load Type
(Steel)
P.1465

Handles / Hinges / Knobs / Slide Rails / LED Lighting / Signal Towers

LED Lighting				
	P.1466 IP65 Universal General Use P.1468	IP20 With Sensor Switch P.1469	IP20 Standard Type P.1470	IP67 Embedded Type P.1471
				
	IP67 Standard Type P.1472	IP67 Low Profile Type P.1473		
Signal Towers				
	P.1475 Foldable P.1476	3 Color-in One Module P.1477	Straight P.1478	

Tool Storage Box

Application Industries: **Automotive part** **Medical**

This figure shows the box for storing fixtures and tools.

It is commonly used to store fixtures and tools for equipment maintenance or replacement, and is widely used in automation, medical device, other processing and manufacturing industries.



Reference price

01 Handle × 1 P.1381



Material ABS Resin
Mounting Pitch L 120mm
Overall Height 39mm
C-UPCA120

56
THB/pcs

Quantity	Unit price	Total price
1	56	56
30	48	1,440


02 Hinge × 2 P.1385



Width 30mm
Length 50mm
C-HHSN50

72
THB/pcs

Quantity	Unit price	Total price
1	72	72
30	61	1,830

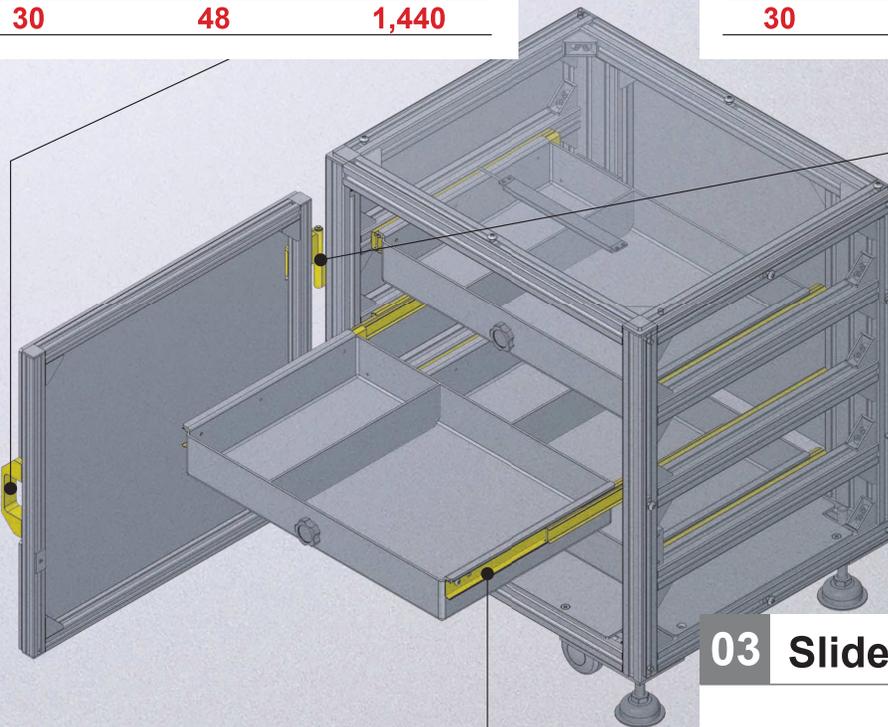

03 Slide Rail × 6 P.1457



Slide Rail Length 300mm
Stroke 222mm
C-SRY27300

373
THB/pcs

Quantity	Unit price	Total price
1	373	373
4	317	1,268

* All products prices are without tax. For prices reference, please visit MISUMI official website.

Economy Series Handles

Wide Range of
Products, Reduced
Costs, Applied to a
variety of installation
requirements



vs Standard Type
Saving
up to

83%

Types of MISUMI Economy series Handles and Examples of Use

In the same machinery, it is also possible to distinguish various installation methods of products for installation according to the different locations of use, so that the machinery design is more reasonable.

Mounting Method	Female Tread Fixing		Outside Mount		Embedded Type
Material (Product Photo)	Metal	Resin	Metal	Resin	Metal
Application	Can be installed from the inside, and generally used for flat door panels		Mostly used for matching aluminum alloy profiles, or the mechanism where the installed part is too thick to be penetrated through the opening		Mostly used for drawer doors, and inspection windows
Example of Use					


Product Features of MISUMI Economy series Round Bar Handles

- MISUMI Economy series round bar handle is processed with round steel, which has better overall roundness than the rolled steel used in the generic products in the market. With better roundness, the tolerance can be better controlled in the subsequent tapping process

<p>*Cases of poor quality of generic products on the market</p>  <p>Due to the insufficient roundness of the bar, the opening is severely biased.</p> <p>The inner diameter is too large, which can easily lead to slippery thread.</p>	<p>MISUMI Economy series</p>  <p>High roundness, without bias.</p> <p>Standard inner diameter, and guaranteed allowable load.</p>	<p>MISUMI Economy series (full inspection)</p>  <p>Full inspection to guarantee mounting pitch.</p> <p>*Full inspection to guarantee mounting pitch</p>
--	---	---

Product Features of MISUMI Economy series Embedded Handles

- Screws and nuts are fixed by riveting process Compared with the generic products in the market fixed by welding, the mounting pitch is better controlled, and the problem of screws falling off due to poor welding is also completely solved.
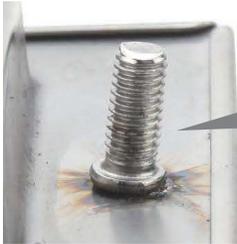
<p>*Cases of poor quality of generic products on the market</p>  <p>Fix by welding. Unable to control the mounting hole distance. Poor welding occurs frequently, causing screws to fall off and cannot be installed.</p>	<p>MISUMI Economy series</p>  <p>It is fixed by riveting, which completely solves the problem of poor welding. Riveting method can be controlled the mounting pitch more effectively. Easy installation</p>
--	--

Product Features of MISUMI Economy series Resin Handles

- The reinforcement is added at the position where it is easy to shrink and deform, so that the problem of shrinkage and deformation after forming can be alleviated, the accuracy of mounting pitch dimension is improved, and the installation is more convenient.

<p>*Cases of poor quality of generic products on the market</p>  <p>No reinforcement, with forming shrinkage Severely deformed, and unable to install</p>	<p>MISUMI Economy series</p>  <p>The reinforcement is added to greatly alleviate the problem of shrinkage and deformation, and the installation is convenient.</p>
--	--

* There is no reinforcement for goods with the mounting pitch of 90mm.

* Generic products on the market are similar products randomly purchased by our company from online or offline markets.

Representative model: C-NUWANS10-100-27

Save Up to **39%** vs Standard Type

61

THB

Shipping from **1 day**




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material	Surface Treatment
C-NUWANC	Steel(Q235)	Chrome Plated*
C-NUWANC	Stainless Steel	Buffed*
C-NUWAN	Steel(Q235)	Chrome Plated*
C-NUWANK	Steel(Q235)	Ferrous Oxide Protective Film (Blackening Treatment)
C-NUWANS	Stainless Steel	Buffed*
C-NUWANA	Aluminum Alloy	Buffed
C-NUWANB	Aluminum Alloy	Electrostatic Paint (Matt Black)
C-NUWANEA	Aluminum Alloy	Clear Anodized

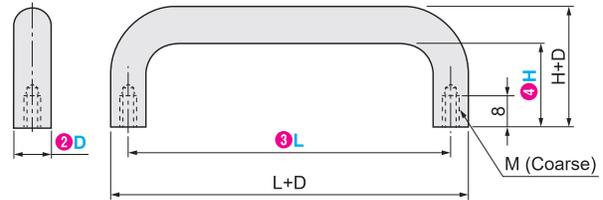

* For products with D=10mm or less, only the surface treatment marked with * can be selected.

Part Number		③ Mounting Pitch L	Inner Height H	M
① Type	② Handle Dia. D			
C-NUWANC (Steel(Q235))	6	48 66	37	4
	7	68*	23	5
	C-NUWANC (Stainless Steel)	8	48 66	37
9		48 66		

* marked dimensions only apply to stainless steel

Part Number		③ Mounting Pitch L	④ Inner Height H	M
① Type	② Handle Dia. D			
C-NUWAN (Steel-Chrome Plated)	10	80	27	5
			50	
			100	
			27	
			50	
			110	
C-NUWANK (Steel-Blackening Treatment)	10	120	27	5
			30*	
			50	
			27	
			30*	
			50	
C-NUWANS (Stainless Steel-Buffered)	10	125	27	5
			50	
			160	
			27	
			50	
			200	
C-NUWANA (Aluminum Alloy-Buffered)	10	250	27	5
			50	
			150	
			40	
			75	
			188	
C-NUWANB (Aluminum Alloy-Electrostatic Paint)	12	238	40	8
			75	
			288	
			40	
			75	
			40	

* marked dimensions only apply to stainless steel

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ④.

Part Number (①Type · ②D) - ③L - ④H
C-NUWANS10 - 100 - 27

How to search on website



By Type: Search on MISUMI official website
C-NUWANC

By Keyword: Step 1 Search on MISUMI official website
handle round bar

Step 2 Select MISUMI economy series brand



Representative model: C-NUWANSL10-80-27

Save Up to **33%**
vs Standard Type

Shipping from **1 day**



118 THB


Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material		Surface Treatment
	Body	Holding Part	
C-NUWANL	Steel(Q235)	Rubber	Chrome Plated
C-NUWANSL	Stainless Steel	Rubber	Buffed

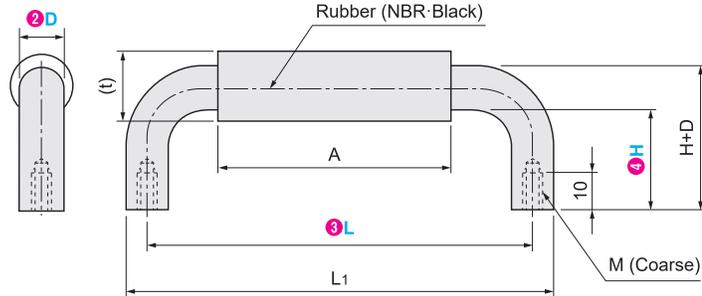

Part Number		③ Mounting Pitch L	④ Inner Height H	L1	M	A	(t)	
① Type	② Dia. D							
C-NUWANL (Steel(Q235))	10	80	27	90	5	50	11.5	
			50					
		100	27	110				
			50					
		110	27	120				
			50					
		120	27	130				
			50					
	125	27	135					
		50						
	160	27	170					
		50						
	C-NUWANSL (Stainless Steel)	12	200	27	210	8		170
				50				
250			27	260				
			50					
150			40	162				
			75					
188	40	200						
	75							
238	40	250						
	75							
288	40	300						
	75							

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ④.

Part Number (①Type · ②D) - ③L - ④H
C-NUWANSL10 - 80 - 27

How to search on website



By Type Search on MISUMI official website
C-NUWANL

By Keyword Step 1 ▶ Search on MISUMI official website
handle round bar

Step 2 ▶ Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Handles Round Bar Welded Type

Representative model: C-NUWANW10-100

Save Up to **30%**
vs Standard Type


Shipping
from
1 day



71

THB


Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.

Quantity of volume discount above is for representative Part No. It may differ by the Part.

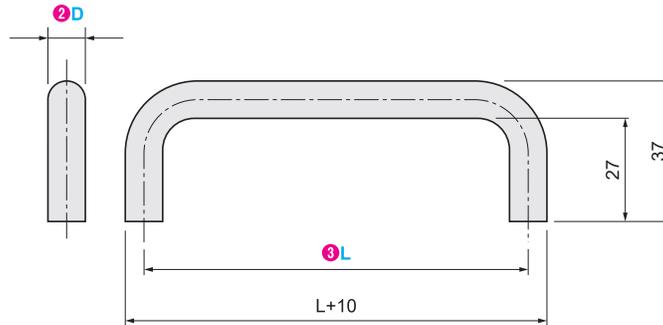

Material: Steel(Q235)
Surface Treatment: Tumble Polish

Part Number		Mounting Pitch L
Type	Dia. D	
C-NUWANW	10	80
		100
		120


Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type · 2 D) - 3 L
C-NUWANW10 - 100



Example

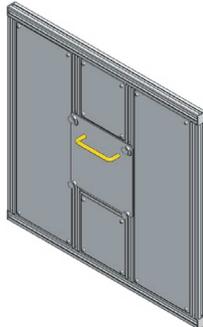

Welded handle Product drawings Example of use: Assembly with viewing window.

How to search on website



By Type

Search on MISUMI official website

C-NUWANW



By Keyword

Step 1 Search on MISUMI official website

handle round bar



Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NUHFN100

Save Up to **56%**
vs Standard Type

Shipping from **1 day**

144 THB



Volume Discount


Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material	Surface Treatment
C-NUHFN	Steel(Q235)	Chrome Plated
C-NUHFNS	Stainless Steel	Buffed*
C-NUHFNSC		
C-NUHFNA	Aluminum Alloy	Buffed
C-NUHFNB		Electrostatic Paint (Matt Black)
C-NUHFNEA		Clear Anodized

*For products with D=6mm and 8mm, only the surface treatment marked with * can be selected.

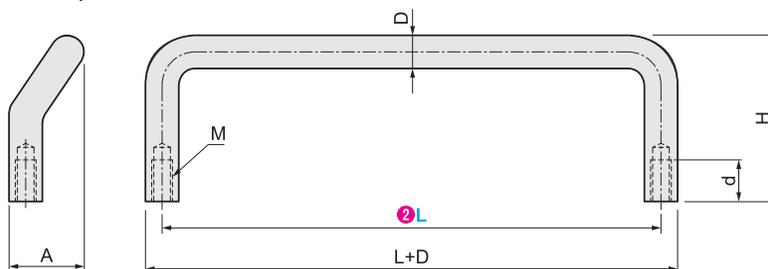

Part Number		Handle Dia. D	H	A	d	M	
1 Type	2 Mounting Pitch L						
C-NUHFNSC (Stainless Steel · Buffed)	60	6	30	16	7	4	
	80		31.5				
	100	8	32	18	10	5	
	120		40				
C-NUHFN (Steel(Q235) · Chrome Plated)	48	10	47	40	13	5	
	66						
	C-NUHFNS (Stainless Steel · Buffed)						88
	C-NUHFNA (Aluminum Alloy · Buffed)						100
	C-NUHFNB (Aluminum Alloy · Electrostatic Paint)						120
	C-NUHFNEA (Aluminum Alloy · Anodized)						125
							160

* Externally mounted gasket accessories are available. Please refer to the product web page for details.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 L)

C-NUHFN100

How to search on website



By Type

Search on MISUMI official website

C-NUHFNSC

By Keyword

Step 1 Search on MISUMI official website

handle angled

Step 2 Select MISUMI economy series brand

 
MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-UADL100

Save Up to **30%** vs Standard Type

Shipping from **1 day**

369

THB





Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material	Surface Treatment
C-UADL	Aluminum Alloy	Tumble Polish
C-UADEL	Aluminum Alloy	Anodized

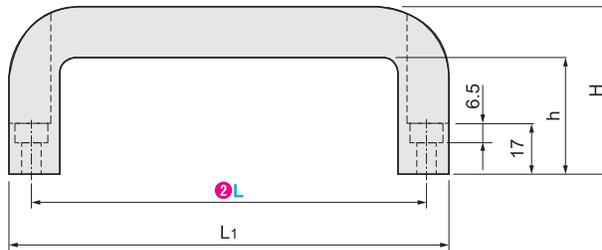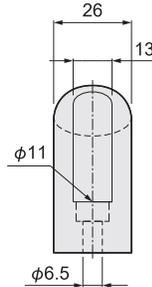

Part Number		L ₁	H	h	Allowable Load (N)
① Type	② Mounting Pitch L				
C-UADL (Tumble Polish) C-UADEL (Anodized)	100	114	47	30	1200
	116*	130	53	36	
	132	146	55	38	800
	150	164	67	50	600
	164	178	57	40	
	196	210			

The dimension with * is available for anodized products.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②L)
C-UADL100

How to search on website



By Type Search on MISUMI official website
C-UADL

By Keyword Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
aluminum handle

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-UABLA20-100

Save Up to **30%**
vs Standard Type

Shipping from **1 day**



292 THB


Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material	Surface Treatment
C-UABL	Aluminum Alloy	Tumble Polish
C-UABLA	Aluminum Alloy	Anodized

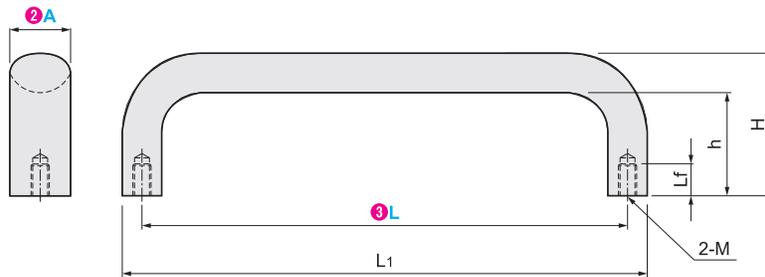

Part Number		③ Mounting Pitch L	L1	Lf	H	h	M (Coarse)	Allowable Load (N)
① Type	② A							
C-UABL (Tumble Polish) C-UABLA (Anodized)	20	100*	113	10	47	34	M6	1100
		112	125		49	36		
		120*	133		51	38		700
		128	141					600

The dimension with * is available for tumble polished products.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (① Type · ② A) - ③ L
C-UABLA20 - 100



By Type Search on MISUMI official website
C-UABL

By Keyword Step 1 Search on MISUMI official website
aluminum handle

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Handles Side Mount Type

Representative model: C-NUWANY120

Save Up to **30%** vs Standard Type



500


THB

Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

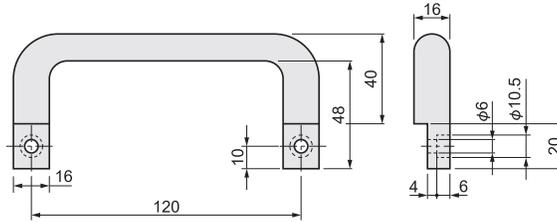

Material: Stainless Steel
Surface Treatment: Buffed

Part Number	Allowable Load (N)	Mass (g)
C-NUWANY120	500	270



Part Number
C-NUWANY120



Casting Handles Stainless Steel

Representative model: C-UWASND80

Save Up to **30%** vs Standard Type



414


THB

Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

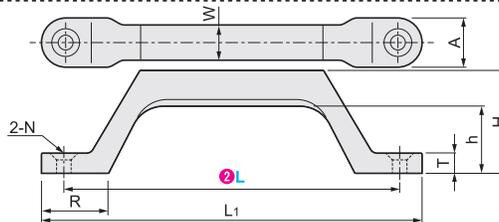

Material: Stainless Steel
Surface Treatment: Buffed

Part Number	Type	Mounting Pitch L	L1	H	h	T	A	W	R	N		Allowable Load (N)
										Through Hole	Countersink Hole	
C-UWASND		80	96	32	20	6	18	12	20	4.5	8.5	500
		100	116						23			
		150	170									
		200	220	46	30	9	22	16	30	6.5	12.5	

Please be aware that there may be a delay in the delivery time.



Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2L)
C-UWASND80

How to search on website



By Type: Search on MISUMI official website
C-UWASND

By Keyword: Step 1 Search on MISUMI official website
casting handle

Step 2 Select MISUMI economy series brand



Representative model: C-USANS125

Save Up to **30%** vs Standard Type

Shipping from 1 day




237 THB

Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

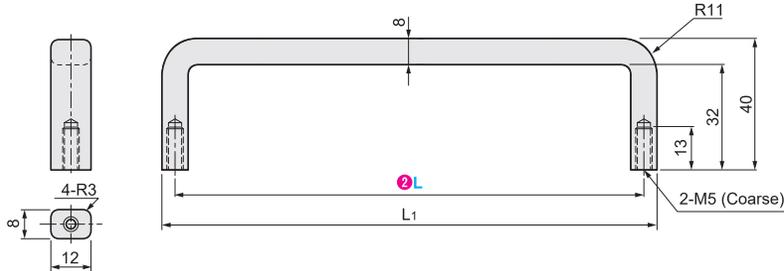

Material: Stainless Steel
Surface Treatment: Buffed

Part Number		L1	Allowable Load (N)
1 Type	2 Mounting Pitch L		
C-USANS	80	88	2500
	100	108	
	125	133	


Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 L)
C-USANS125



Example

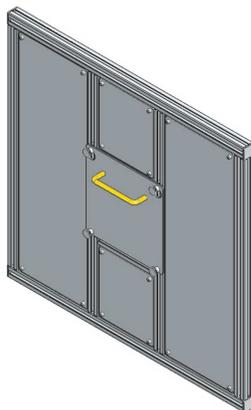

Economy series Aluminum Handles Barrel Grinding Tumble Polish Example of Use: The picture shows the recommended use of aluminum alloy structure assembly and disassembly beds

How to search on website



By Type: Search on MISUMI official website
C-USANS

By Keyword: Step 1 Search on MISUMI official website
handle square

Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-UWAFN100

Save Up to **83%** vs Standard Type

202

THB

Shipping from **1 day**



Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Handles / Hinges / Knobs / Slide Rails / LED Lighting / Signal Towers

Handles
P.1367

Hinges
P.1383

Magnetic Catches
P.1405


Locks
P.1414

Knobs
P.1431

Linear Slide Rails
P.1448

LED Lighting
P.1466

Signal Towers
P.1475

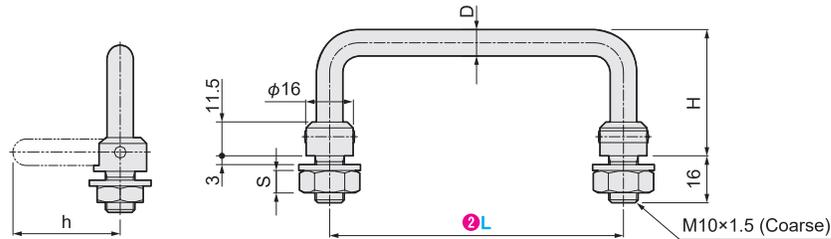

Material: Carbon Steel
Surface Treatment: Chromate Plating

Part Number		D	H	h	S	Allowable Load (N)
①Type	②Mounting Pitch L					
C-UWAFN	100					500
	120	9	43	36.5	7.6	
	180					

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②L)
C-UWAFN100

How to search on website



By Type: Search on MISUMI official website
C-UWAFN

By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
foldable handle

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NUWUANA-B

Save Up to **45%** vs Standard Type

Shipping from 1 day



156 THB


Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.


2B (Threaded Type)

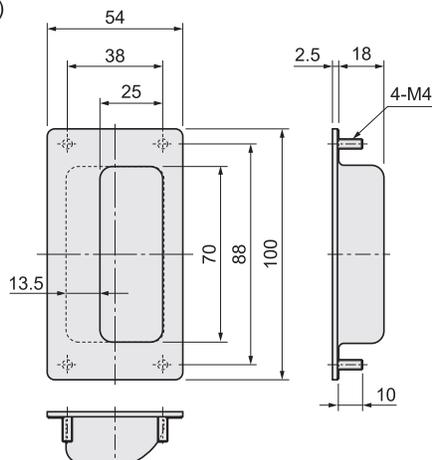

Panel Mounting Dimension

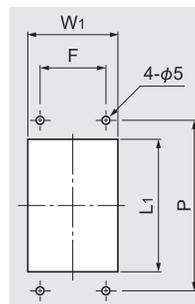

2S (Tapered Hole Type)

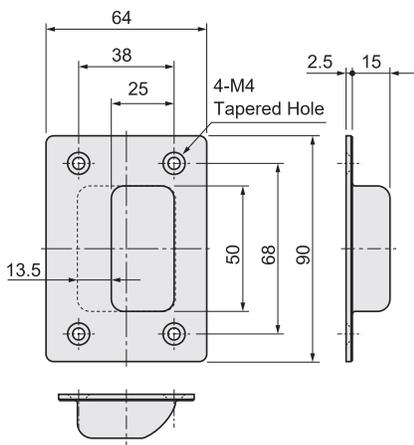

Material: Stainless Steel
Surface Treatment: Hairline Finish

1 Part Number	2 Mounting Hole	F	P	W1	L1
C-NUWUANA	B (Threaded Type)	38	88	44	75
	S (Tapered Hole Type)		68		54

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

1 Part Number - 2 Mounting Hole
C-NUWUANA - B

How to search on website



By Type: Search on MISUMI official website
C-NUWUANA

 
By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
embed handle



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Embedded Handles Flat Type Slim

Representative model: C-NUWAUNS90

Save Up to **39%** vs Standard Type

69

THB

Shipping from **1 day**





Volume Discount


Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

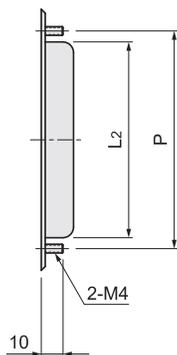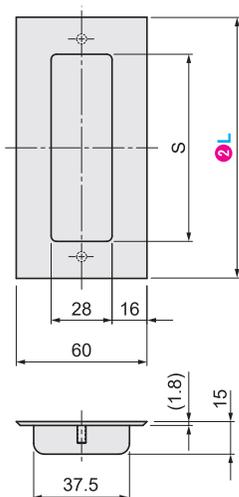

Panel Mounting Dimensions

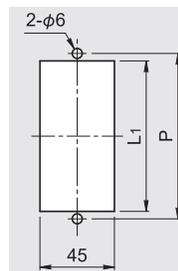

Material: Stainless Steel
Surface Treatment: Hairline Finish

Part Number	Screw Mounting Pitch P	S	L ₁	L ₂
1 Type	2 L			
C-NUWAUNS	90	74	58	63
	120	100	86	93

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2L)
C-NUWAUNS90

How to search on website



By Type Search on MISUMI official website
C-NUWAUNS

By Keyword Step 1 Search on MISUMI official website
embed handle

 
Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NUWUAN94-B

Save Up to **36%** vs Standard Type

Shipping from **1 day**



173 THB



Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

③B (Threaded Type) ③N (Tapped Type)

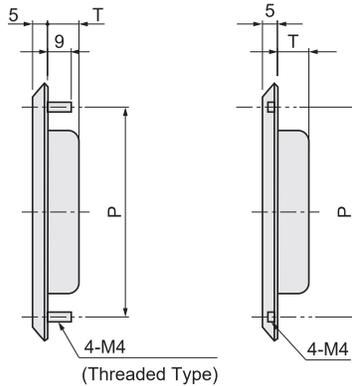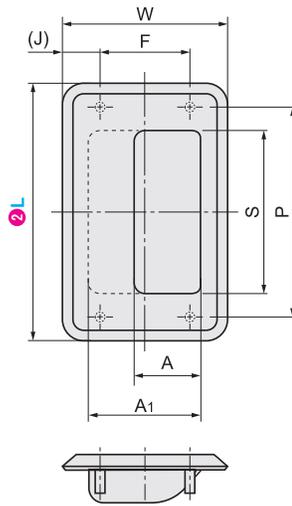

Panel Mounting Dimensions

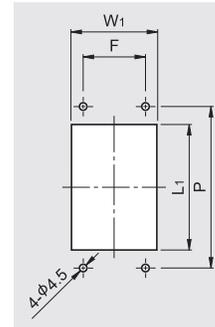

③Tapped products are also available. Please refer to the web page information for details.

Material: Stainless Steel
Surface Treatment: Hairline Finish

Part Number	①Type	②L	③ Mounting Hole	W	Pitch P	F	S	A	A1	T	(J)	L1	W1
C-NUWUAN		94	B (Threaded) N (Tapped)	60	76	32	61	25	43	12	14.5	63	45
		109.5		64	88	38	67.5		40	14.5	13	73	42
		138		88	110	65	96	35	62	21	11.5	99	64

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②L) - Mounting Hole (③)
C-NUWUAN94 - B

How to search on website



By Type Search on MISUMI official website
C-NUWUAN

By Keyword Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
embed handle

MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



ABS Plastic Handles With Counterbored

Representative model: C-UPPN120

Save Up to **57%** vs Standard Type

49

THB

Shipping from **1 day**




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material
C-UPCA	ABS Resin
C-UPPN	Polypropylene

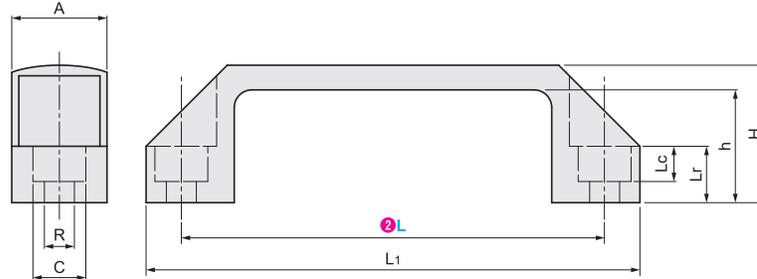

Part Number	Material	H	h	A	L ₁	R	C	L _r	L _c		
										①Type	②Mounting Pitch L
C-UPCA	ABS Resin	36	29	20	107	6.5	10	13	7		
										90	
										120	
C-UPPN	Polypropylene	37	31	20	110	6.5	12	13	7		
										90	
C-UPPN	Polypropylene	39	36	26	140	8.5	14	15.3	9		
										120	
										180	

For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②L)
C-UPPN120

How to search on website



By Type: Search on MISUMI official website
C-UPCA

By Keyword: Step 1 Search on MISUMI official website
plastic handle

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-UPCFN120

Save Up to **66%** vs Standard Type

 Shipping from **1 day**




156 THB

Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

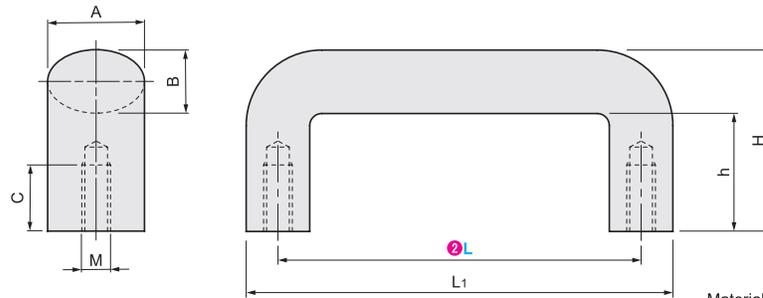

Material: Handle Part: Phenolic Resin
Threaded Part: Brass (Insert)


Part Number		L1	M	H	h	A	B	C	Mass (g)	Allowable Load (N)
1 Type	2 Mounting Pitch L									
C-UPCFN	90	106	6	45	29	23.5	16	12	73	500
	120	138	8	50	32	26	18	16	110	
	160	177							136	
	180	198	56	38	148					

For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Ordering Example

Part Number (1 Type · 2 L) **C-UPCFN120**

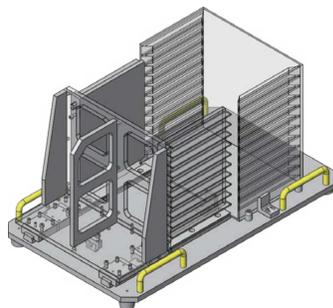

How to search on website

By Type: Search on MISUMI official website

By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"

Install MISUMI APP

Economy series Hinge

Wide Range of Products,
applicable to a variety of
installation requirements,
Effectively reduce costs



vs Standard Type

Saving
up to**73%**

Advantages of MISUMI Economy series

- Fine workmanship, and quality assurance
- Improved structure, firm and durable

	Aluminum Hinge		Stainless Steel Hinge	
	Generic products on the market *	MISUMI Economy series	Generic products on the market *	MISUMI Economy series
	Mounting holes are inaccurate and cannot be assembled	Full inspection of all products with special fixtures, ensuring quality	Ordinary riveted central shaft, small contact area, easy to fall off, and not firm	Modification of the central shaft structure, contact surface enhancement, additional welding joints, firm and durable


* Generic products on the market are similar products randomly purchased by our company from online or offline markets

Example of Use

Aluminum Hinge	Stainless Steel Hinge
Suitable for aluminum alloy frames, and adapted to the opening of profile groove size	Highly versatile and suitable for a variety of door frame materials, especially for equipment with high overall weight of the door or requiring high load.

Aluminum Alloy Heavy Load Hinge


- The material of the mechanism of the central shaft is changed to realize the allowable load force UP
- Reducing design change costs and improving design versatility
- Aluminum alloy heavy load type compared with MISUMI standard products by same size and specification, the load can be increased by 2 times.
- Reducing design modifications due to load limitations, parts management costs, and assembly difficulties

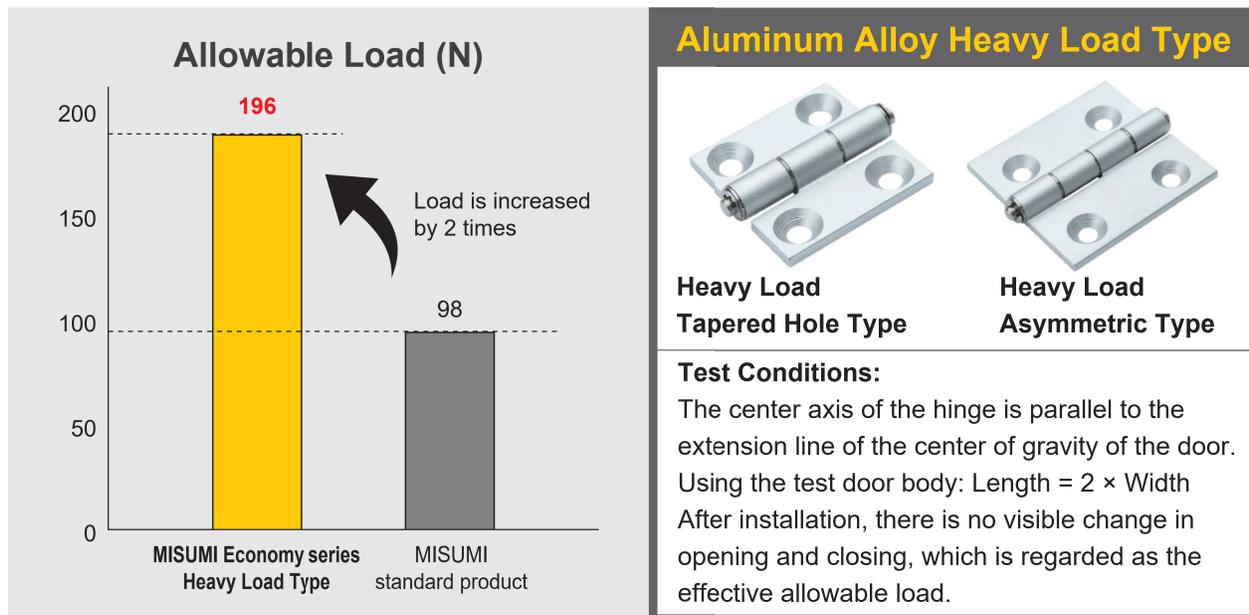

* The allowable load is the value when 2 pieces are used

Stainless Steel Heavy Load Hinges with Bearings

- Additional auxiliary bearings to reduce the opening and closing resistance, ensuring safe and efficient use
- Relieving the friction of hinge opening and closing, and reducing the opening and closing starting force
- For stainless steel heavy load hinges with bearings, compared with MISUMI standard product, the opening and closing starting force is reduced by 56%.
- Reducing friction of parts, and alleviating opening and closing noise

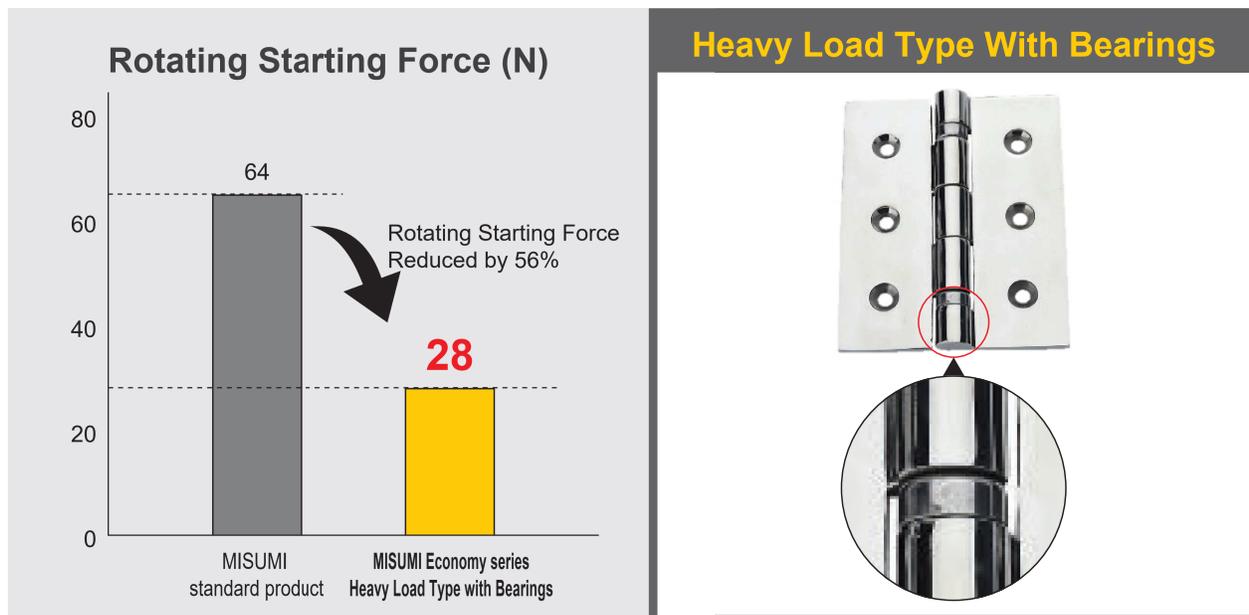

* The test data are obtained through testing by our company, which are for reference only.

Representative model: C-HHSN25

Save Up to **56%**
vs Standard Type

28

THB

Shipping
from
1 day




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

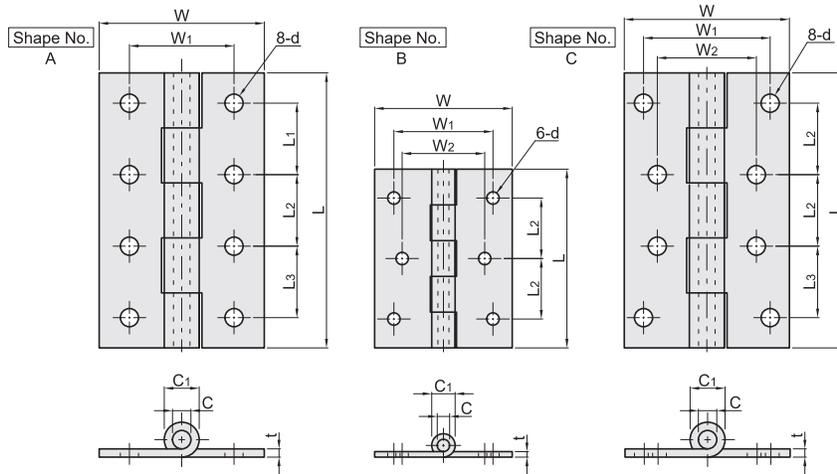

Material: Stainless Steel
Surface Treatment: Sandblasting Grinding

Part Number	Length L	Shape No.	Width W	W1	W2	L1	L2	L3	C	C1	t	d	Division	* Allowable Load (N)	Mass (g)		
C-HHSN	25	A	20	12	-	16	-	-	2	3.8	0.8	3.4	3	9.8	6		
	30					22									7		
	40					28									12		
	50	B	30	22	-	36	-	-	3	6.4	1.5	4.5	5	58.8	16		
	65A					23									25		
	65					36									30	22	22
	75A	A	50	30	-	27	-	-	4	8.5	2	5.5	5	147	46		
	75					36									30	26	26
	90A					38									-	35	35
	90	46	36	34	34												
	100A	38	-	26	26	26	294	100									
	100	C	60	46	36	26	26	26	6	12.7	3	6.6	5	294	100		

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2No.)

C-HHSN25

How to search on website



By Type

Search on MISUMI official website

C-HHSN



By Keyword

Step 1 Search on MISUMI official website

flat hinge



Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-HHKS25

Save Up to **30%** vs Standard Type

47

THB




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

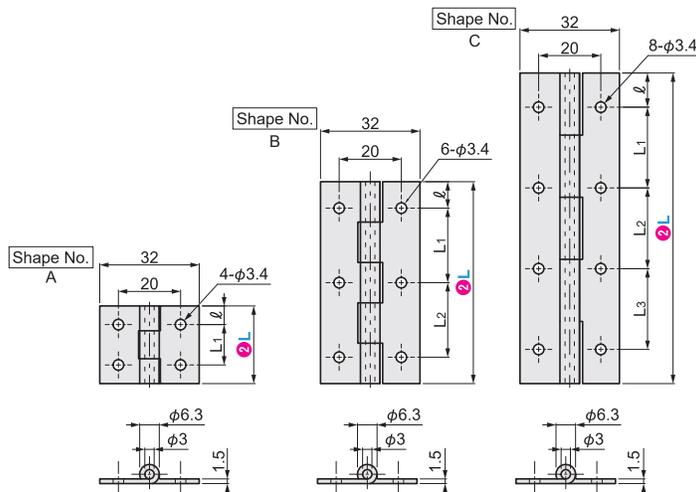

Material: Stainless Steel
Surface Treatment: Sandblasting Grinding

Part Number		Shape No.	ℓ	L1	L2	L3	Division	* Allowable Load (N)	Mass (g)
Type	Length L								
C-HHKS	25	A	6	13	-	-	3	29.4	13
	30		7	16				39.2	16
	40		8	24				58.8	21
	50		10	30				68.6	26
	65	B	8.5	24	24	5	98.0	34	
	75		9.5	28	28		107.8	39	
	90		10	35	35		127.4	47	
	100		C	11	26		26	26	147.0

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2L)

C-HHKS25

How to search on website



By Type

Search on MISUMI official website

C-HHKS

By Keyword

Step 1 Search on MISUMI official website

flat hinge

Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Stainless Steel Hinges Tapered Hole

Representative model: C-SHHPSDN5-2

Save Up to **65%** vs Standard Type

Shipping from **1 day**



80

THB

Volume Discount



Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

③ One Side 2 Holes

③ One Side 3 Holes

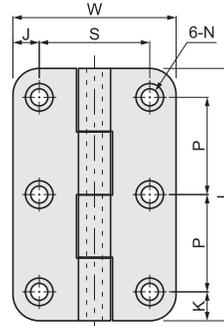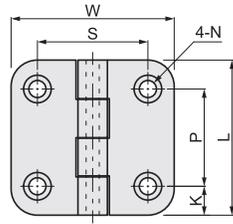

Material: Stainless Steel
Surface Treatment: Sandblasting Grinding

Part Number	① Type	② No.	③ Number of holes on one side	* Allowable Load		Length L	Width W	K	P	J	S	N										
				kg	N							Through Hole	Countersink Hole	T	E	R	D					
C-SHHPSDN	5	2	2	9	88	41	36	8	25	7.5	21	5.5	8.6 (For M4)	2	4.6	9.2	5					
			3	11	108	66																
		6	2	12	117	48	48	9	30	8	32											
			3	15	147	78																
		8	2	25	245	59	62	11	37	10	42							6.5	10.5 (For M5)	3	5.6	11.2
			3	38	372	96																
	845	2	30	294	70	80	13.5	43	16.5	47	5.6	11.2	5									
		3	40	392	113									6.1	12.2	6						

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (① Type · ② No.) - ③ Number of holes on one side
C-SHHPSDN5 - 2

How to search on website



By Type: Search on MISUMI official website
C-SHHPSDN

By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
sus hinge



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SHHPSKN5-2



Save Up to **55%** vs Standard Type

104

THB

Shipping from **1 day**


Volume Discount

Quantity	2~29	30~49	50~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.


③ Symmetrical Type One Side 2 Holes

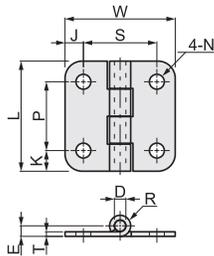

③ Symmetrical Type One Side 3 Holes

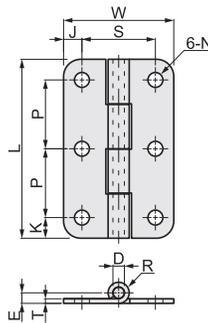

③ Asymmetric Type One Side 2 Holes

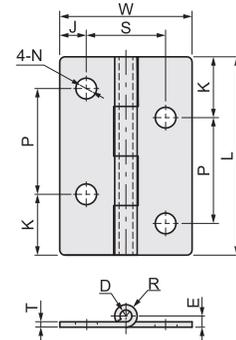

Material: SUS304
Surface Treatment: Sandblasting Grinding

Part Number		③ Number of holes on one side	Type	* Allowable Load		Length L	Width W	K	P	J	S	N	T	E	R	D		
① Type	② No.			kg	N													
C-SHHPSKN	5	2	Symmetrical Type	9	88	41	36	8	25	7.5	21	5.5		2	4.6	4.6	5	
		3		11	108	66												
	6	2		12	117	48	48	9	30	8	32	6.5						
		3		15	147	78												
	8	2		25	245	59	62	11	37	10	42		3	5.6	5.6			
		3		38	372	96												
C-SHHPSKN	5P	2	Asymmetric Type	9	88	40	35	15	20	6	23	4.2	1.5	3	3	3		
	6P	2		15	147	75	50	23	40	10	30	5	2	4.5	4.5	4.5		

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②No.) - ③Number of holes on one side
C-SHHPSKN5 - 2

How to search on website



By Type Search on MISUMI official website
C-SHHPSKN

 
By Keyword Step 1 Search on MISUMI official website
sus hinge

Step 2 Select MISUMI economy series brand
MiSUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Stainless Steel Hinges With Slotted Holes

Representative model: C-SHPSNAN5

Save Up to **69%**
vs Standard Type

90

THB

Shipping
from
1 day




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

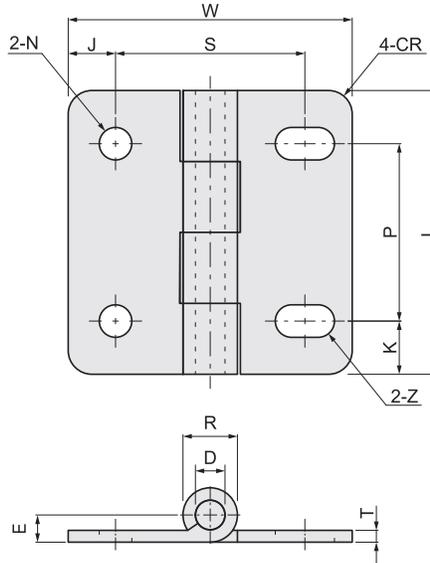

Material: Stainless Steel
Surface Treatment: Sandblasting Grinding

Part Number		* Allowable Load		Mass g	Length L	Width W	K	P	J	S	N	Z	T	E	R	D	CR
1 Type	2 No.	kg	N														
C-SHPSNAN	5	9	88	34	41	36	8	25	7.5	21	5.5	5.5×6.5	2	4.6	9.2	5	4
	6	12	117	48	48	48	9	30	8	32							
	8	25	245	111	59	62	62	11	37	10	42	6.5	6.5×10	3	6.1	12.2	6

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 No.)

C-SHPSNAN5

How to search on website



By Type

Search on MISUMI official website

C-SHPSNAN

By Keyword

Step 1 Search on MISUMI official website

sus hinge

Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-HHSZDN50

Save Up to **70%** vs Standard Type

133 THB

Shipping from **1 day**


Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.



Type	Material	Surface Treatment		Hole Type
		Chain Piece		
C-HHSZN	Stainless Steel	Buffed		Flat Head Screw Type
C-HHSZTN				Ultra Low Head Screw Type
C-HHSZDN	Zinc Alloy	Chrome Plated		Flat Head Screw Type

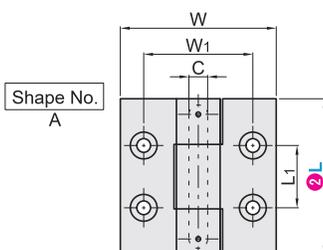

(Flat Head Screw Type)

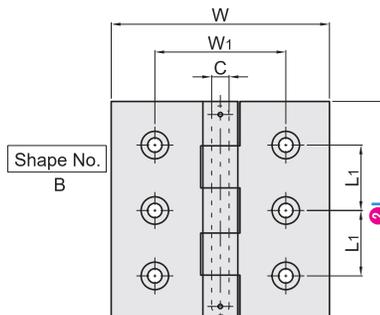

(Ultra Low Head Screw Type)

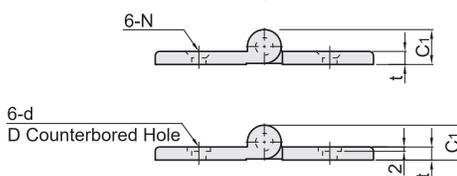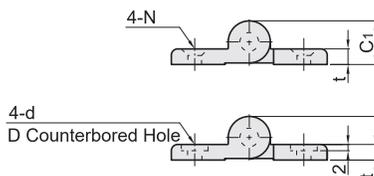

Part Number	Shape No.	W	W ₁	L ₁	C	C ₁	t	Flat Head Screw Type		Ultra Low Head Screw Type		Division	* Allowable Load (N)
								N		D	d		
								Through Hole	Counterbored Hole				
C-HHSZN (Stainless Steel · Flat Head Screw Type)	A	50	35	20	6	14	5	4.4	8.6	8.6	4.6	3	350
								5.6	10.6	9.6	5.6		450
C-HHSZTN (Stainless Steel · Ultra Low Head Screw Type)	A	75	50	40	6	14	5	4.4	8.6	10.6	6.6	5	650
										6.6	12.6		-
C-HHSZDN (Zinc Alloy · Flat Head Screw Type)	B	100	60	30	8	16	6	4.4	8.6	8.6	4.6	5	850
				37.5									-

* The allowable load is the value when 2 pieces are used.
* Zinc alloy material does not apply to dimensions L100 and 125.
⚠ The product model C-HHSZTN125 is currently not available for sale.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2L)

C-HHSZDN50

How to search on website



By Type

Search on MISUMI official website

C-HHSZN

By Keyword

Step 1 Search on MISUMI official website

heavy load hinge

Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-HHSYZN50

Save Up to **66%** vs Standard Type

Shipping from **1 day**




116 THB

Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

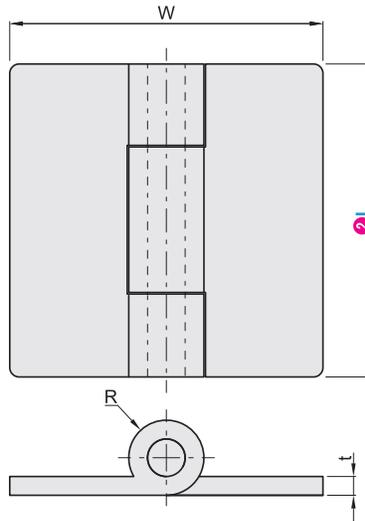

Material: Stainless Steel
Surface Treatment: Sandblasting Grinding

Part Number		Width W	R	t	* Allowable Load (N)
① Type	② Length L				
C-HHSYZN	50	50	6	3	196
	60	64			245
	75	70			294
	100	100	10	4	588
	125				686
	150				120

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②L)

C-HHSYZN50

How to search on website



By Type

Search on MISUMI official website

C-HHSYZN

By Keyword

Step 1 ▶ Search on MISUMI official website

heavy load hinge

Step 2 ▶ Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-HHSZB65



Shipping from 1 day

1,114 THB


Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.


Type	Material	Surface Treatment	Hole Type
		Chain Piece	
C-HHSZB	Stainless Steel	Buffed	Flat Head Screw Type
C-HHSZTB			Ultra Low Head Screw Type

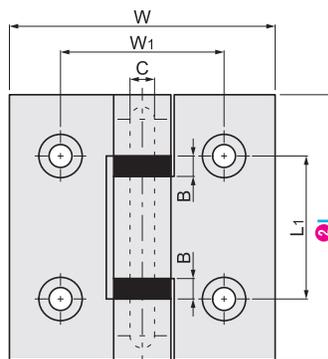

(Flat Head Screw Type)

 

(Ultra Low Head Screw Type)

 

Part Number		Width W	W ₁	L ₁	C	C ₁	t	B	Flat Head Screw Type		Ultra Low Head Screw Type		Division	* Allowable Load (N)
1 Type	2 Length L								N		D	d		
		Through Hole	Counterbored Hole											
C-HHSZB (Flat Head Screw Type)	65	65	40	35	6	14	5	4.5	5.6	10.6	9.6	5.6	3	450
C-HHSZTB (Ultra Low Head Screw Type)	75	75	50	40	8	16	6		6.6	12.6	10.6	6.6		650

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 L)

C-HHSZB65



By Type

Search on MISUMI official website

C-HHSZB

By Keyword

Step 1 Search on MISUMI official website

heavy load hinge

Step 2 Select MISUMI economy series brand

 
MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-HHCSNC5

Save Up to **46%**
vs Standard Type

88

THB

Shipping
from
1 day




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.

Quantity of volume discount above is for representative Part No. It may differ by the Part.

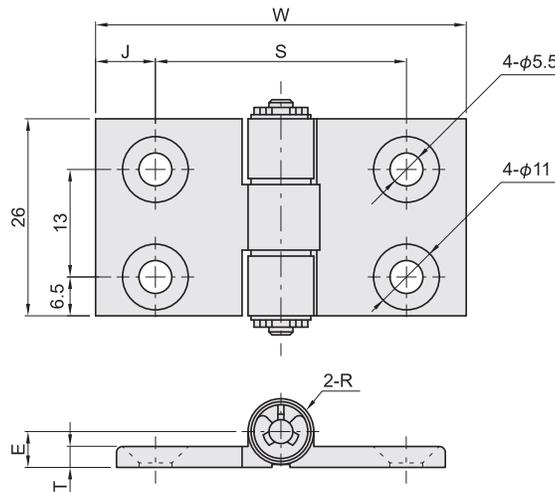

Material: Body: A6063-T5
Bushing: Polyacetal
Surface Treatment: Body : Clear Anodized

Part Number		* Allowable Load		Mass	Width	J	Mounting	T	E	R
① Type	② No.	kg	N	g	W		Pitch S			
C-HHCSNC	5	8	78	15	35.4	7.2	21	3.5	5.5	5
	6			18	48	8	32		6	5.5
	8	12	118	21	62	10	42	4.5	6	5.5
	8-45			30	80	16.5	47			

* The allowable load is the value when 2 pieces are used.

Ordering
Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②No.)

C-HHCSNC5

How to search
on website



By
Type

Search on MISUMI official website

C-HHCSNC



By
Keyword

Step 1 ▶ Search on MISUMI official website

aluminum hinge



Step 2 ▶ Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-HHCSNT5

Save Up to **47%** vs Standard Type

92

THB


Shipping from **1 day**

Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

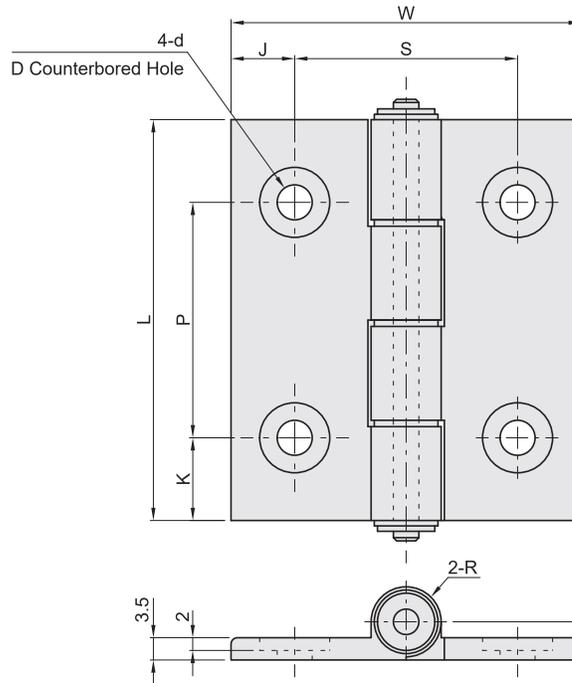

Material: Body: A6063-T5
Bushing: Polyacetal
Surface Treatment: Body : Clear Anodized

Part Number	* Allowable Load	Mass g	Length L	Width W	K	P	J	Mounting Pitch S	d Through Hole	D Counterbored Hole	E
C-HHCSNT	8	78	24	35.4	11	25	7.2	21	5.5	11	5.5
			30								
			50	63	62	13	37	10	42	6	

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 No.)
C-HHCSNT5

How to search on website



By Type Search on MISUMI official website
C-HHCSNT

By Keyword Step 1 Search on MISUMI official website
aluminum hinge

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Aluminum Hinges Slotted Hole

Representative model: C-HHYSNA5

Save Up to **48%** vs Standard Type

96

THB

Shipping from **1 day**




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

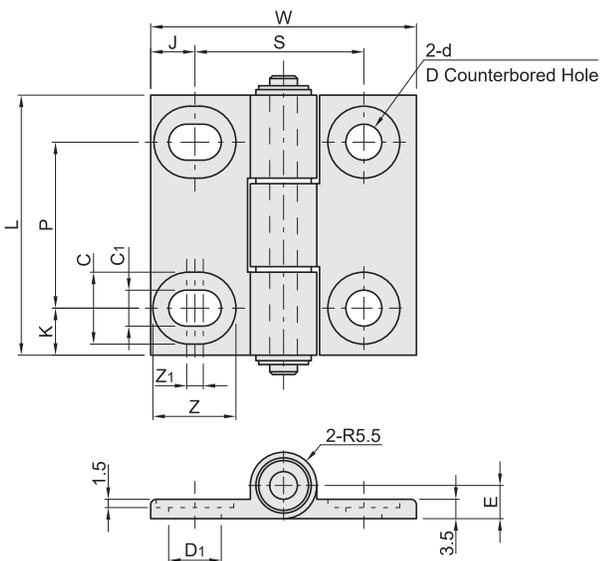

Material: Body: A6063-T5
Bushing: Polyacetal
Surface Treatment: Body : Clear Anodized

Part Number	* Allowable Load		Mass g	Length L	Width W	K	P	J	Mounting Pitch S	d Through Hole	D Counterbored Hole	D1	C	C1	Z	Z1	E
	1 Type	2 No.															
C-HHYSNA	5		24	47	35.4	11	25	7.2	21	5.5	11	7	11	5.5	12.5	1.5	5.5
	6	8	78		31	48	8.5	30	8								
	8		51	63	62	13	37	10	42	6.5	13	11.5	13	6.5	18	5	6

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 No.)

C-HHYSNA5



By Type: Search on MISUMI official website
C-HHYSNA

By Keyword: Step 1 Search on MISUMI official website
aluminum hinge

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-HHFL5

Save Up to **73%** vs Standard Type

Shipping from **1 day**

85 THB

Volume Discount


Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material		Surface Treatment
	Body	Bushing	Body
C-HHFL	A6063-T5	Polyacetal	Clear Anodized
C-HHBFL			Black Anodized

③ One Side 2 Holes

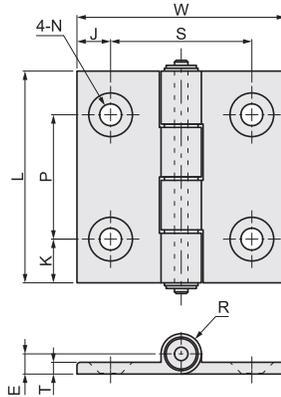

③ One Side 3 Holes

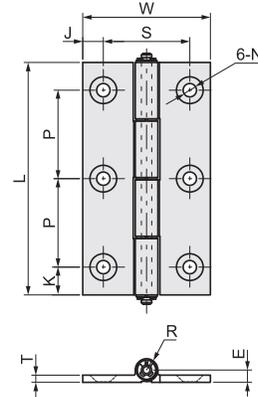

Part Number	① Type	② No.	③ Number of holes on one side	* Allowable Load		Mass	Length L	W	K	P	J	S	N		T	E	R
				kg	N								Through Hole	Counterbored Hole			
C-HHFL (Clear Anodized)	5	5	2	8	78	24	47	35.4	11	25	7.2	21	5.5	11	3.5	5.5	5
			3	15	147	50	66		8								
	6	2	8	78	30	47	48	8.5	30	8	32	6.5	13	6		5.5	
		3	15	147	70	78		9									
C-HHBFL (Black Anodized)	8	8	2	8	78	50	63	62	13	37	10	42	6.5	13	4.5	6	5.5
			3	15	147	110	113		13.5								
	8-45	2	12	118	72	63	80	10	43	16.5	47	6.5	13	4.5		6	5.5
C-HHBFL (Black Anodized)	6	6	2	8	78	30	47	48	8.5	30	8	32	6.5	13	3.5	6	5.5
			3	15	147	70	78		9								
	8	8	8	78	50	63	62	13	37	10	42	6.5	13	4.5		6	5.5
8-45	2	12	118	72	63	80	10	43	16.5	47	6.5	13	4.5	6	5.5		

③ One Side 2 Holes for 8-45 specification at default



Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②No.) - ③Number of holes on one side
 C-HHFL5 - 2
 C-HHBFL8-45



By Type: Search on MISUMI official website

By Keyword: Step 1 ▶ Search on MISUMI official website

Step 2 ▶ Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Aluminum Hinges Tapered Hole Asymmetric Type

Representative model: C-HHFLS6-5

Save Up to **64%** vs Standard Type

92

THB

Shipping from **1 day**




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

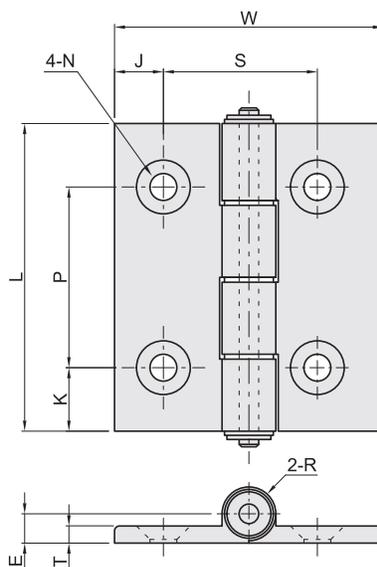

Material: Body: A6063-T5
Bushing: Polyacetal
Surface Treatment: Body : Clear Anodized

Part Number	* Allowable Load		Mass g	Length L	Width W	K	P	J	Mounting Pitch S	N		T	E	R	
	1 Type	2 No.								kg	N				Through Hole
C-HHFLS	6-5	8	78	29	47	44	8.5	30	8	26.5	5.5	11	3.5	6	5.5
											6.5	13			
	8-5	12	118	49	63	55	13	37	10	31.5	5.5	11			
											6.5	13			
	845-5	12	118	49	63	55	13	37	7.5	34	5.5	11			
											6.5	13			
8-6	12	118	49	63	62	13	37	10	37	6.5	13				
										6.5	13				
845-6	12	118	49	63	62	13	37	8	39	6.5	13				

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 No.)
C-HHFLS6-5

How to search on website



By Type Search on MISUMI official website
C-HHFLS

By Keyword Step 1 Search on MISUMI official website
aluminum hinge

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-HHDLS6-5

Save Up to **70%** vs Standard Type

169

THB




Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

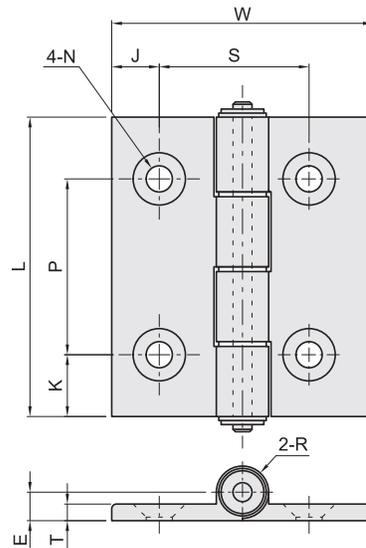

Material: Body: A6063-T5
Bushing: Stainless Steel
Surface Treatment: Body : Clear Anodized

Part Number		* Allowable Load		Mass g	Length L	Width W	K	P	J	Mounting Pitch S	N		T	E	R
1 Type	2 No.	kg	N								Through Hole	Counterbored Hole			
C-HHDLS	6-5	20	198	33	47	44	8.5	30	8	26.5	5.5	11	3.5	6	5.5
	8-5			6.5							13				
	845-5			5.5							11				
	8-6	30	294	52	63	55	13	37	7.5	34	5.5	11			
				8-6							6.5	13			
				845-6							6.5	13			

* The allowable load is the value when 2 pieces are used.



Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 No.)
C-HHDLS6-5

How to search on website



By Type Search on MISUMI official website
C-HHDLS

By Keyword Step 1 Search on MISUMI official website
heavy load hinge

Step 2 Select MISUMI economy series brand
 MISUMI **MISUMI economy**

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-HHDL5

Save Up to **71%** vs Standard Type

163

THB

Shipping from **1 day**




Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Material		Surface Treatment
	Body	Bushing	Body
C-HHDL	A6063-T5	Stainless Steel	Clear Anodized
C-HHBDL			Black Anodized

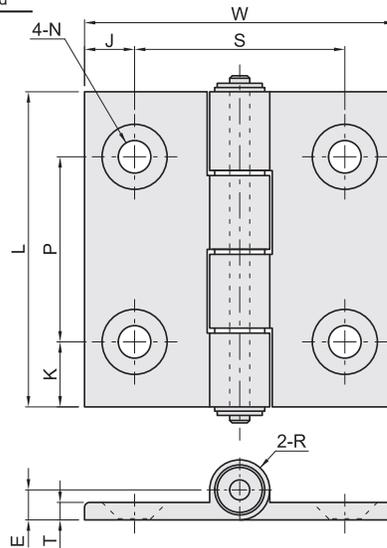

Part Number		* Allowable Load		Mass g	Length L	Width W	K	P	J	S	N		T	E	R	
Type	No.	kg	N								Through Hole	Counterbored Hole				
C-HHDL (Clear Anodized)	5	20	196	28	47	35.4	11	25	7.2	21	5.5	11	3.5	5.5	5	
	6			34		48	8.5	30	8	32						
	C-HHBDL (Black Anodized)	8	30	294	56	63	62	13	37	10	42	6.5	13	4.5	6	5.5
		8-45			78		80	10	43	16.5	47					

* The allowable load is the value when 2 pieces are used.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2No.)
C-HHDL5



By Type: Search on MISUMI official website
C-HHDL

By Keyword: Step 1 Search on MISUMI official website
heavy load hinge

Step 2 Select MISUMI economy series brand
MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Concealed Hinges Round Hole

New Products

Representative model: E-HHG90-S



Shipping from 1 day

63 THB

Volume Discount


Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Part Number	Material	Surface Treatment
E-HNS90	SUS304	-
E-HHG90-B	SPCC	Baking Paint (Black)
E-HHG90-S		Zinc Plating

Part Number	Radial Load (kg)	Axial Load (kg)	Mass (g)
E-HNS90	51	100	138
E-HHG90-B			
E-HHG90-S			

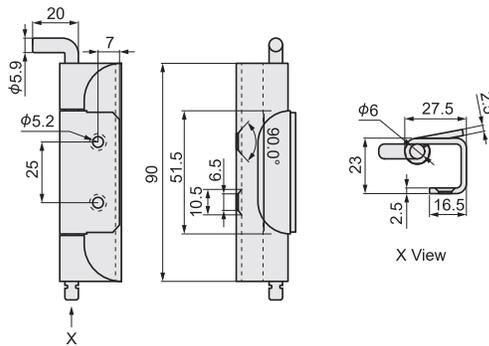

Ordering Example

Part Number
E-HHG90-S

Concealed Hinges Waist Hole / Round Hole Type

New Products

Representative model: E-HHG90-S



Shipping from 1 day

61 THB

Volume Discount


Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Part Number	Material	Surface Treatment
E-HHS90	SUS304	-
E-HHG90-B	SPCC	Baking Paint (Black)
E-HHG90-S		Zinc Plating

Part Number	Radial Load (kg)	Axial Load (kg)	Mass (g)
E-HHS90	51	100	138
E-HHG90-B			
E-HHG90-S			

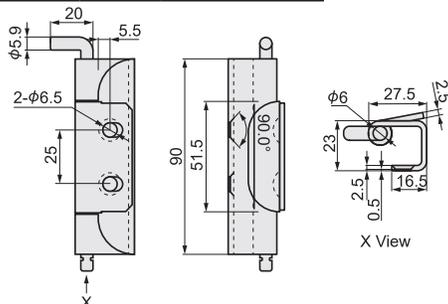

Ordering Example

Part Number
E-HHG90-S

How to search on website



By Type Search on MISUMI official website
E-HHS90

By Keyword Step 1 Search on MISUMI official website
concealed hinge

Step 2 Select MISUMI economy series brand



Concealed Hinges Limit Type

New
Products

Representative model: E-HCL268




Shipping
from
1 day

138

THB

Volume Discount


Quantity	4~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.

Quantity of volume discount above is for representative Part No. It may differ by the Part.

Part Number	Material	Surface Treatment
E-HCL268	SUS304	Vibration Finishing
E-HCL268-B	SPPC	Baking Paint (Black)

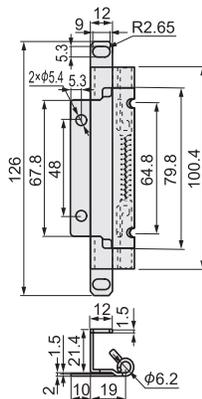

Part Number	Radial Load (kg)	Axial Load (kg)	Mass (g)
E-HCL268	28	50	100
E-HCL268-B			

Ordering
Example

Part Number
E-HCL268

Concealed Hinges Quick Detach Type

New
Products

Representative model: E-HCL201




Shipping
from
1 day

113

THB

Volume Discount


Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.

Quantity of volume discount above is for representative Part No. It may differ by the Part.

Part Number	Material	Surface Treatment
E-HCL201	SUS304	Vibration Finishing
E-HCL201-B	SPPC	Baking Paint (Black)

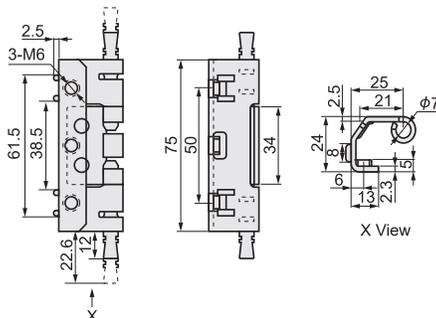

Ordering
Example

Part Number
E-HCL201

How to search
on website



By
Type

Search on MISUMI official website

E-HCL201



By
Keyword

Step 1 ▶ Search on MISUMI official website

concealed hinge



Step 2 ▶ Select MISUMI economy series brand

MiSUMI





New Products

Representative model: E-HYGL60



Shipping from **1** day

21

THB


Volume Discount

Quantity	4~69	70~119	120~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Part Number	Material	Surface Treatment
E-HYGL	SPCC	Zinc Plating
E-HYGR		
E-HYSL	SUS304	Buffed
E-HYSR		

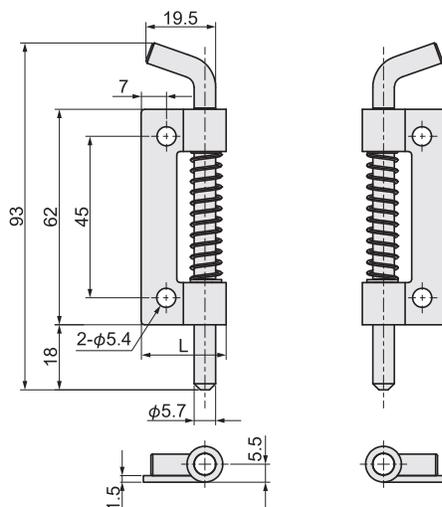

Part Number		Specification	Radial Load (N)	Axial Load (N)	Mass (g)
1 Type	2 No.				
E-HYGL	60	Left Pull-Out Type	100	130	43
E-HYGR		Right Pull-Out Type			
E-HYSL		Left Pull-Out Type	150	200	44
E-HYSR		Right Pull-Out Type			

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 No.)
E-HYGL60

How to search on website



By Type Search on MISUMI official website
E-HYGL

By Keyword Step 1 Search on MISUMI official website
detachable hinge

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-HNZL50



Shipping from **1 day**

411

THB

Volume Discount

Quantity	4~5	6~
Discount	Unit Price	15%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

	Material	Surface Treatment
Body	SUS316	Buffed
Bushing	Wear Resistant Polyacetal	-


(The picture shows the Left Pull-Out Type)

Number of holes on one side: 2

Number of holes on one side: 3

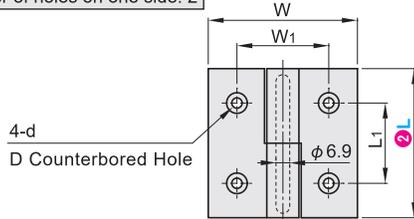

4-d
D Counterbored Hole

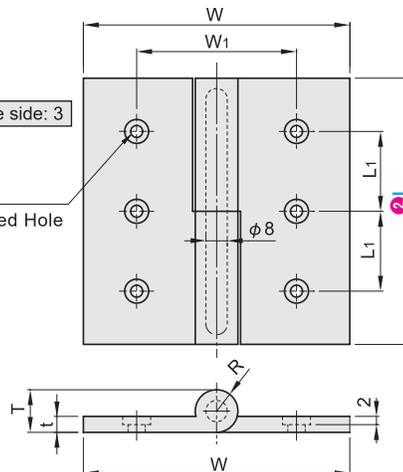

Part Number	Type	L	Number of holes on one side	W	W1	L1	T	R	t	D	d	Mass (g)
E-HNZL (Left Pull-Out Type)	1	50	2	50	35	20	14	13.5	5	8.6	4.6	120
		65		65	40	35				9.6	5.6	185
E-HNZR (Right Pull-Out Type)	1	75	3	75	50	40	16	15.5	6	10.6	6.6	270
		100		100	60	30						450

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2L)
E-HNZL50

How to search on website



By Type

Search on MISUMI official website

E-HNZL



By Keyword

Step 1 Search on MISUMI official website

detachable hinge



Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-HHPNR5



Shipping from **1 day**

130

THB

Volume Discount


Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

	Material	Surface Treatment
Body	A6063S-T5	Anodized
Bushing	Wear Resistant Polyacetal	-

E-HHPNL
(Left Pull-Out Type)

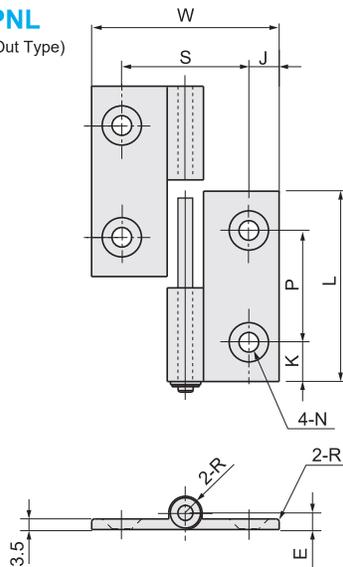

E-HHPNR
(Right Pull-Out Type)

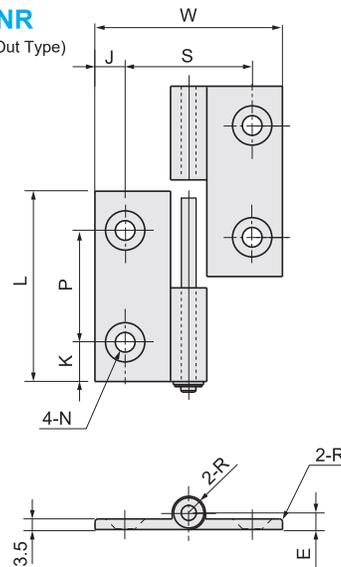

Part Number	Type	2No.	L	W	K	P	J	S	N		E	R	Mass (g)
									Through Hole	Countersink Hole			
E-HHPNL (Left Pull-Out Type)	5	47	36	11	25	7.5	21	5.5	11	5	5	22	
													6
E-HHPNR (Right Pull-Out Type)	8	63	62	13	37	10	42					48	

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1Type · 2No.)

E-HHPNR5



By Type Search on MISUMI official website
E-HHPNL

 
By Keyword Step 1 Search on MISUMI official website
detachable hinge

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products



Representative model: C-MGCEN1

Save Up to **43%** vs Standard Type

109

THB

Shipping from **1 day**


Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

C-MGCEN1

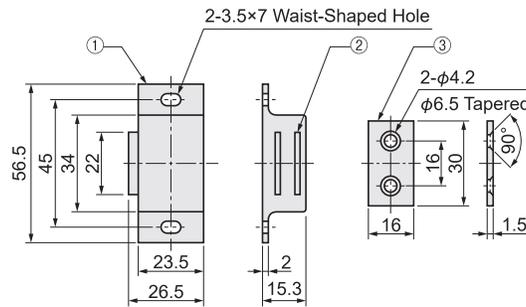

C-MGCEN2

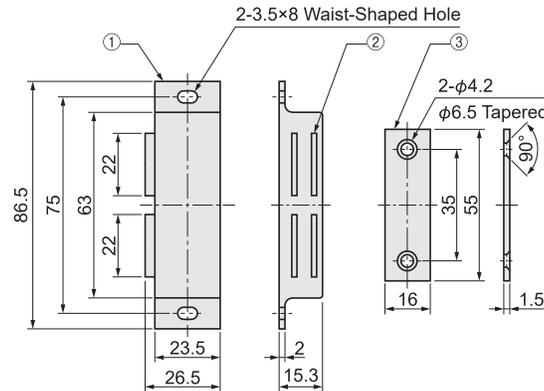

Material: ① Case: Stainless Steel
② Magnet: Ferrite
③ Adsorption Plate: SUS430

Part Number		Retention Force (N)	Mass (g)
① Type	② No.		
C-MGCEN	1	53	36.7
	2	88	72

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②No.)
C-MGCEN1

How to search on website



By Type: Search on MISUMI official website
C-MGCEN

 
By Keyword: Step 1 ▶ Search on MISUMI official website
magnet catch

Step 2 ▶ Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products



Representative model: C-MGCBN2

Save Up to **30%** vs Standard Type

88

THB

Shipping from **1 day**

Volume Discount


Quantity	4~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No.	Part Name	Material	Surface Treatment
①	Case	SUS304	Buffed
②	Magnetic Yoke	SPCC	Nickel Plating
③	Magnet	Ferrite	-
④	Base	Aluminum Alloy	Anodized
⑤	Adsorption Plate	SUS430	-

C-MGCBN1

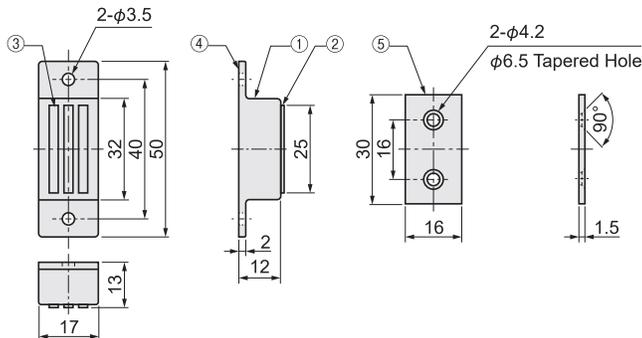

C-MGCBN2

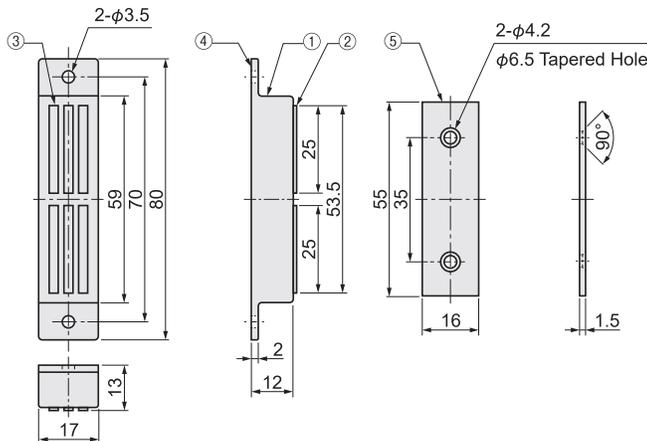

Part Number		Retention Force (N)	Mass (g)
①Type	②No.		
C-MGCBN	1	68	32
	2	98	63

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②No.)

C-MGCBN2

How to search on website



By Type

Search on MISUMI official website

C-MGCBN



By Keyword

Step 1 Search on MISUMI official website

magnet catch



Step 2 Select MISUMI economy series brand

MiSUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Resin Magnetic Catch Two-Way Fixed Type

New Products



Representative model: C-MGCC1

Save Up to **30%** vs Standard Type

100 THB


Shipping from **1 day**

Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

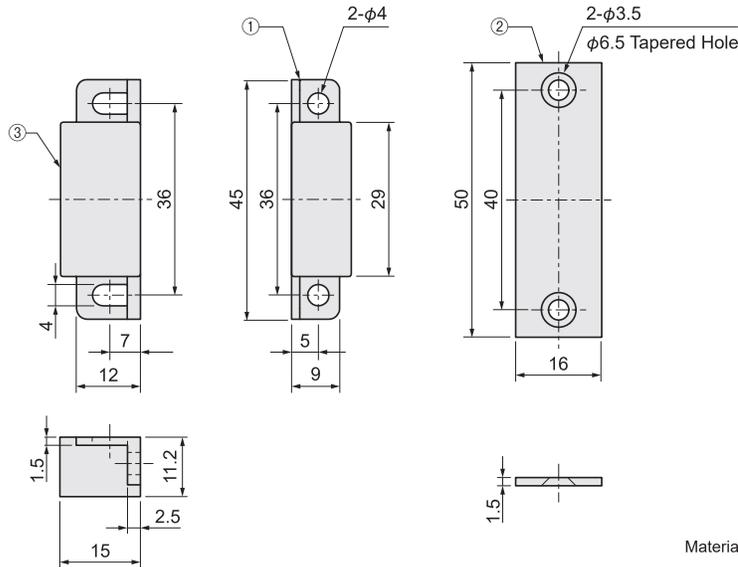

Material: ①Main Body: Polyacetal
②Adsorption Plate: SUS430
③Magnet: Ferrite

Part Number		Retention Force (N)	Case Color
①Type	②No.		
C-MGCC	1	9	Black
	2	13	Gray
	3	19	Milky White
	4	32	White

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②No.)

C-MGCC1

How to search on website



By Type

Search on MISUMI official website

C-MGCC

By Keyword

Step 1 ▶ Search on MISUMI official website

magnet catch

Step 2 ▶ Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products



Representative model: C-MGCP1

Save Up to **56%** vs Standard Type

43

THB

Shipping from **1 day**


Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No.	Part Name	Material	Surface Treatment
①	Case	ABS	-
②	Magnetic Yoke	Steel(Q235)	Zinc Plating
③	Magnet	Ferrite	-

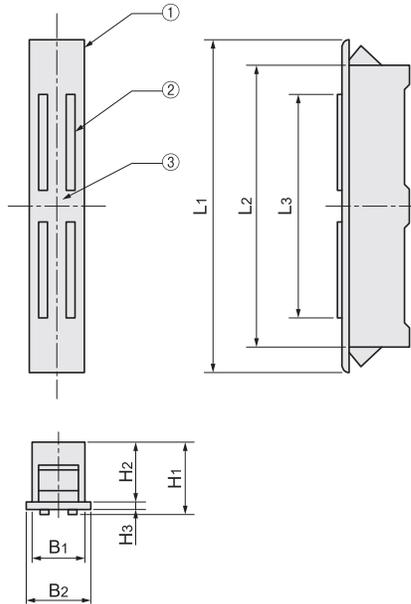

Part Number		Length L1	L2	L3	B1	B2	H1	H2	H3	Case Color	Retention Force (N)
①Type	②No.										
C-MGCP	1	39.8	33.6	21.6	8	10	14.1	11	1	White	38
	2	64	54.6	43			13.9	11.5		1.5	Black
	3	54.3	54.3		10	10.5	13.8		White		97

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②No.)

C-MGCP1



By Type Search on MISUMI official website
C-MGCP

By Keyword Step 1 ▶ Search on MISUMI official website
magnet catch

Step 2 ▶ Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Resin Magnetic Catch Vertical Fixed Small Type

New Products



Representative model: C-MXSR1

Save Up to **63%** vs Standard Type

34

THB

Shipping from **1 day**


Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No.	Part Name	Material	Surface Treatment
①	Case	PP	-
②	Magnetic Yoke	Steel(Q235)	Zinc Plating
③	Magnet	Ferrite	-
④	Adsorption Plate	Steel(Q235)	Zinc Plating

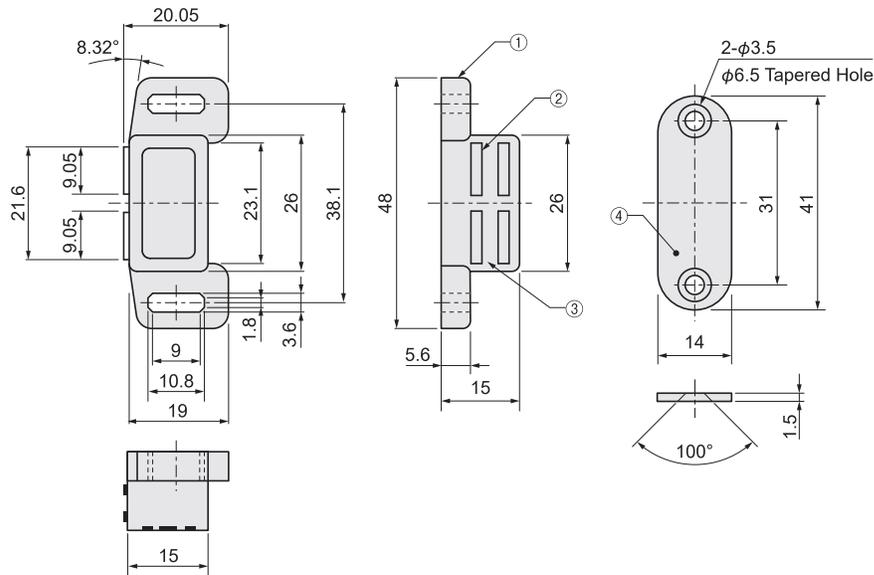

Part Number		Retention Force (N)	Case Color
① Type	② No.		
C-MXSR	1	38	White
	2		Brown

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②No.)

C-MXSR1

How to search on website



By Type

Search on MISUMI official website

C-MXSR

By Keyword

Step 1 ▶ Search on MISUMI official website

magnet catch

Step 2 ▶ Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products



Representative model: C-MCBB1

Save Up to **57%** vs Standard Type

41

THB

Shipping from **1 day**


Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No.	Part Name	Material	Surface Treatment
①	Case	PP	-
②	Magnetic Yoke	Steel(Q235)	Zinc Plating
③	Magnet	Ferrite	-

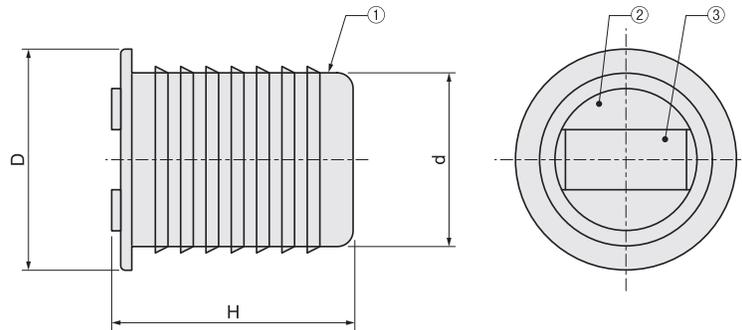

Part Number		Retention Force (N)	D	d	H	Case Color
① Type	② No.					
C-MCBB	1	38	14	11	15.3	Brown
	2					Black
	3	57	16	13	18.3	Brown
	4					Black

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②No.)

C-MCBB1

How to search on website



By Type

Search on MISUMI official website

C-MCBB

By Keyword

Step 1 Search on MISUMI official website

magnet catch

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Resin Magnetic Catch Parallel Fixed Type

New Products



Representative model: C-MGBR

Save Up to **38%** vs Standard Type

67

THB

Shipping from **1 day**


Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No.	Part Name	Material	Surface Treatment
①	Case	PP	-
②	Magnetic Yoke	Steel(Q235)	Zinc Plating
③	Magnet	Ferrite	-
④	Adsorption Plate	Steel(Q235)	Zinc Plating

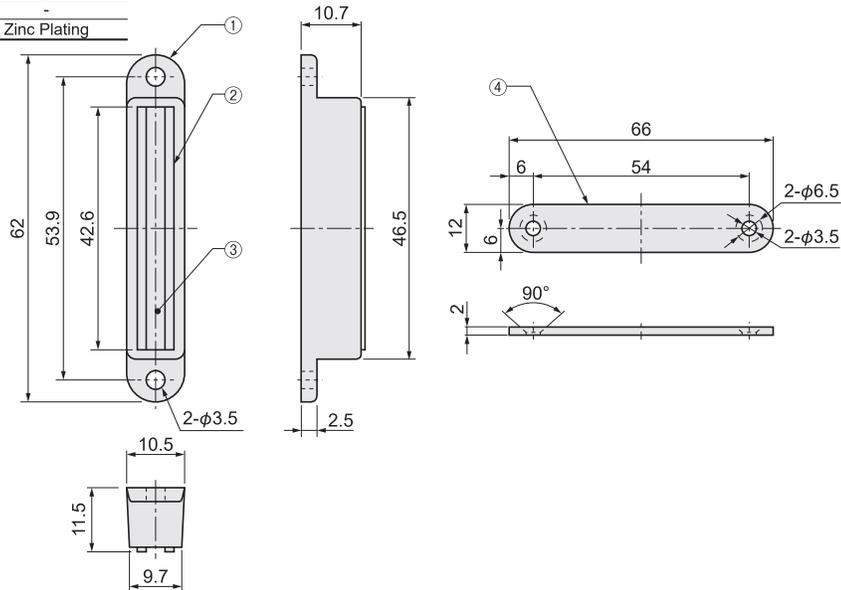

Part Number	Retention Force (N)
C-MGBR	38

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Part Number
C-MGBR

How to search on website



By Type: Search on MISUMI official website
C-MGBR

 
By Keyword: Step 1 Search on MISUMI official website
magnet catch

Step 2 Select MISUMI economy series brand
 MISUMI **MISUMI economy**

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products



Representative model: C-MGCR

Save Up to **54%**
vs Standard Type

Shipping from **1 day**

50 THB


Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No.	Part Name	Material	Surface Treatment
①	Case	PP	-
②	Magnetic Yoke	Steel(Q235)	Zinc Plating
③	Magnet	Ferrite	-
④	Adsorption Plate	Steel(Q235)	Zinc Plating

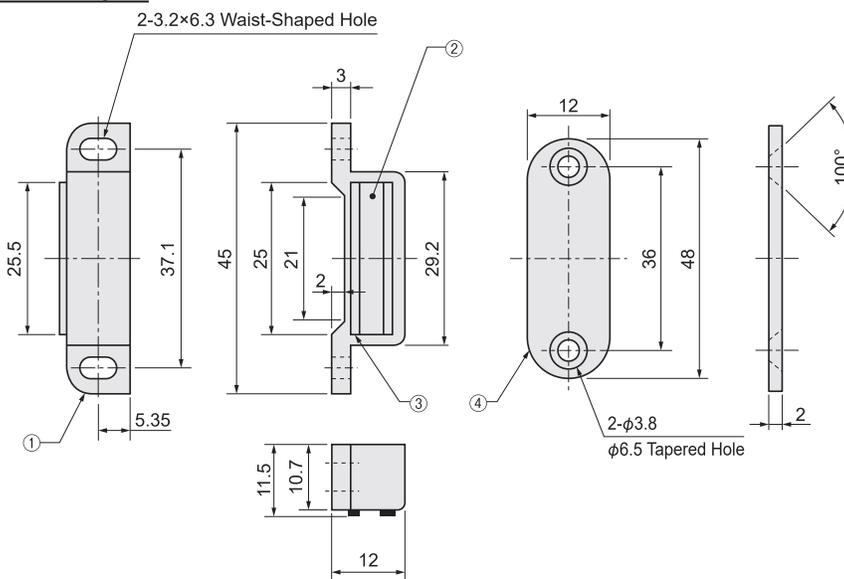

Part Number	Retention Force (N)
C-MGCR	38

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Part Number
C-MGCR

How to search on website



By Type: Search on MISUMI official website
C-MGCR

By Keyword: Step 1 Search on MISUMI official website
magnet catch

Step 2 Select MISUMI economy series brand
 MISUMI **MISUMI economy**

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products



Representative model: C-MGCPN

Save Up to **53%** vs Standard Type

43

THB

Shipping from **1 day**

Volume Discount


Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No.	Part Name	Material	Surface Treatment
①	Case	PP	-
②	Magnetic Yoke	Steel(Q235)	Zinc Plating
③	Magnet	Ferrite	-
④	Adsorption Plate	Steel(Q235)	Zinc Plating

C-MGCPN (Small Embedded Type)

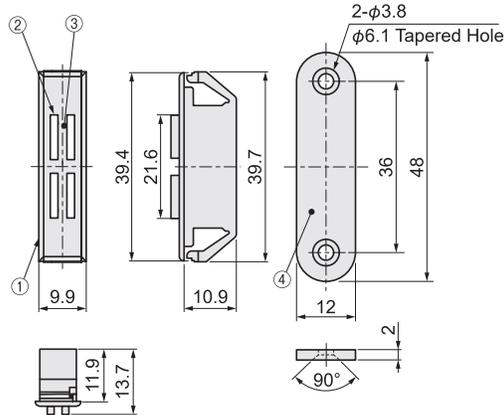

C-MGCBR (Strong Force Type)

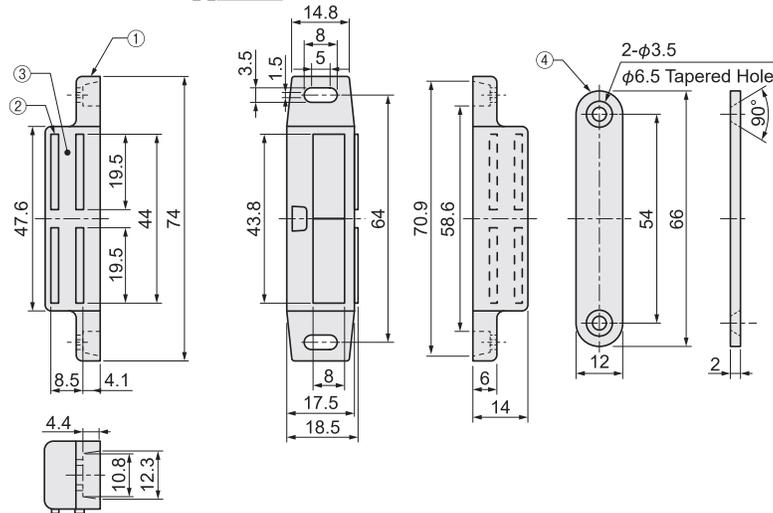

Part Number	Type	Retention Force (N)
C-MGCPN	Small Embedded Type	38
C-MGCBR	Strong Force Type	116

Note) For more information on product specifications and dimensional drawings, please refer to the product catalog on the website.

Ordering Example

Part Number

C-MGCPN
C-MGCBR

How to search on website



By Type

Search on MISUMI official website

C-MGCPN

By Keyword

Step 1 Search on MISUMI official website

magnet catch

Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Economy series Locks

New Arrival

Wide Range of Products

Economical and Durable

Easy Installation

Handles

P.1367

Hinges

P.1383

Magnetic
Catches

P.1405

Locks

P.1414

Knobs

P.1431

Linear Slide
Rails

P.1448

LED Lighting

P.1466

Signal Towers

P.1475

Product Features

· Cylindrical Locks: Most commonly used for small and medium-sized equipment, especially suitable for equipment that often needs frequent detection of door opening and closing

Type	Standard Type	Locking Type	Butterfly Type	Knob Type
Features	Most commonly seen cylindrical locks, available with a variety of stop heights and lock hole shapes	Stroke compression by internal spring, thus locking the door frame	Equipped with butterfly handles to facilitate door opening and closing	Equipped with an easy-to-grip knob to facilitate door opening and closing
Typical Products				
Catalog Page	P.1416	P.1418	P.1421	P.1422

· Flat Locks: Most commonly used for large and medium-sized equipment

Type	Standard Type	Slim Type	Compression Lever Type	Panel Locks Type
Features	The most commonly seen flat locks, available with a variety of lock body lengths	Ultra slim design, suitable for special applications	Adjustable by bolt	Stainless steel material, with excellent anti-rust performance
Typical Products				
Catalog Page	P.1424	P.1427	P.1429	P.1430

Advantages of MISUMI economy series locks

MISUMI economical series locks have undergone various third-party tests such as the number of insertion and removal times, handle torque, weight bearing, and adhesion force, and also come with test reports, ensuring quality and enabling more worry-free use.

Lock Service Life Test

Test Model: E-PAD-117-D-B

Test Site Picture

The key insertion, rotation, and withdrawal are defined as one operation, and after 1000 operations, both the key and plug work properly.

Lock Load Strength Test

Test Model: E-PAD-117-D-B

Test Site Picture

Strength test: The maximum pressure is 47.87KN. No deformation damage, high strength, and not easy to deform.

Toothed washers added for more secure installation

Generic products on the market

Difficulties in use With no anti-loosening measures, the lock is easy to loosen during use. Due to absence of grinding treatment, the surface of stainless steel products is not bright enough.

MISUMI Economy series

Toothed washers are added to ensure secure lock installation. Grinding process is added to stainless steel products, resulting in a brighter surface.

Toothed washer

* Generic products on the market are similar products randomly purchased by our company from online or offline markets

New Products

Representative model: E-PY-28-T



83

THB


Shipping from **1 day**

Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

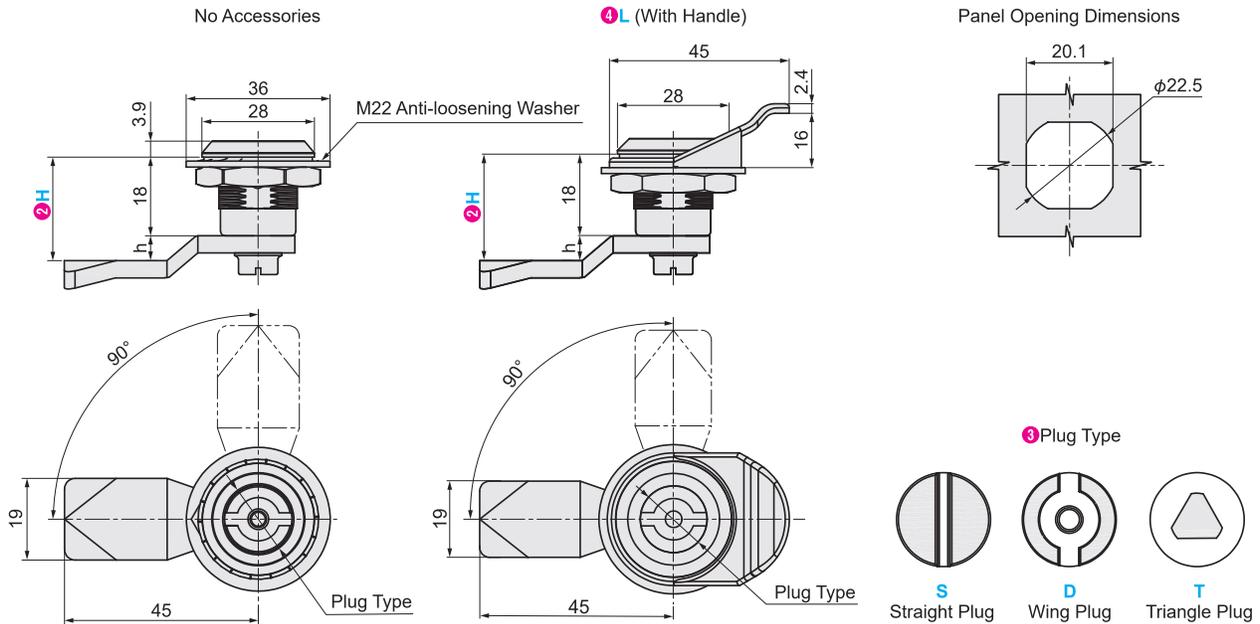

Material: Zinc Alloy
Surface Treatment: Bright Chromate Plating

1 Type	2 H	3 Plug Type	4 Accessories	h
E-PY	18	S (Straight Plug)	- (No Accessories) L (Handles)	0
	24			6
	28			10
	18	D (Wing Plug)		0
	24			6
	28			10
	18	T (Triangle Plug)		0
	24			6
	28			10

The straight plug is not equipped with a key and can be unlocked with a coin.
The locks with wing cylinder and triangle cylinder are equipped with a key.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 4.

Part Number (1) Type	-	2 Stop Height H	-	3 Plug Type	-	4 Accessories
E-PY	-	28	-	T	-	
E-PY	-	28	-	T	-	L

How to search on website



By Type

Search on MISUMI official website

E-PY



By Keyword

Step 1 Search on MISUMI official website

door lock



Step 2 Select MISUMI economy series brand

MISUMI



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-PYS-18-T



223

THB


Shipping from 1 day

Volume Discount

Quantity	2~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

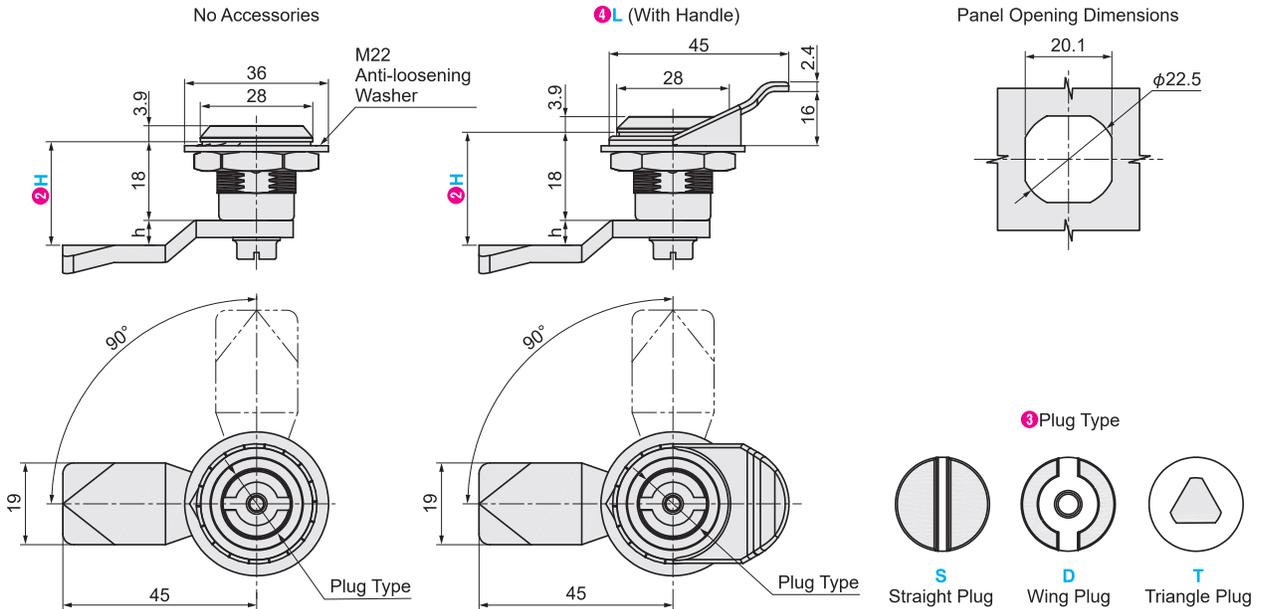

Material: SUS304
Surface Treatment: Buffed

1 Type	2 H	3 Plug Type	4 Accessories	h
E-PYS	18	S (Straight Plug)	-	0
	24			6
	28			10
	18	D (Wing Plug)		0
	24			6
	28			10
	18	T (Triangle Plug)	L (Handles)	0
	24			6
	28			10

The straight plug is not equipped with a key and can be unlocked with a coin.
The locks with wing cylinder and triangle cylinder are equipped with a key

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 4.

Part Number (1 Type) - 2 Stop Height H - 3 Plug Type - 4 Accessories

E-PYS - 18 - T -

E-PYS - 18 - T - L

How to search on website



By Type Search on MISUMI official website
E-PYS

By Keyword Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-JY-28-T



140

THB

Shipping from **1 day**


Volume Discount

Quantity	4~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.




No Accessories

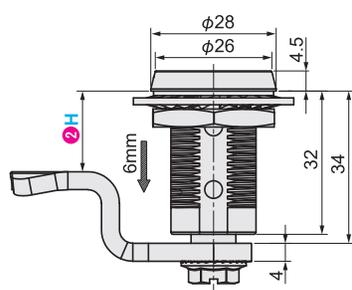

4 L (With Handle)

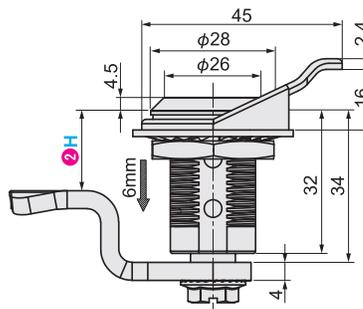

Panel Opening Dimensions

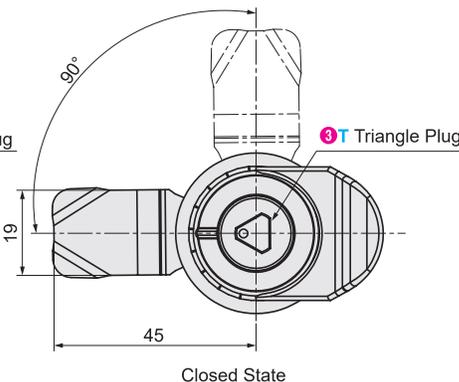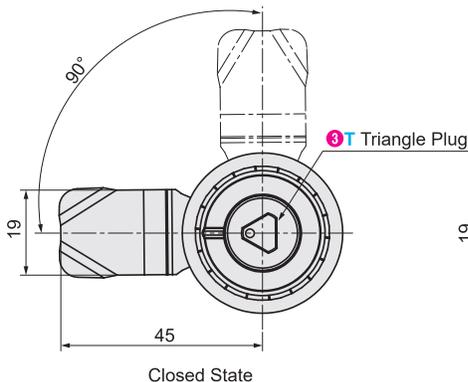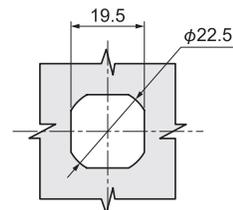

Material: Zinc Alloy
Surface Treatment: Bright Chromate Plating

1 Type	2 H	3 Plug Type	4 Accessories
E-JY	18	T (Triangle Plug)	- (No Accessories)
	28		L (Handles)

Compression distance is 6mm
Each lock is equipped with a key

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 4.

Part Number (1 Type) - 2 Stop Height H - 3 Plug Type - 4 Accessories

E-JY - 28 - T -
E-JY - 28 - T - L

How to search on website



By Type Search on MISUMI official website
E-JY

By Keyword Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-JYS-28-T



673

THB

Shipping from **1 day**

Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%








Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

No Accessories

④ L (With Handle)

Panel Opening Dimensions

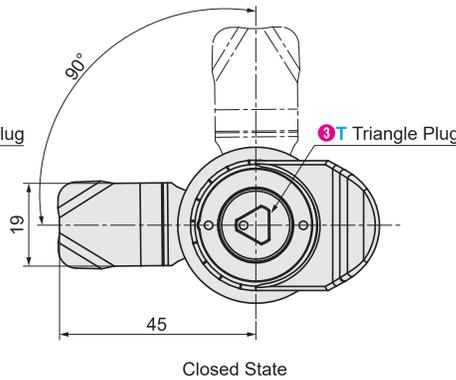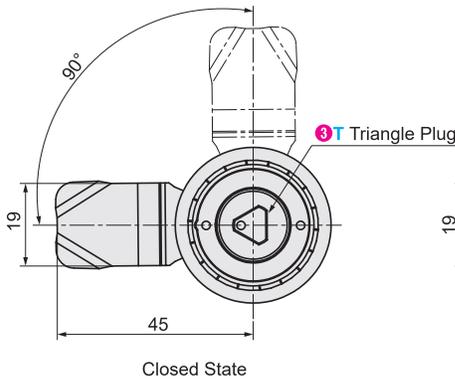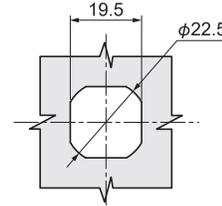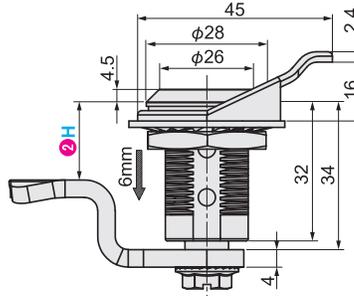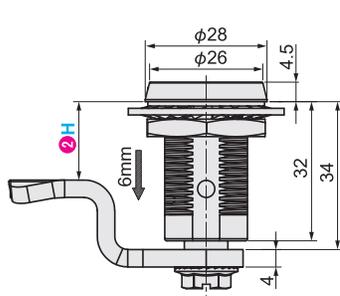

Material: SUS304
Surface Treatment: Buffed

① Type	② H	③ Plug Type	④ Accessories
E-JYS	18	T (Triangle Plug)	- (No Accessories)
	28		L (Handles)

Compression distance is 6mm
Each lock is equipped with a key

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ④.

Part Number (① Type) - ② Stop Height H - ③ Plug Type - ④ Accessories
 E-JYS - 28 - T
 E-JYS - 28 - T - L

How to search on website



By Type Search on MISUMI official website

 
By Keyword Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-FYD-20-S



110

THB


Shipping from **1 day**

Volume Discount

Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

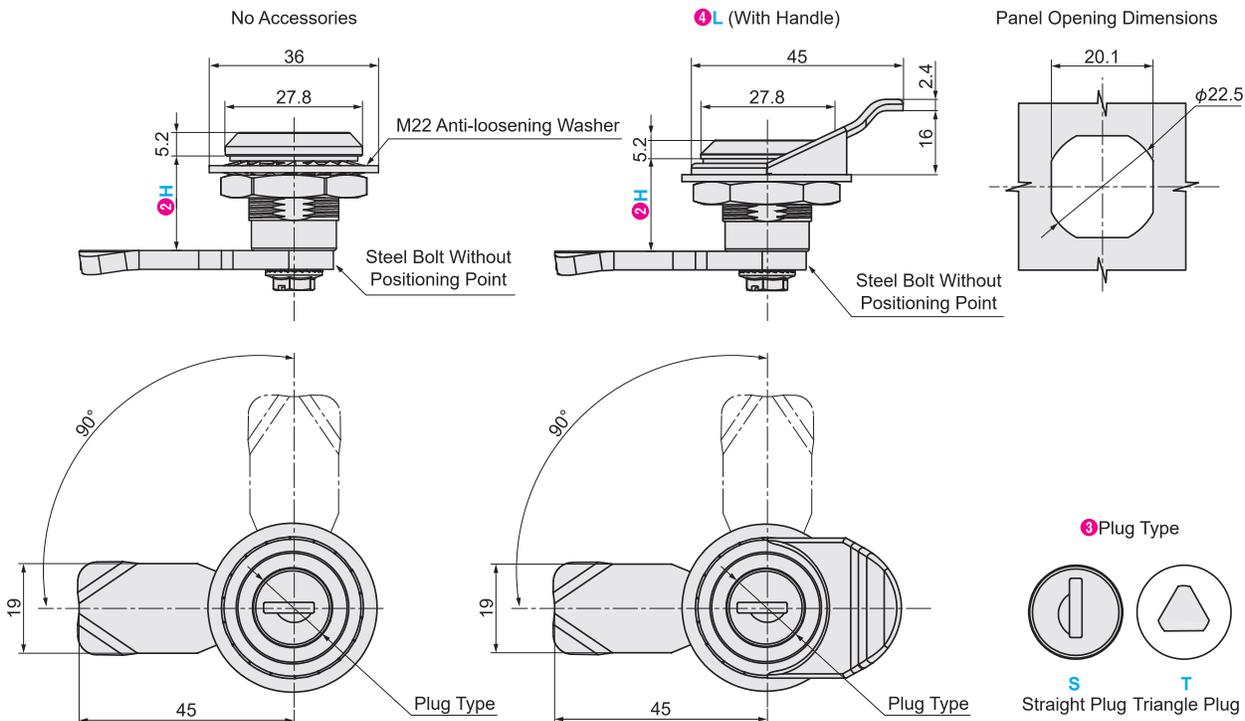

Material: Zinc Alloy
Surface Treatment: Bright Chromate Plating

1 Type	2 H	3 Plug Type	4 Accessories
E-FYD	20	S (Straight Plug) T (Triangle Plug)	- (No Accessories) L (Handles)

Each lock is equipped with a key

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 4.

Part Number (1 Type)	-	2 Stop Height H	-	3 Plug Type	-	4 Accessories
E-FYD	-	20	-	S	-	
E-FYD	-	20	-	S	-	L

How to search on website



By Type Search on MISUMI official website
E-FYD

By Keyword Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-DY-18-D

Shipping from **1 day**







144 THB

Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

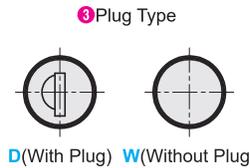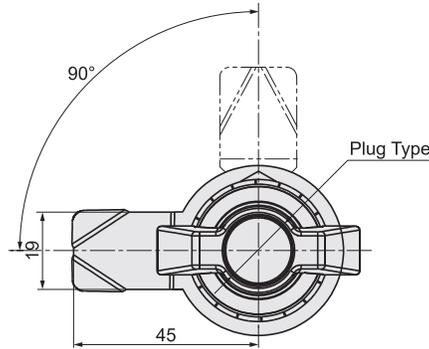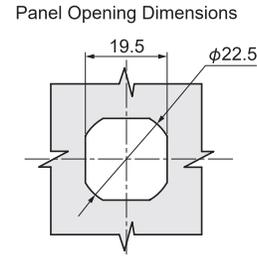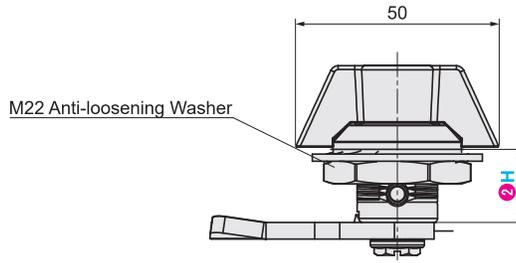

Material: Zinc Alloy
Surface Treatment: Bright Chromate Plating

1 Type	2 H	3 Plug Type
E-DY	18	D (With Plug)
		W (Without Plug)

Only locks with plugs come with toothed washers
Locks with plugs are all equipped with two keys

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type) - (2 Stop Height H) - (3 Plug Type)
E-DY - 18 - D

How to search on website



By Type Search on MISUMI official website
E-DY

By Keyword Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-BTD-28



223

THB


Shipping from **1 day**

Volume Discount



Quantity	2~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

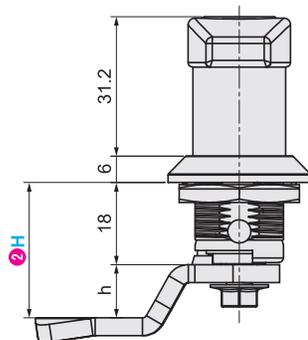

Panel Opening Dimensions

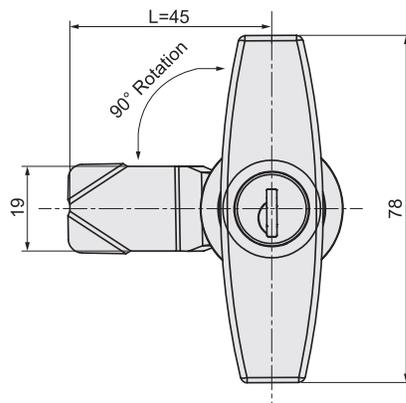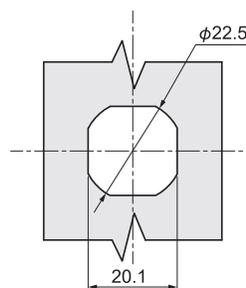

Material: Zinc Alloy
Surface Treatment: Bright Chromate Plating

1 Type	2 H	h	Plug Type
E-BTD	18	0	With Plug
	28	10	

Locks with plugs are all equipped with two keys

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

1 Type - 2 Stop Height H
E-BTD - 28

How to search on website



By Type Search on MISUMI official website
E-BTD

By Keyword Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Knob Locks L-Shaped

New Products

Representative model: E-BLD-28



Shipping from **1 day**

240



THB

Volume Discount

Quantity	2~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

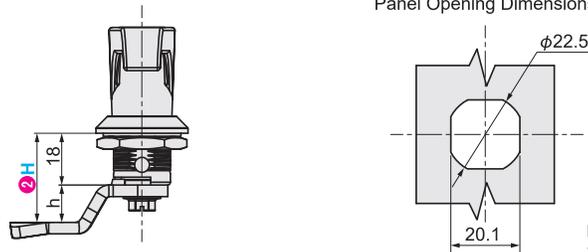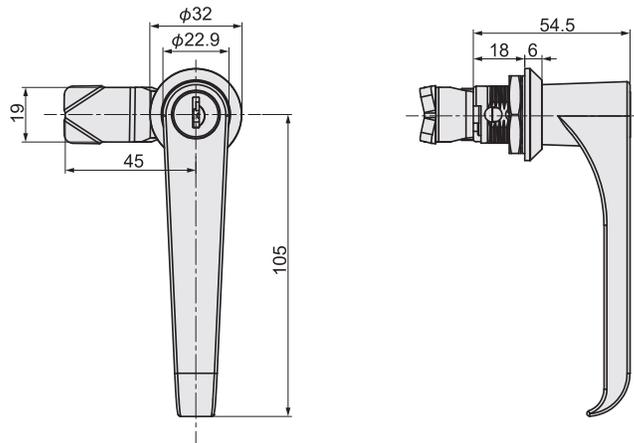

Material: Zinc Alloy
Surface Treatment: Bright Chromate Plating

1 Type	2 H	h	Plug Type
E-BLD	18	0	With Plug
	28	10	

Each lock is equipped with a key

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

1 Type - 2 Stop Height H
E-BLD - 28

How to search on website



By Type Search on MISUMI official website
E-BLD

By Keyword Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand

MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-PAD-117-D-S



250

THB

Shipping from **1 day**

Volume Discount


Quantity	2~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Color	Material			Surface Treatment		
	Base	Knobs	Bolt	Base	Knobs	Bolt
S (Silver)	Aluminum Alloy	Zinc Alloy	A3 Steel	Sliver Paint	Sliver Paint	Zinc Plating
B (Black)	Aluminum Alloy	Zinc Alloy	A3 Steel	Black Paint	Black Paint	Zinc Plating

E-PAD (Single-Point Bolt)

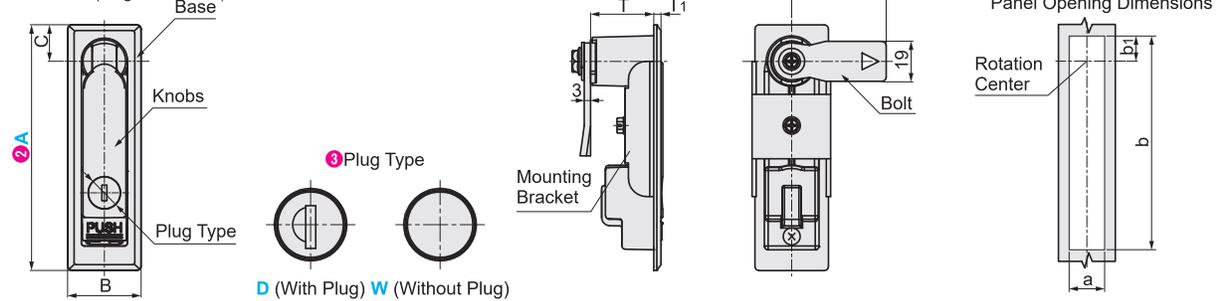

E-PAT (Three-Point Bolt)

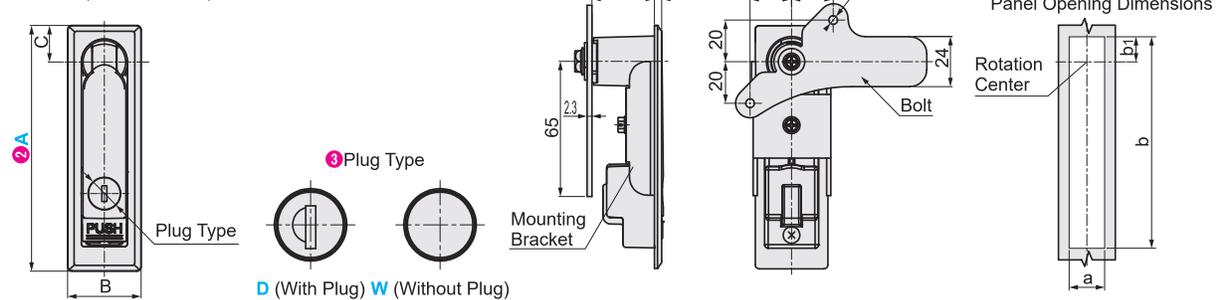

1 Type	2 Lock Body Length A	3 Plug Type	4 Lock Body Color	B	C	T	T1	a	b	b1
E-PAD (Single-Point Bolt) E-PAT (Three-Point Bolt)	84	D (With Plug) W (Without Plug)	S (Silver)	32	16.5	30	3	27.5	76	12.7
	117		B (Black)	35	17.5			27	103	
	138			38	23	3.5	27.5	128	16.8	

Locks with plugs are all equipped with two keys

Ordering Example: Please order after selecting part number and parameters according to the selection steps 1 to 4.

1 Type - 2 Lock Body Length A - 3 Plug Type - 4 Lock Body Color

E-PAD - 117 - D - S

How to search on website

By Type: Search on MISUMI official website. Input: E-PAD

By Keyword: Step 1 Search on MISUMI official website. Step 2 Select MISUMI economy series brand. Input: door lock

MISUMI economy logo

MISUMI contact: Tel: 038-959200 or 1382, Email: cs@misumi.co.th

MISUMI WEB "Chat": MISUMI WEB Chat Now icon

Install MISUMI APP: MISUMI app icon and QR code

Flat Locks Push Dot Push Button Type

New Products

Representative model: E-PLD



Shipping from **1 day**

106

THB


Volume Discount

Quantity	2~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Material			Surface Treatment		
Base	Knobs	Bolt	Base	Knobs	Bolt
Zinc Alloy	Zinc Alloy	A3 Steel	Sandblasting Chrome Plated	Sandblasting Chrome Plated	Zinc Plating

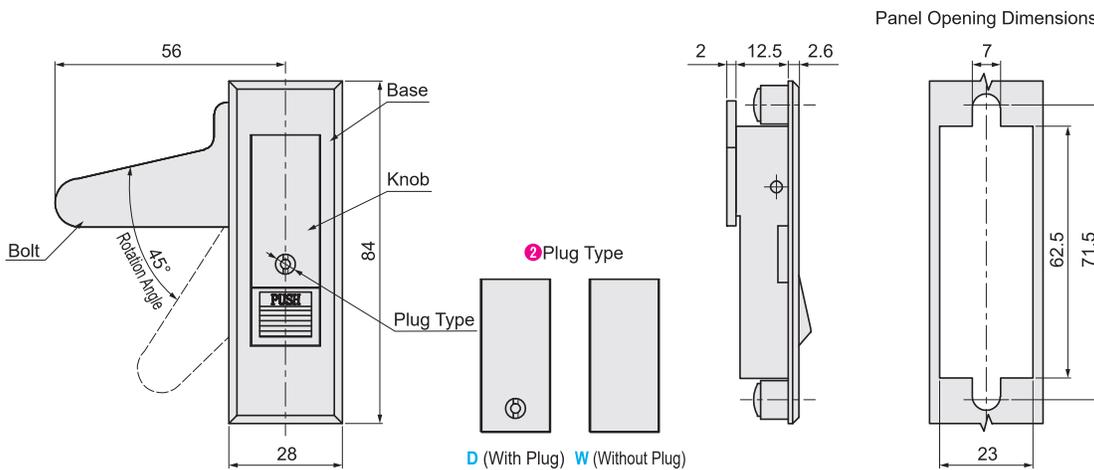

Part Number	
1 Type	2 Plug Type
E-PL	D (With Plug) W (Without Plug)

Locks with plugs are all equipped with two keys

Please order after selecting part number and parameters according to the selection steps **1** to **2**.

Ordering Example
Part Number (**1**Type · **2**Plug Type)
E-PLD

How to search on website

By Type: Search on MISUMI official website

By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-BAD-117-S



Shipping from 1 day

225

THB

Volume Discount


Quantity	2~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Color	Material			Surface Treatment		
	Base	Knobs	Bolt	Base	Knobs	Bolt
S (Silver)	Aluminum Alloy	Zinc Alloy	A3 Steel	Sliver Paint	Sliver Paint	Zinc Plating
B (Black)	Aluminum Alloy	Zinc Alloy	A3 Steel	Black Paint	Black Paint	Zinc Plating

E-BAD (Single-Point Bolt)

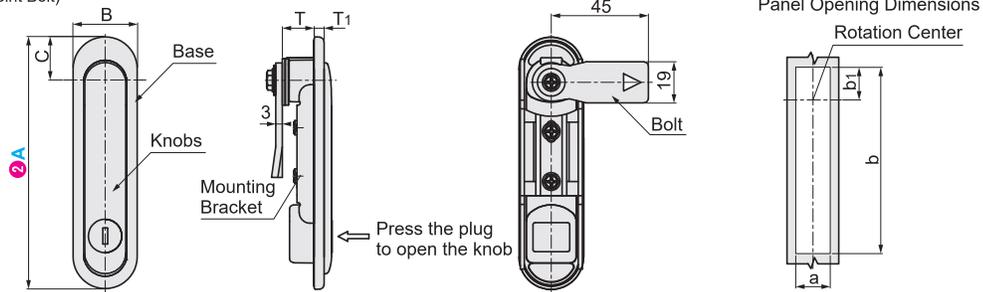

E-BAT (Three-Point Bolt)

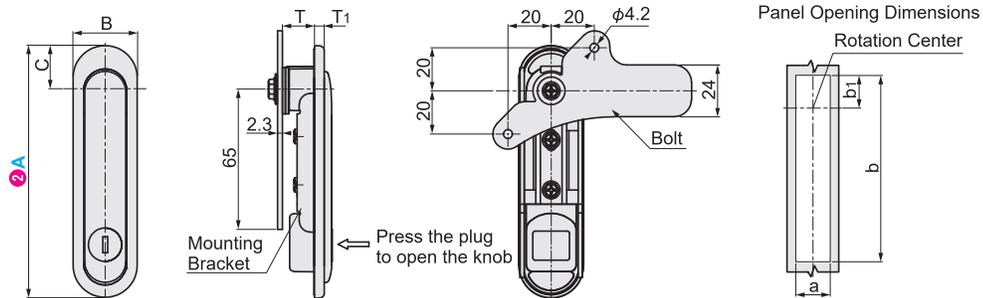

① Type	② Lock Body Length A	③ Lock Body Color	B	C	T	T1	a	b	b1
E-BAD (Single-Point Bolt) E-BAT (Three-Point Bolt)	84	S (Silver) B (Black)	28	21	15	4.5	24	63	12.7
	117		30	20				96	11
	138		33	27.5				117	13.6

Each lock is equipped with two keys

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

① Type - ② Lock Body Length A - ③ Lock Body Color

E-BAD - 117 - S

How to search on website



By Type: Search on MISUMI official website

Type: E-BAD

By Keyword: Step 1 Search on MISUMI official website

Keyword: door lock

Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-BLS-121-D



Shipping from **1 day**

1,265 THB

Volume Discount


Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.


③ D (Single-Point):

Panel Opening Dimensions

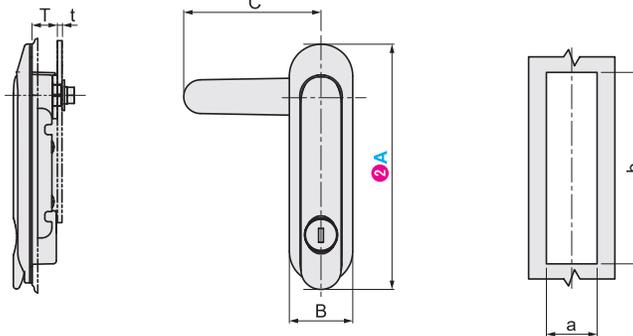

③ T (Three-Point):

Panel Opening Dimensions

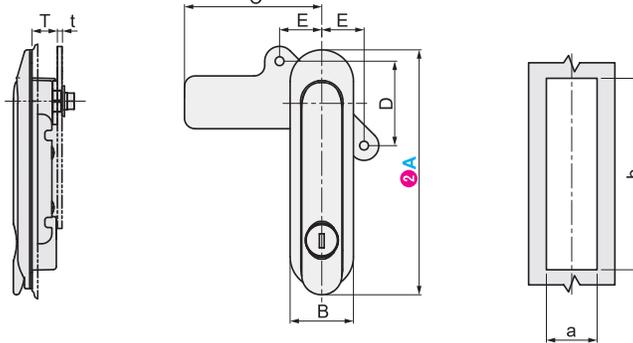

Material: SUS304
Surface Treatment: Buffed

① Type	② Lock Body Length A	③ Bolt Type	B	C	D	E	T	t	a	b
E-BLS	91	D (Single-Point)	28.5	65	-	-	12.5	2.5	24	63
	121		30							96
	149		33							72
	91	T (Three-Point)	28.5	65	40	20	12.5	2.3	24	63
	121		30							96
	149		33							72

Locks with plugs are all equipped with two keys

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

① Type - ② Lock Body Length A - ③ Bolt Type
E-BLS - 121 - D

How to search on website



By Type: Search on MISUMI official website
E-BLS

By Keyword: Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-YAD-117-D-S



378

THB

Shipping from **1 day**

Volume Discount


Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Lock Body Color	Material			Surface Treatment		
	Base	Knobs	Bolt	Base	Knobs	Bolt
S (Silver)	Aluminum Alloy	Zinc Alloy	A3 Steel	Sliver Paint	Sliver Paint	Zinc Plating
B (Black)	Aluminum Alloy	Zinc Alloy	A3 Steel	Black Paint	Black Paint	Zinc Plating

E-YAD (Single-Point Bolt)

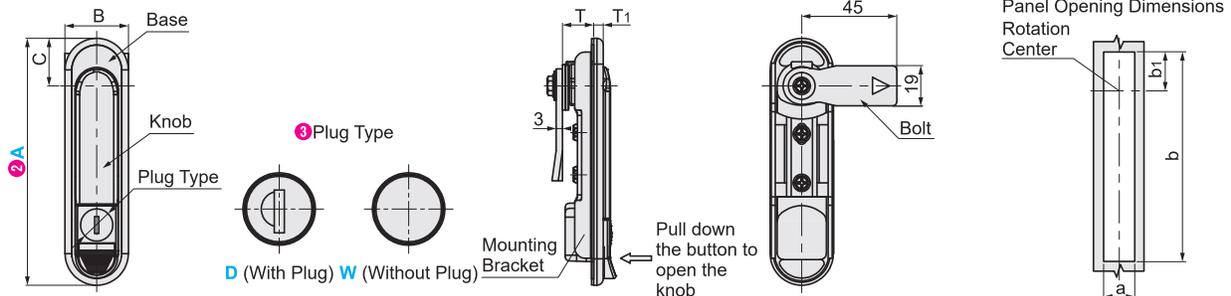

E-YAT (Three-Point Bolt)

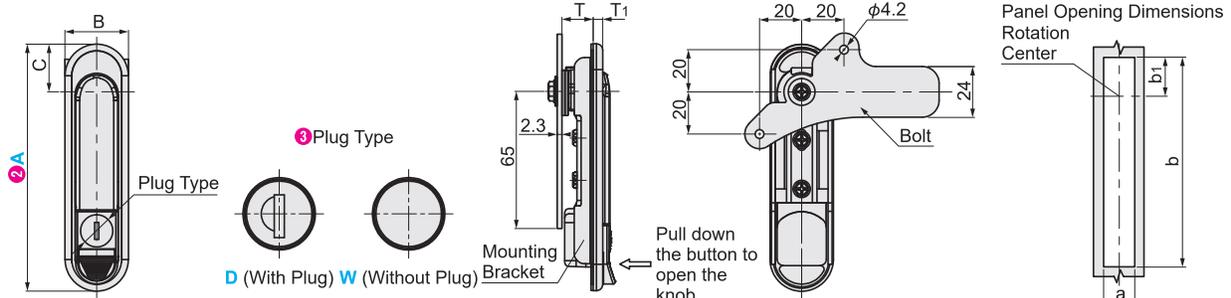

① Type	② Lock Body Length A	③ Plug Type	④ Lock Body Color	B	C	T	T1	a	b	b1
E-YAD (Single-Point Bolt)	84	D (With Plug) W (Without Plug)	S (Silver) B (Black)	28.5	22.5	15	4.5	23.5	62.5	12.2
	117			30	23				95.5	11.9
E-YAT (Three-Point Bolt)	138			25.6	117			13.5		

Locks with plugs are all equipped with two keys

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ④.

Part Number (① Type) - Lock Body Length A - Plug Type - Lock Body Color
E-YAD - 117 - D - S

How to search on website



By Type: Search on MISUMI official website
E-YAD

By Keyword: Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-YG-S



Shipping from **1 day**

1,603 THB


Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Lock Body Color	Material	Surface Treatment	
		Base	Knobs
S (Silver)	Zinc Alloy	Nickel Plating	Nickel Plating
B (Black)		Coated Black	Coated Black

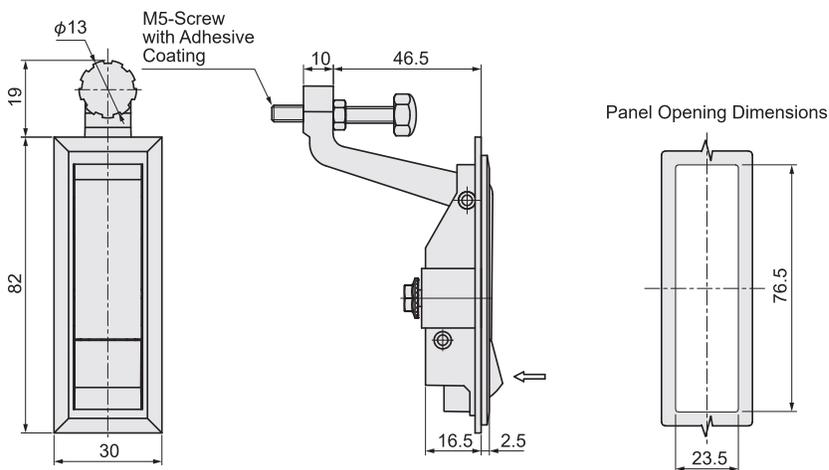

Part Number ① Type	② Lock Body Color
E-YG	S (Silver)
	B (Black)

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (① Type) - ② Lock Body Color
E-YG - S

How to search on website



By Type: Search on MISUMI official website
E-YG

By Keyword: Step 1 Search on MISUMI official website
door lock

Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



New Products

Representative model: E-MWS



184 THB

Shipping from 1 day


Volume Discount

Quantity	2~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

E-MWS

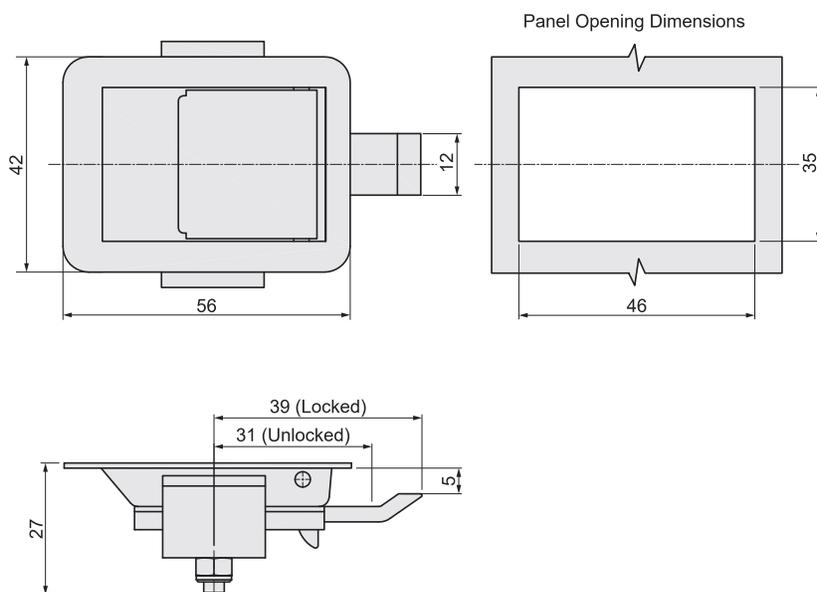

Material: SUS304
Surface Treatment: Hairline Finish

Ordering Example

Part Number
E-MWS

How to search on website



By Type
Search on MISUMI official website

By Keyword
Step 1 ▶ Search on MISUMI official website

Step 2 ▶ Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Economy series Knobs

Suitable for standard screws and nuts Fixing, locking, etc.

Smooth surface

Easy to use




vs Standard Type
Saving up to
86%


Advantages of MISUMI Economy series

· High-quality phenolic raw materials, smooth and beautiful surface with luster

· Improved process, no screw tilt, and easy to use

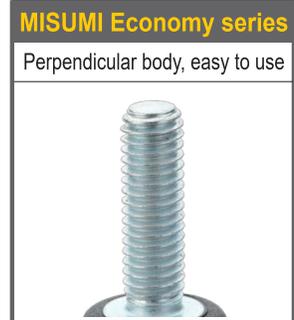


· High screw torque for more secure locking
The screw complies with GB standard management, which has a higher torque force than generic products in the market, and more secure locking in actual application, reducing the risk of shaking and loosening.

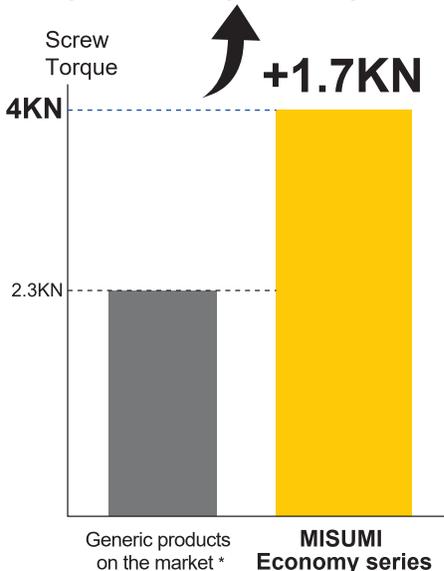

Example of Use

Mainly used on the outside of the equipment for easy opening and carrying, and can also be used for locking parts

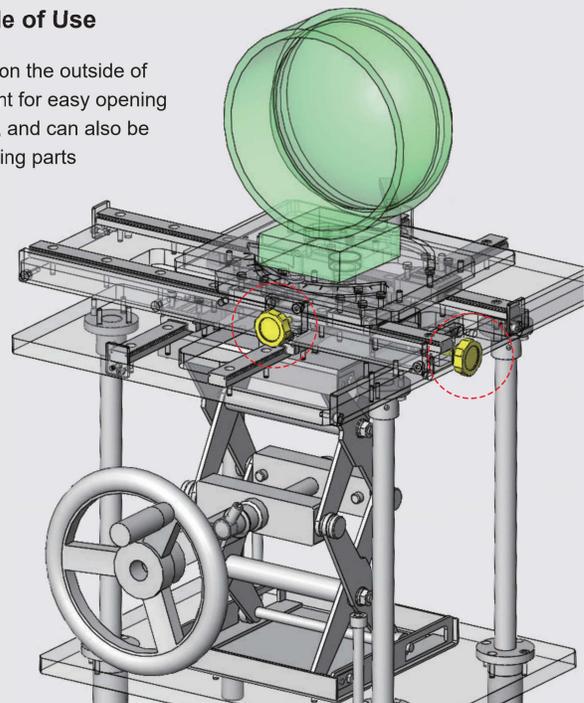

* Generic products on the market are similar products randomly purchased by our company from online or offline markets



Representative model: C-NKOS4-10

Save Up to **30%** vs Standard Type

143

THB



Volume Discount


Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.

Quantity of volume discount above is for representative Part No. It may differ by the Part.

C-NKOS (Threaded Type)

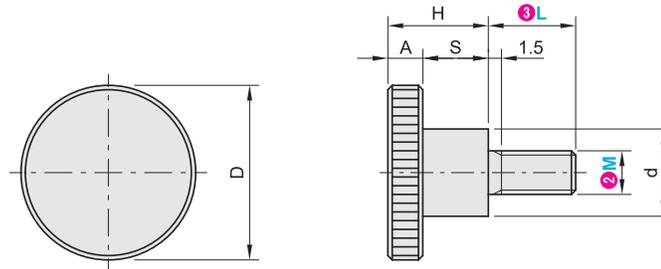

C-NKMS (Tapped Type)

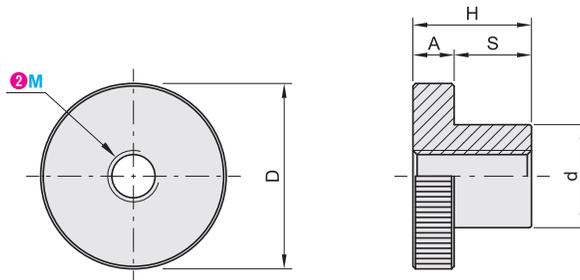

Material: Stainless Steel
Surface Treatment: Hairline Finish

Threaded Type

Part Number		Length L	D	d	A	H	S
Type	Thread M						
C-NKOS	4	10	16	8	3.5	9.5	6
	5		20	10	4	11.5	7.5
	6	16	24	12	5	15	10
		20					
		25					

Tapped Type

Part Number		D	d	A	H	S
Type	Thread M					
C-NKMS	3	12	6	2.5	7.5	5
	6	24	12	5	15	10
	10	36	20	8	23	15



Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type · 2 M) - (3 L)
C-NKOS4 - 10

How to search on website



By Type Search on MISUMI official website
C-NKOS

By Keyword Step 1 Search on MISUMI official website
knurled knob

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NOOS3-16

Save Up to **30%**
vs Standard Type

115

THB

Shipping
from
1 day




Volume Discount

Quantity	4~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

C-NOOS (Threaded Type)

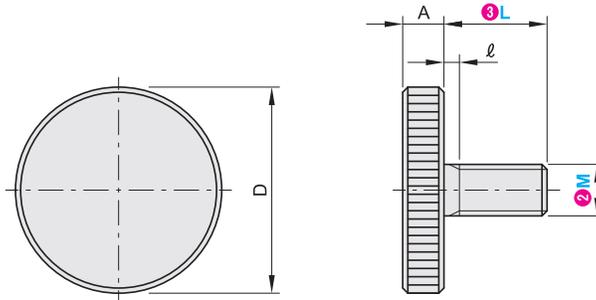

C-NOMS (Tapped Type)

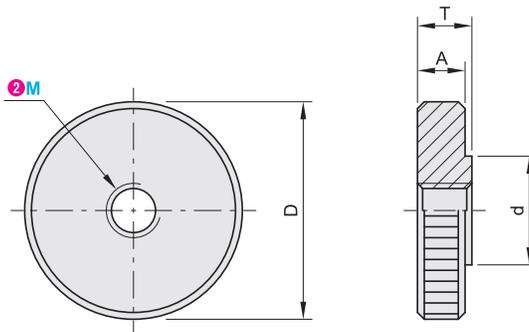

Material: Stainless Steel
Surface Treatment: Hairline Finish

Threaded Type

Part Number		③ Length L	D	A	l
① Type	② Thread M				
C-NOOS	3	16	12	2.5	1
	4	10	16	3.5	1.5

Tapped Type

Part Number		T	D	A	d
① Type	② Thread M				
C-NOMS	4	4	16	3.5	8

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②M) - ③L
C-NOOS3 - 16

How to search on website



By Type Search on MISUMI official website
C-NOOS

By Keyword Step 1 ▶ Search on MISUMI official website
knurled knob

Step 2 ▶ Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-NOSC4-10-12

Save Up to **30%** vs Standard Type

Shipping from **1 day**

156 THB


Volume Discount

Quantity	4~9	10~14	15~
Discount	Unit Price	15%	30%




Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

C-NOSC (Standard Type)

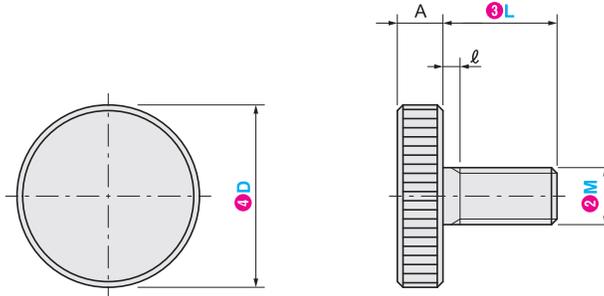

C-NKOSC (Stepped Type)

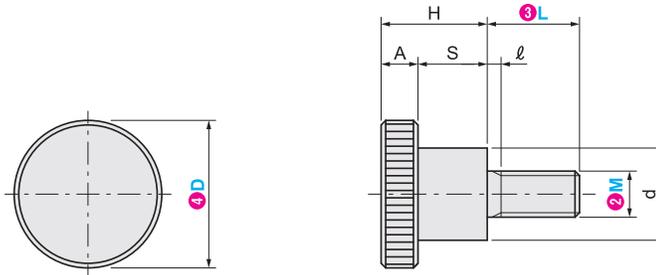

Material: Stainless Steel
Surface Treatment: Hairline Finish

Standard Type

Part Number		③ Length L	④ O.D. D	A	ℓ
① Type	② Thread M				
C-NOSC	4	10	12	3.5	1.5
		16			
	5	10	16	4	

Stepped Type

Part Number		③ Length L	④ O.D. D	d	A	H	S	ℓ
① Type	② Thread M							
C-NKOSC	4	10	12	8	3.5	9.5	6	1.5
	5	10	16	10	4	11.5	7.5	



Please order after selecting part number and parameters according to the selection steps ① to ④.

Part Number (①Type · ②M) - ③L - ④D
C-NOSC4 - 10 - 12

How to search on website



By Type Search on MISUMI official website
C-NOSC

By Keyword Step 1 Search on MISUMI official website
knurled knob

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NKOSD6-15

Save Up to **30%** vs Standard Type

298

THB




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

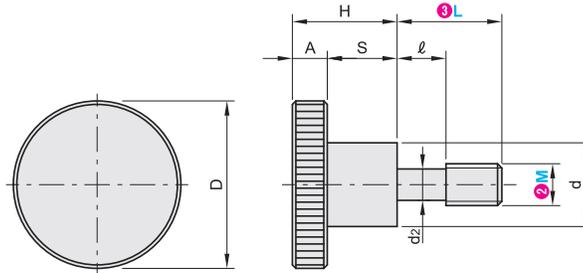

Material: Stainless Steel
Surface Treatment: Hairline Finish

Part Number		③ Length L	D	d	A	H	S	d2	l
① Type	② Thread M								
C-NKOSD	6	15	24	12	5	15	10	4.5	7
		20							12
	8	30	30	16	6	16	12	6	20

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②M) - (③L)
C-NKOSD6 - 15

How to search on website



By Type: Search on MISUMI official website
C-NKOSD

By Keyword: Step 1 Search on MISUMI official website
knurled knob

Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-NDZM4-10

Save Up to **86%** vs Standard Type

26

THB



Volume Discount



Quantity	1~69	70~119	120~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body Material	Material	Thread Surface Treatment
C-NDZM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NDZF	Tapped Type		Brass	-

C-NDZM (Threaded Type)

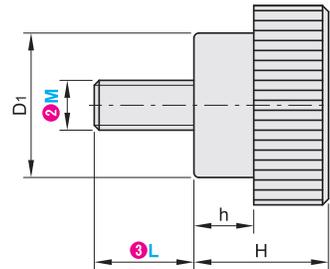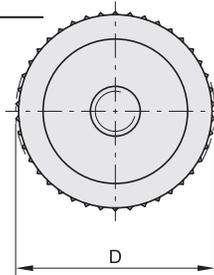

C-NDZF (Tapped Type)

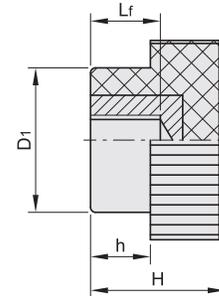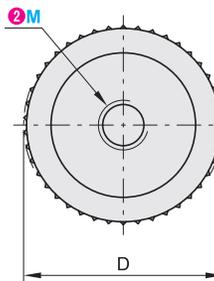

Threaded Type

Part Number		Length L Selection			D	H	D1	h
1 Type	2 Thread M	3						
C-NDZM	4	10	15	20	20	13.5	14.5	6
	5	10	15	20				
	6	10	15	20	25	16.5	16	8
	8	15	20	25				

Tapped Type

Part Number		Lf	D	H	D1	h
1 Type	2 Thread M					
C-NDZF	4	7	20	13.5	14.5	6
	5	9				
	6	11	25	16.5	16	8
	8	15				

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type · 2 M) - 3 L
C-NDZM4 - 10

How to search on website



By Type: Search on MISUMI official website
C-NDZM

By Keyword: Step 1 Search on MISUMI official website
t knob

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NZWM4-10

Save Up to **82%** vs Standard Type

19

THB

Shipping from **1 day**



Volume Discount



Quantity	1~69	70~119	120~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body Material	Material	Thread Surface Treatment
C-NZWM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NZWF	Tapped Type		Brass	-

C-NZWM (Threaded Type)

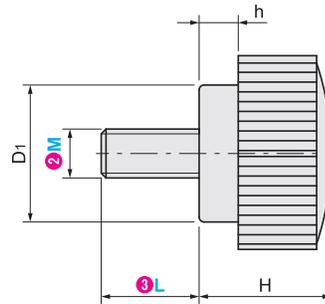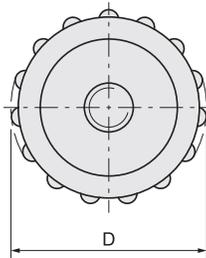

C-NZWF (Tapped Type)

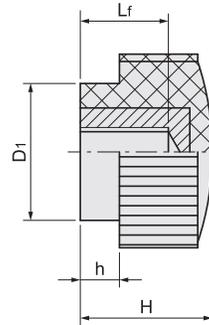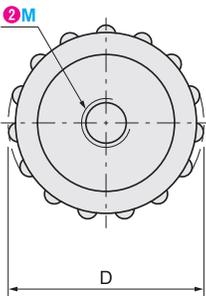

■ Threaded Type

Part Number		③ Length L Selection			D	H	D ₁	h
① Type	② Thread M	10	15	20				
C-NZWM	4	10	15	20	15.5	10.5	11.5	2
	5	10	15	20	20	13.5	14	4.5
	6	10	15	20	24.5	16	16.5	5
	8		15	20	25	32	20	18

■ Tapped Type

Part Number		L _f	D	H	D ₁	h
① Type	② Thread M					
C-NZWF	4	7	15.5	10.5	11.5	2
	5	9	20	13.5	14	4.5
	6	11	24.5	16	16.5	5
	8	15	32	20	18	6.5

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②M) - ③L
C-NZWM4 - 10

How to search on website



By Type

Search on MISUMI official website

C-NZWM



By Keyword

Step 1 Search on MISUMI official website

grained knob



Step 2 Select MISUMI economy series brand

MISUMI

 


MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NDXF5

Save Up to **67%** vs Standard Type

33

THB

Shipping from **1** day



Volume Discount



Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body Material	Material	Thread Surface Treatment
C-NDXM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NDXF	Tapped Type	Phenolic	Brass	-

C-NDXM (Threaded Type)

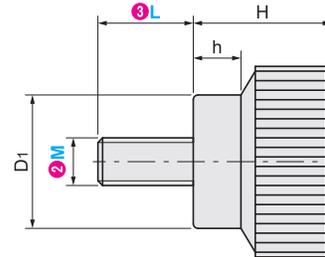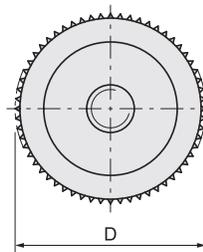

C-NDXF (Tapped Type)

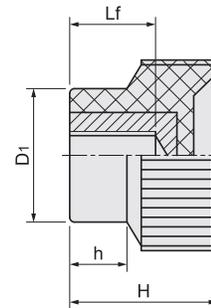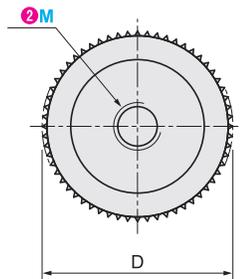

Threaded Type

Part Number		Length L Selection			D	H	D1	h
1 Type	2 Thread M	3						
C-NDXM	4	10	15	20	20	15.5	14	5
	5	10	15	20				
	6	15	20	30	24.5	18.5	16	7
	8	15	20	30	32	22	20	9

Tapped Type

Part Number		Lf	D	H	D1	h
1 Type	2 Thread M					
C-NDXF	4	7	20	15.5	14	5
	5	9				
	6	11	24.5	18.5	16	7
	8	15	32	22	20	9

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type · 2 M) - 3 L
C-NDXM5 - 10

How to search on website



By Type Search on MISUMI official website
C-NDXM

By Keyword Step 1 Search on MISUMI official website
disc knob

Step 2 Select MISUMI economy series brand
MiSUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NTXF6



122

THB




Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

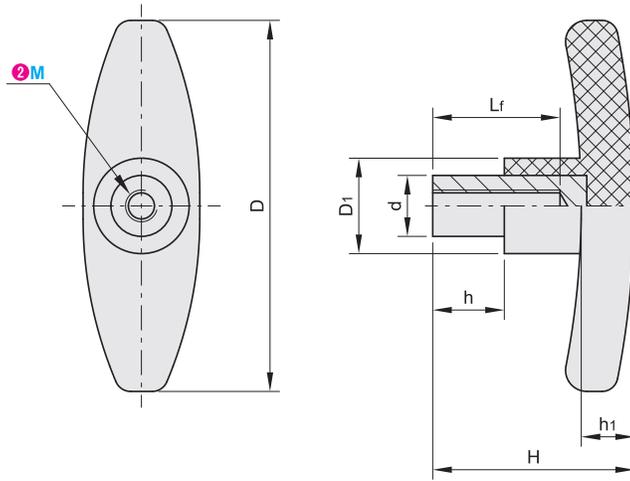

Material: Knob Body: Phenolic Resin
Threaded Part: Brass (Insert)
Main Body Color: Black

Part Number		D	H	D1	d	h	h1	Lf
1 Type	2 Thread M							
C-NTXF	6	70	38	18	12	13.5	10	24
	8	80	43.5	21	15.8	16.5	12.5	26
	10	90	44.5	22.5	18	16	13	25

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 M)
C-NTXF6

How to search on website



By Search on MISUMI official website
Type C-NTXF

By Keyword Step 1 Search on MISUMI official website
Keyword t knob

Step 2 Select MISUMI economy series brand

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NSJF10



180

THB




Volume Discount

Quantity	1~9	10~14	15~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

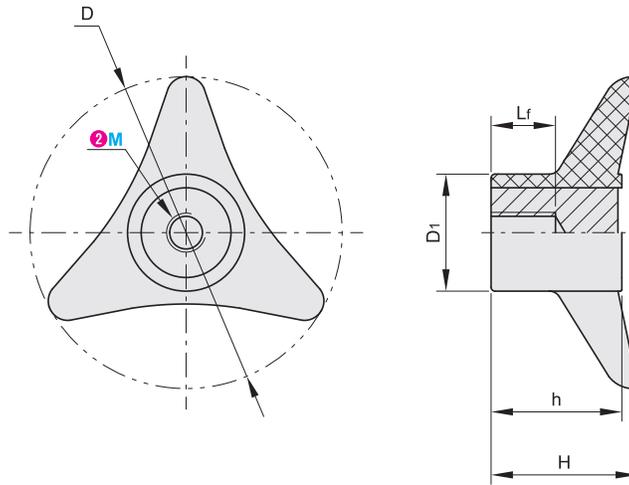

Material: Knob Body: Phenolic Resin
Threaded Part: Brass (Insert)
Main Body Color: Black

Part Number		D	H	D1	h	Lf
1 Type	2 Thread M					
C-NSJF	10	80	38	30	34	17
	12	100	42.5	35	41	21

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 2.

Part Number (1 Type · 2 M)
C-NSJF10



By Type Search on MISUMI official website
C-NSJF

By Keyword Step 1 Search on MISUMI official website
arch knob

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Triangular Arch Knobs

Representative model: C-NSJGM5-10

Save Up to **55%** vs Standard Type

33

THB

Shipping from **1 day**



Volume Discount



Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body Material	Thread Material	Thread Surface Treatment
C-NSJGM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NSJGF	Tapped Type	-	Brass	-

C-NSJGM (Threaded Type)

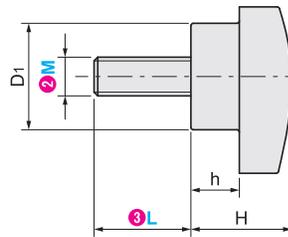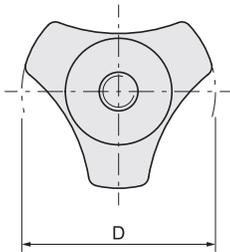

C-NSJGF (Tapped Type)

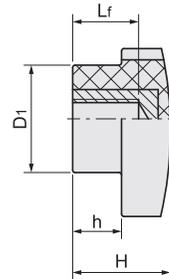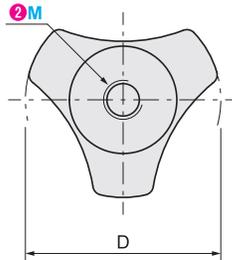

Threaded Type

Part Number		Length L Selection			D	H	D ₁	h
1 Type	2 Thread M	3						
C-NSJGM	5	10	20	25	25	14	14	7
	6		20	25	30	32	19	17
	8		20	25	30	40	21	22

Tapped Type

Part Number		L _f	D	H	D ₁	h
1 Type	2 Thread M					
C-NSJGF	5	10	25	14	14	7
	6	12	32	19	17	10
	8	16	40	21	22	

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type · 2 M) - 3 L
 C-NSJGM5 - 10

How to search on website



By Type: Search on MISUMI official website

By Keyword: Step 1 Search on MISUMI official website

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NWJM5-10

Save Up to **39%** vs Standard Type

34

THB

Shipping from **1 day**



Volume Discount



Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body		Thread
		Material	Material	Surface Treatment
C-NWJM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NWJF	Tapped Type		Brass	

C-NWJM (Threaded Type)

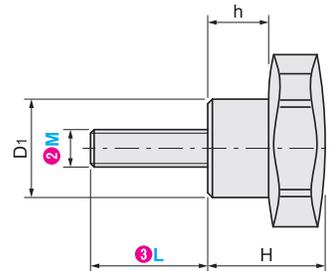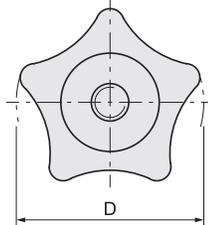

C-NWJF (Tapped Type)

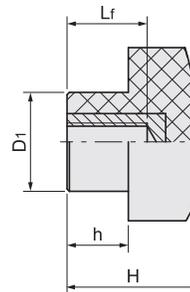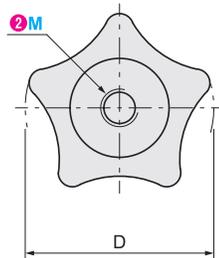

Threaded Type

Part Number		Length L Selection			D	H	D1	h		
1 Type	2 Thread M	3								
C-NWJM	5	10	15	20	25	21.5	14.5	8.5		
	6	10	15	20	32	23.5	20	9.5		
	8		15	20	25	40	26	21	11	
	10			20	25	30	50	32	27	12.5
	12			20	25	30	63	37	31	16.5

Tapped Type

Part Number		Lf	D	H	D1	h
1 Type	2 Thread M					
C-NWJF	5	10	25	21.5	14.5	8.5
	6	11	32	23.5	20	9.5
	8	16	40	26	21	11
	10	20	50	32	27	12.5
	12	25	63	37	31	16.5

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type · 2 M) - (3 L)
C-NWJM5 - 10

How to search on website



By Type: Search on MISUMI official website
C-NWJM

By Keyword: Step 1 Search on MISUMI official website
pentagonal knob

Step 2 Select MISUMI economy series brand
 MiSUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NLJF8

Save Up to **50%** vs Standard Type

55

THB

Shipping from **1 day**



Volume Discount



Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body Material	Thread Material	Thread Surface Treatment
C-NLJM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NLJF	Tapped Type	-	Brass	-

C-NLJM (Threaded Type)

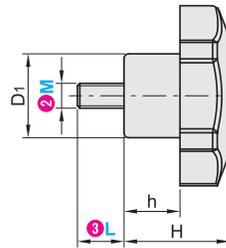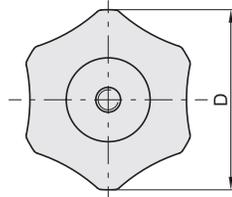

C-NLJF (Tapped Type)

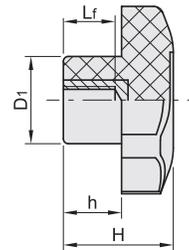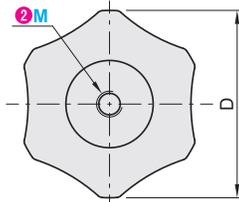

■ Threaded Type

Part Number		③ Length L Selection	D	D1	H	h
① Type	② Thread M					
C-NLJM	8	10 15	58	27	34	18

■ Tapped Type

Part Number		Lf	D	D1	H	h
① Type	② Thread M					
C-NLJF	8	16	58	27	34	18
	10	18				
	12	25				

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②M) - ③L
 C-NLJM8 - 10

How to search on website



By Type: Search on MISUMI official website
 C-NLJM

By Keyword: Step 1 Search on MISUMI official website
 six lobed knob

Step 2 Select MISUMI economy series brand
 MiSUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NQJM10-25

Save Up to **43%** vs Standard Type

71

THB

Shipping from **1 day**





Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



① Shipping days may differ by Quantity.
② Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body Material	Material	Thread Surface Treatment
C-NQJM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NQJF	Tapped Type	-	Brass	-

C-NQJM (Threaded Type)

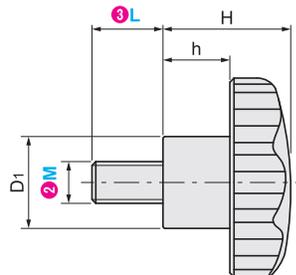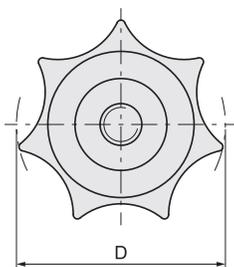

C-NQJF (Tapped Type)

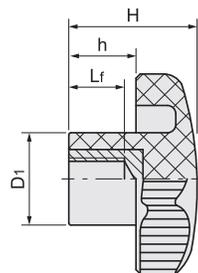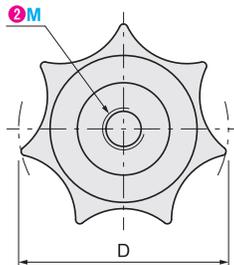

Threaded Type

Part Number		③ Length L Selection		D	H	D ₁	h
① Type	② Thread M						
C-NQJM	10	25	30	50	32.5	22.5	16
	12	25	30	80	50.5	36	25

Tapped Type

Part Number		L _f	D	H	D ₁	h
① Type	② Thread M					
C-NQJF	10	17	50	32.5	22.5	16
	12	21	80	50.5	36	25

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (① Type · ② M) - ③ L
C-NQJM10 - 25

How to search on website



By Type: Search on MISUMI official website
C-NQJM

 
By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
heptagonal knob



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Heptagonal Knob Female Thread

Representative model: C-NLZT6

Save Up to **57%** vs Standard Type

Shipping from **1 day**




32 THB

Volume Discount

Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

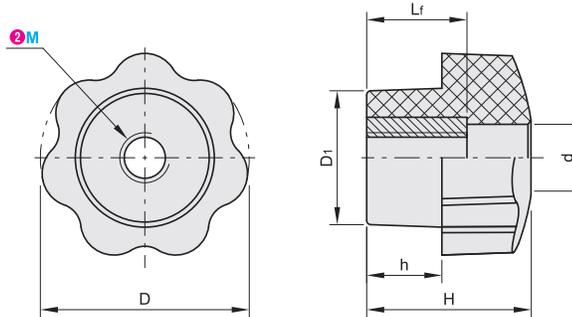

Material: Knob Body: Phenolic Resin
Threaded Part: Brass (Insert)
Main Body Color: Black

Part Number		D	D ₁	H	h	L _f	d
①Type	②Thread M						
C-NLZT	6	25	16	20	9	12	8
	8	32	18	26	13	20	9
	10	40	22	29	14	25	11
	12	50	29	32	15		15

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ②.

Part Number (①Type · ②M)
C-NLZT6

How to search on website



By Type: Search on MISUMI official website
C-NLZT

By Keyword: Step 1 Search on MISUMI official website
heptagonal knob

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





Representative model: C-NLZTM6-15

Save Up to **53%** vs Standard Type

29

THB



Volume Discount



Quantity	1~29	30~49	50~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body Material	Material	Thread Surface Treatment
C-NLZTM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NLZTF	Tapped Type		Brass	-

C-NLZTM (Threaded Type)

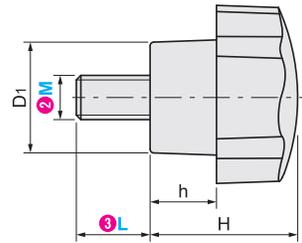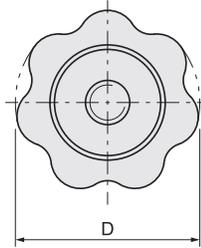

C-NLZTF (Tapped Type)

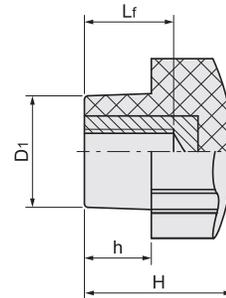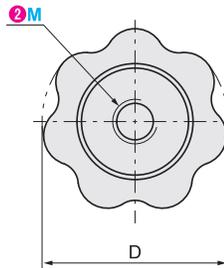

Threaded Type

Part Number		Length L Selection		D	D1	H	h
1 Type	2 Thread M	3					
C-NLZTM	6	10	15	25	15	20	9
	8	10	15	32	18	26	13
	10	15	20	40	22	28	14

Tapped Type

Part Number		Lr	D	D1	H	h
1 Type	2 Thread M					
C-NLZTF	6	12	25	15	20	9
	8	16	32	18	26	13
	10	18	40	22	28	14
	12	25	50	29	32	15



Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type · 2 M) - 3 L
C-NLZTM6 - 15

How to search on website



By Type: Search on MISUMI official website
C-NLZTM

By Keyword: Step 1 Search on MISUMI official website
star knob

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-NBJF10

Save Up to **59%** vs Standard Type

54

THB

Shipping from **1 day**



Volume Discount



Quantity	4~29	30~49	50~
Discount	Unit Price	15%	30%





Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Type	Threaded Part	Body		Thread
		Material	Material	Surface Treatment
C-NBJM	Threaded Type	Phenolic	Steel(Q235)	White Zinc Plating
C-NBJF	Tapped Type		Brass	-

C-NBJM (Threaded Type)

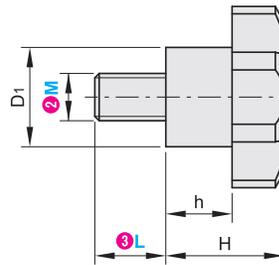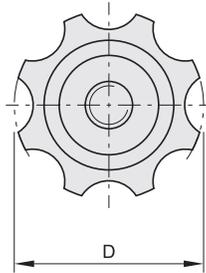

C-NBJF (Tapped Type)

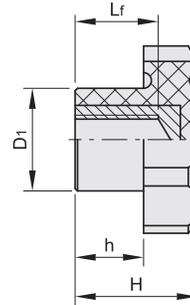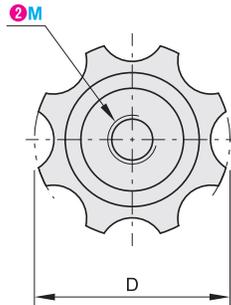

■ Threaded Type

Part Number		③ Length L Selection	D	H	D1	h
① Type	② Thread M					
C-NBJM	10	15 25	40	25	21	14
	12	15 25	50		25	

■ Tapped Type

Part Number		Lf	D	H	D1	h
① Type	② Thread M					
C-NBJF	10	17	40	25	21	14
	12	21	50		25	

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type · ②M) - ③L
C-NBJM10 - 15

How to search on website



By Type Search on MISUMI official website
C-NBJM

By Keyword Step 1 ▶ Search on MISUMI official website
octagonal knob

Step 2 ▶ Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Economy series Linear Slide Rails

Smooth sliding and durable
New product with tap for easy installation



vs Standard Type

Saving up to

31%



Durability Test

MISUMI Economy series linear slide rail is stamped with high-quality self-made mold, and the assembly accuracy of finished products is guaranteed. After 50,000 cycles of reciprocating movement with load, it can still be used normally in smooth sliding without deformation in appearance.



Test Conditions: Install the sample correctly on the durability tester, load 24.5KG in the drawer, make continuous pushing and pulling movement with a speed of 12 cycles/minute, observe the change of the sample and record the state of the product when the corresponding number of cycles is reached.

Number of cycles	Sliding resistance	Sag when fully extended
10000	0.8KG	1mm
20000*	0.8KG	1mm
30000	0.7KG	1mm
40000	0.7KG	1.2mm
50000	0.7KG	1.2mm

* With opening and closing every ten minutes, 20000 cycles is about equal to the number of uses in a year.

* The test data are obtained through testing by our company, which are for reference only

Salt Spray Test

MISUMI Economy series linear slide rail (steel) ensures 24 hours salt spray test without rusting and excellent rust prevention performance.




Test time (H)	Generic products on the market *	MISUMI Economy series
24	Black spots appear in one place	Normal
48	10% black spots at the inner rail	2% black spots at the inner rail
72	Large area of rust at the outer rail	3% black spots at the outer rail
96	Large area of red rust inside the slide rail with steel ball rusted	Black spots inside the slide rail with steel ball rusted

* Generic products on the market are similar products randomly purchased by our company from online or offline markets


* The test data are obtained through testing by our company, which are for reference only

Installation Precautions

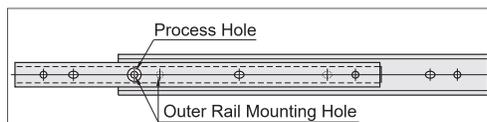


When installing the interference part between the slide rail and the mounting hole, please move the process hole to a position above the mounting hole before installing the screws.

Sectional View of Normal Type
Accessories Required:
Screw + Nut

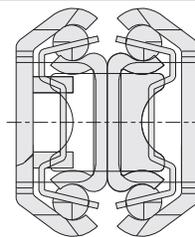


Sectional View with Tap
Accessories Required:
Screw

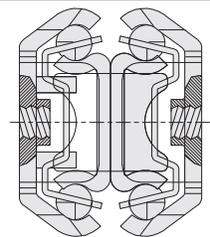


Precautions for use

Example of installation direction

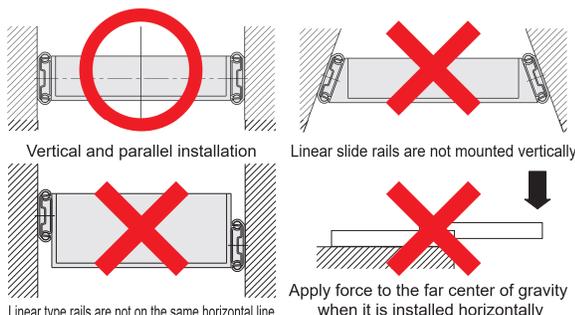


* It is recommended not to use it when torque loads are withstood

Linear slide rail when ball creep occurs

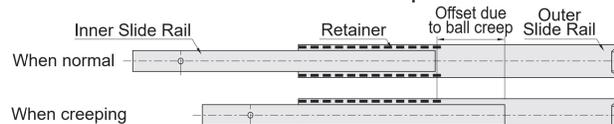

Because of the offset, the retainer has reached the left end of the outer slide rail, but it is not in the full stroke state.

In order to eliminate the ball creep phenomenon, please apply force to make the inner slide rail slide to the full stroke state.

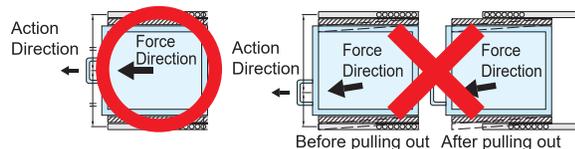

Before pulling out After pulling out

Slide Rails Two Step Slide Light Load Type (Width:20mm, Steel)

Representative model: C-SRY20300



436

THB




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



⚠ Shipping days may differ by Quantity.
⚠ Quantity of volume discount above is for representative Part No. It may differ by the Part.

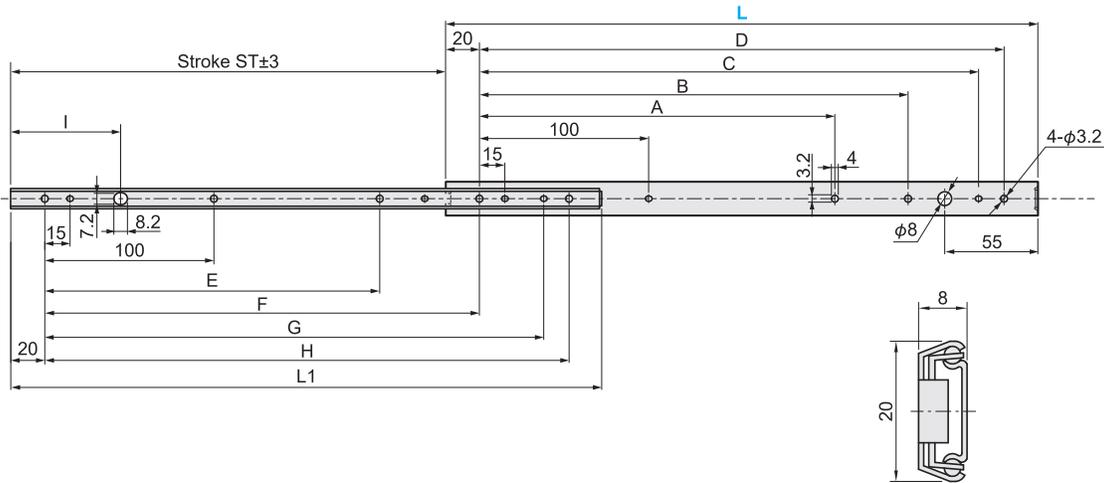

Material: Steel(Q235)
Surface Treatment: Zinc Plating

Part Number		Stroke ST	L1	A	B	C	D	E	F	G	H	I	Rated Load (N/2 pcs)			
Type	Rail Length L															
C-SRY20	200	132	198.5	-	-	145	160	-	-	145	160	55	127			
	250	182	248.5			195	210		150	195	210		147			
	300	220	298.5	-	160	245	260	-	190	245	260	140	157			
	350	257	348.5						210	295	310		225	295	310	147
	400	294	398.5						260	345	360		265	345	360	127
	450	331	448.5	205	310	395	410	190	300	395	410	140	105			
	500	381	498.5	230	360	445	460	225	337	445	460					

⚠ Use M3 round head screws or small clamping screws for mounting slide rails.
⚠ When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SRY20300

How to search on website



By Type Search on MISUMI official website

 
By Keyword Step 1 Search on MISUMI official website

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRY20300



862

THB




Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

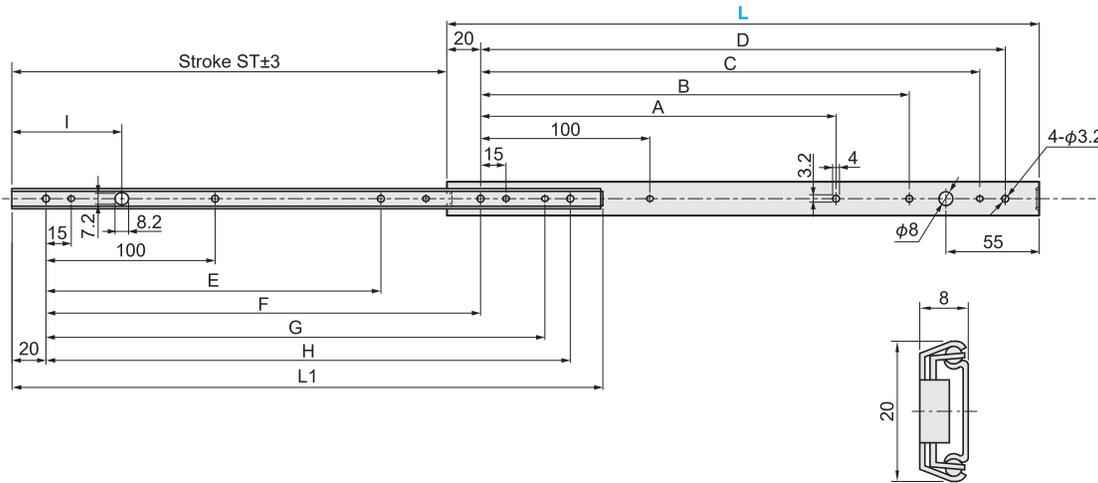

Material: SUS304

Part Number		Stroke ST	L1	A	B	C	D	E	F	G	H	I	Rated Load (N/2 pcs)						
Type	Rail Length L																		
C-SSRY20	200	132	198.5	-	-	145	160	-	-	145	160	55	127						
	250	182	248.5			195	210		150	195	210		147						
	300	220	298.5			160	245		260	190	245		260	157					
	350	257	348.5	205	310	395	410	190	300	395	410	140	147						
	400	294	398.5										210	295	310	225	295	310	127
	450	331	448.5										260	345	360	265	345	360	105
	500	381	498.5										230	360	445	460	225	337	445

Use M3 round head screws or small clamping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SSRY20300



By Type Search on MISUMI official website
C-SSRY20

 
By Keyword Step 1 Search on MISUMI official website
slide rail 2 step

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SRYM20300



453

THB




Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

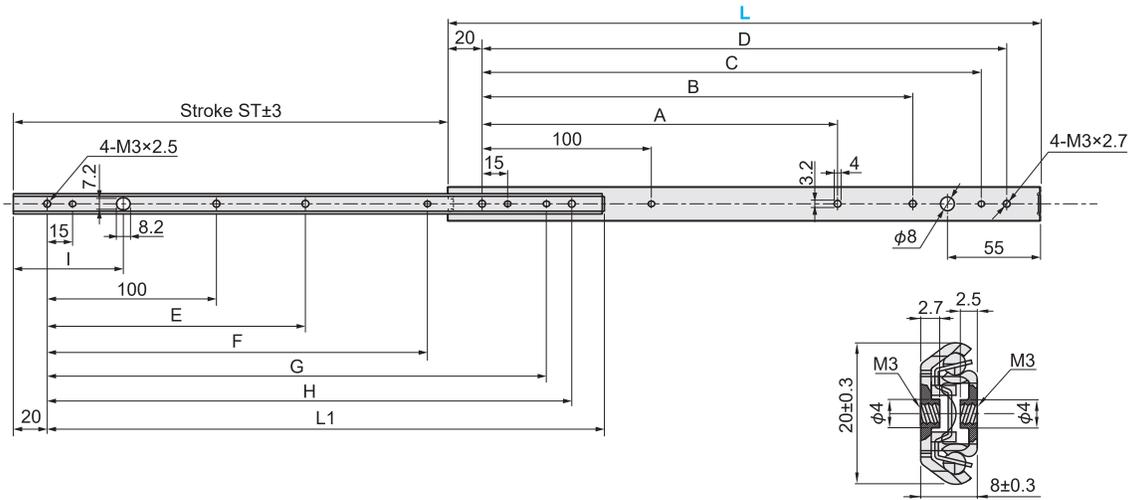

Material: Steel(Q235)
Surface Treatment: Zinc Plating

Part Number		Stroke ST	L1	A	B	C	D	E	F	G	H	I	Rated Load (N/2 pcs)								
Type	Rail Length L																				
C-SRYM20	200	132	198.5	-	-	145	160	-	-	145	160	55	127								
	250	182	248.5			195	210		150	195	210		147								
	300	220	298.5			160	245		260	190	245		260	157							
	350	257	348.5	205	310	395	410	190	300	395	410	140	147								
	400	294	398.5										260	345	360	265	345	360			
	450	331	448.5										230	360	445	460	225	337	445	460	127
	500	381	498.5										230	360	445	460	225	337	445	460	105

Use M3 round head screws or small clamping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SRYM20300



By Type: Search on MISUMI official website

By Keyword: Step 1 Search on MISUMI official website

Step 2 Select MISUMI economy series brand
 MISUMI **MISUMI economy**

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRYM20300



880

THB




Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



⚠ Shipping days may differ by Quantity.
⚠ Quantity of volume discount above is for representative Part No. It may differ by the Part.

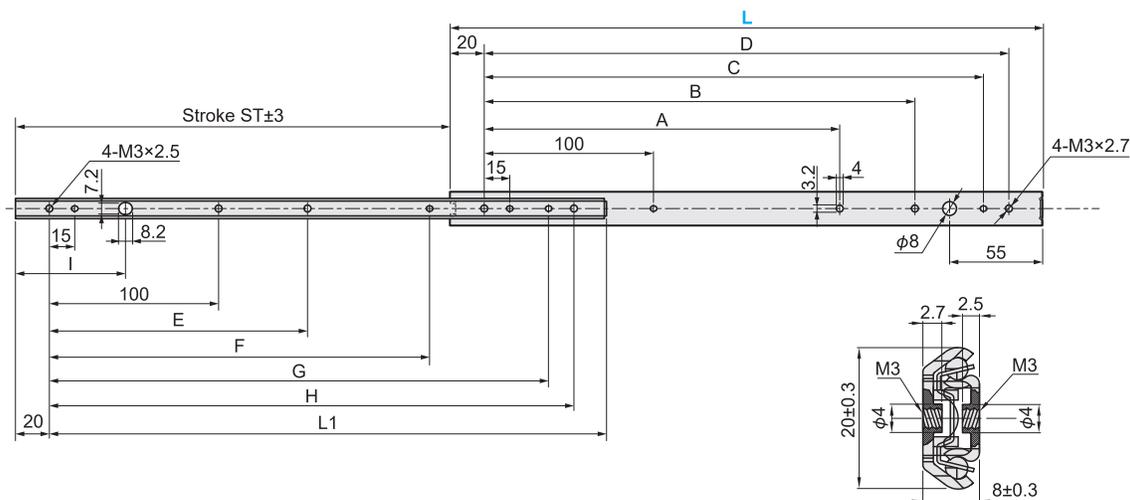

Material: SUS304

Part Number		Stroke ST	L1	A	B	C	D	E	F	G	H	I	Rated Load (N/2 pcs)
Type	Rail Length L												
C-SSRYM20	200	132	198.5	-	-	145	160	-	-	145	160	55	127
	250	182	248.5			195	210		150	195	210		147
	300	220	298.5			160	245		260	190	245		260
	350	257	348.5	205	310	395	410	190	300	395	410	140	147
	400	294	398.5										260
	450	331	448.5	230	360	445	460	225	337	445	460	105	
	500	381	498.5										

⚠ Use M3 round head screws or small clamping screws for mounting slide rails.
⚠ When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SSRYM20300

How to search on website



By Type Search on MISUMI official website
C-SSRYM20

By Keyword Step 1 Search on MISUMI official website
slide rail 2 step

Step 2 Select MISUMI economy series brand
 MISUMI **MISUMI economy**

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Slide Rails Three Step Slide Light load Type (Width:20mm, Steel)

Representative model: C-SRXY20300



641

THB





Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

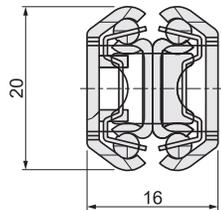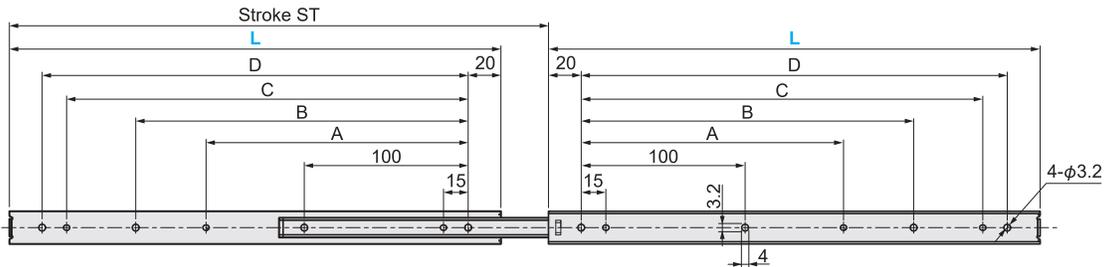

Material: Steel(Q235)
Surface Treatment: Zinc Plating

Part Number		Stroke ST	A	B	C	D	Rated Load (N/2 pcs)
Type	Rail Length L						
C-SRXY20	200	231	-	160	145	160	167
	250	280			195	210	186
	300	329			245	260	196
	350	379	210	295	310	181	
	400	428	260	345	360		
	450	477	205	310	395	410	157
	500	526	230	360	445	460	127

Use M3 round head screws or small clamping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SRXY20300

How to search on website



By Type: Search on MISUMI official website
C-SRXY20

By Keyword: Step 1 ▶ Search on MISUMI official website
slide rail 3 step

Step 2 ▶ Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRXY20300



1,123 THB




Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

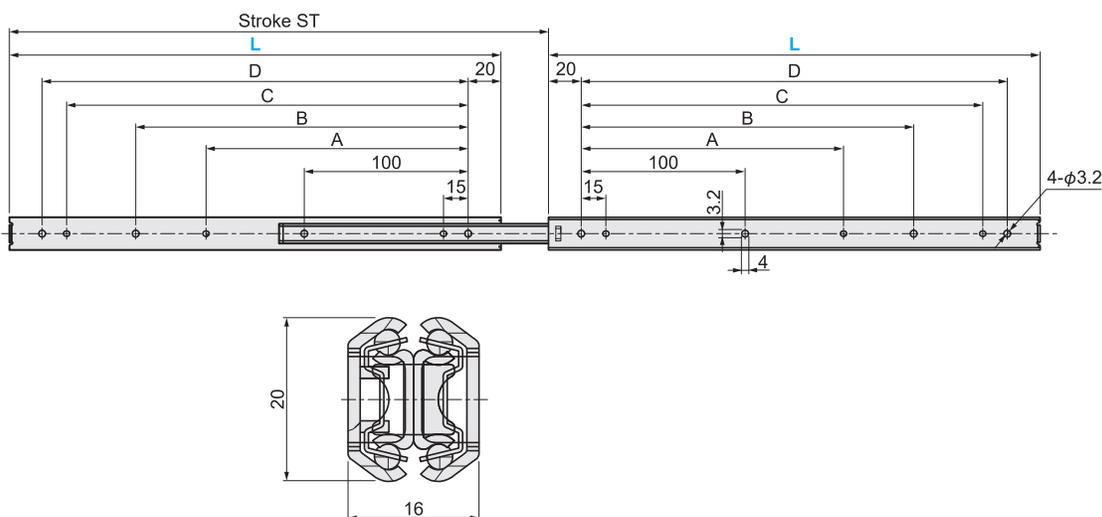

Material: SUS304

Part Number Type	Rail Length L	Stroke ST	A	B	C	D	Rated Load (N/2 pcs)
	250	280	-	-	195	210	
	300	329	-	160	245	260	
	350	379	-	210	295	310	
	400	428	205	260	345	360	157
	450	477	230	310	395	410	
	500	526	230	360	445	460	

Use M3 round head screws or small clamping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SSRXY20300

How to search on website



By Type Search on MISUMI official website
C-SSRXY20

By Keyword Step 1 Search on MISUMI official website
slide rail 3 step

 
Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Slide Rails Three Step Slide Light load Type (Width:20mm, Steel) With Tap

Representative model: C-SRXYM20300



659

THB




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



⚠ Shipping days may differ by Quantity.
⚠ Quantity of volume discount above is for representative Part No. It may differ by the Part.

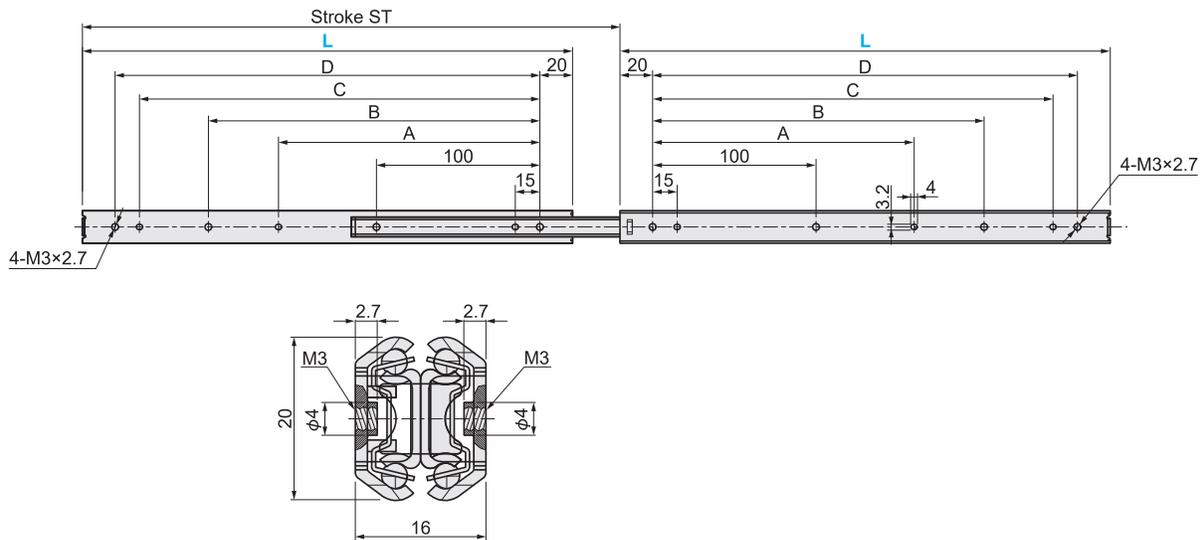

Material: Steel(Q235)
Surface Treatment: Zinc Plating

⚠ The cross-sectional shapes may be slightly different due to the production batch.

Part Number		Stroke ST	A	B	C	D	Rated Load (N/2 pcs)	
Type	Rail Length L							
C-SRXYM20	200	231	-	-	145	160	167	
	250	280			195	210		
	300	329			160	245		260
	350	379	205	310	210	295	310	157
	400	428			260	345	360	
	450	477	230	360	395	410	410	127
	500	526			445	460	460	

⚠ Use M3 round head screws or small clamping screws for mounting slide rails.

⚠ When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SRXYM20300



By Type Search on MISUMI official website
C-SRXYM20

By Keyword Step 1 Search on MISUMI official website
slide rail 3 step

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRXYM20300



1,141 THB




Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

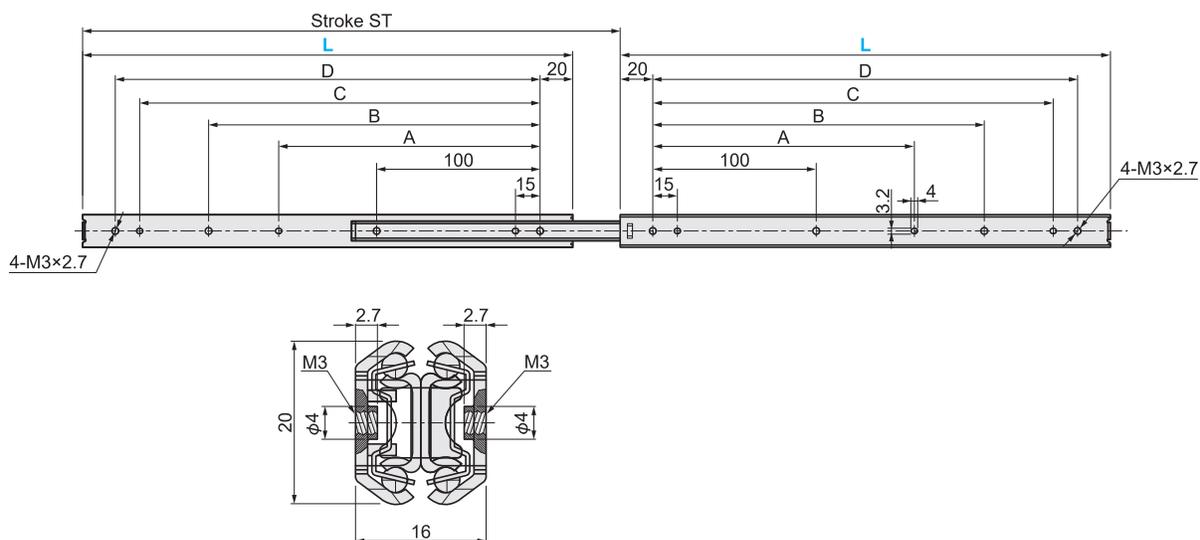

Material: Steel(Q235)
Surface Treatment: Zinc Plating

The cross-sectional shapes may be slightly different due to the production batch.

Part Number		Stroke ST	A	B	C	D	Rated Load (N/2 pcs)	
Type	Rail Length L							
C-SSRXYM20	200	231	-	-	145	160	167	
	250	280			195	210		
	300	329			160	245		260
	350	379	205	310	210	295	310	157
	400	428			260	345	360	
	450	477			395	410	410	
	500	526	230	360	445	460	127	

Use M3 round head screws or small clamping screws for mounting slide rails.

When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SSRXYM20300

How to search on website



By Type Search on MISUMI official website
C-SSRXYM20

By Keyword Step 1 Search on MISUMI official website
slide rail 3 step

Step 2 Select MISUMI economy series brand
MiSUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Slide Rails Two Step Slide Light load Type (Width:27mm, Steel)

Representative model: C-SRY27200

Save Up to **30%** vs Standard Type

206

THB




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Pull-out: Unavailable

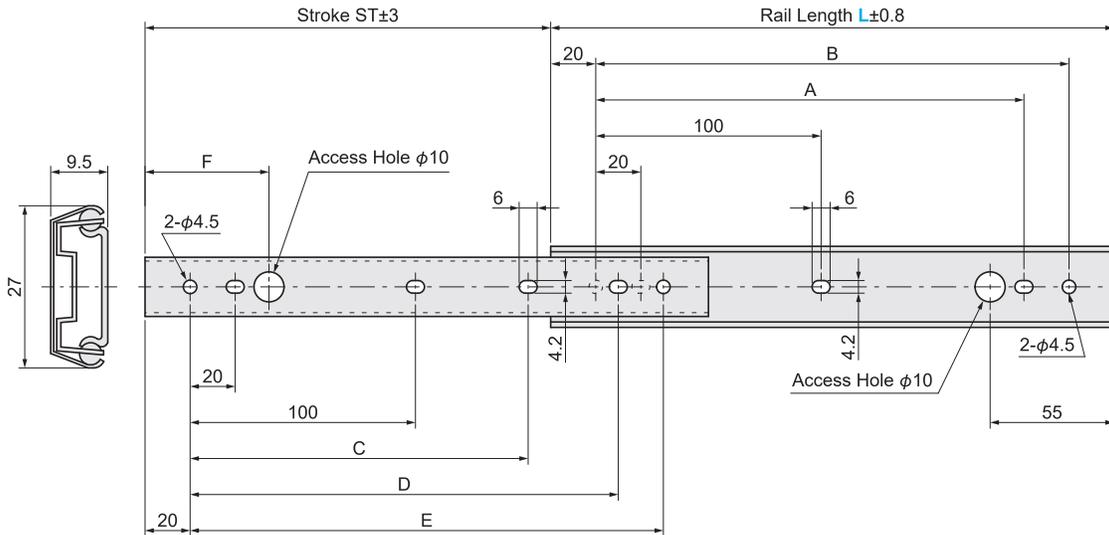

The cross-sectional shapes may be slightly different due to the production batch.

Material: Steel(Q235)
Surface Treatment: Zinc Plating

Part Number		Stroke ST	A	B	C	D	E	F	Rated Load (N/2 pcs)
Type	Rail Length L								
C-SRY27	200	135	140	160	-	140	160	62.5	234
	250	185	190	210	150	190	210		216
	300	222	240	260	190	240	260		207
	350	260	290	310	225	290	310		189
	400	297	340	360	265	340	360	180	
	450	334	390	410	300	390	410	142.5	162
	500	371	440	460	337	440	460		153

Use M4 round head screws or small clamping screws for mounting slide rails.

When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SRY27200

How to search on website



By Type Search on MISUMI official website
C-SRY27

By Keyword Step 1 Search on MISUMI official website
slide rail 2 step

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRY27Y18

Save Up to **30%** vs Standard Type

Shipping from 1 day

420 THB




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Pull-out: Unavailable

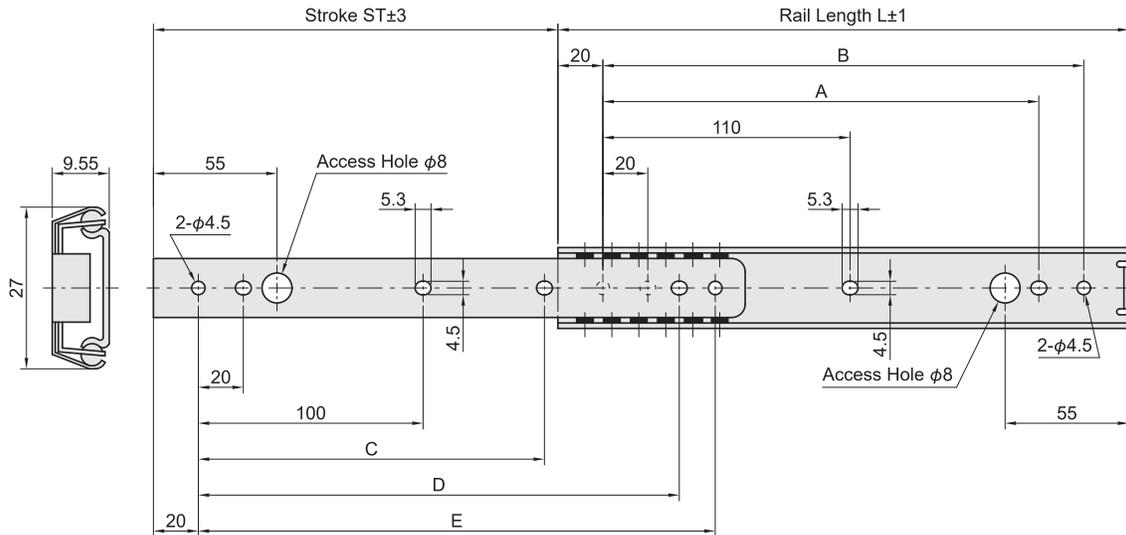

The cross-sectional shapes may be slightly different due to the production batch.

Material: Slide Rail: SUS304
Ball: SUS440C

Part Number		Rail Length L	Stroke ST	A	B	C	D	E	Rated Load (N/2 pcs)
Type	Inch Length Mark								
C-SSRY27	Y08	203.2	136.1	143.2	163.2	-	143.2	163.2	230
	Y10	254.0	186.9	194.0	214.0	154.0	194.0	214.0	221
	Y12	304.8	225.0	244.8	264.8	194.8	244.8	264.8	212
	Y14	355.6	263.1	295.6	315.6	230.6	295.6	315.6	203
	Y16	406.4	301.2	346.0	366.4	271.4	346.4	366.4	185
	Y18	457.2	339.3	397.2	417.2	307.2	397.2	417.2	176
	Y20	508.0	377.4	448.0	468.0	345.0	448.0	468.0	158

Use M4 round head screws or small clamping screws for mounting slide rails.

When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · Inch Length Mark)
C-SSRY27Y18

How to search on website



By Type Search on MISUMI official website
C-SSRY27

By Keyword Step 1 Search on MISUMI official website
slide rail 2 step

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Slide Rails Three Step Slide Light load Type (Width:27mm, Steel)

Representative model: C-SRXY27200

Save Up to **31%** vs Standard Type

430

THB

Shipping from **1 day**




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

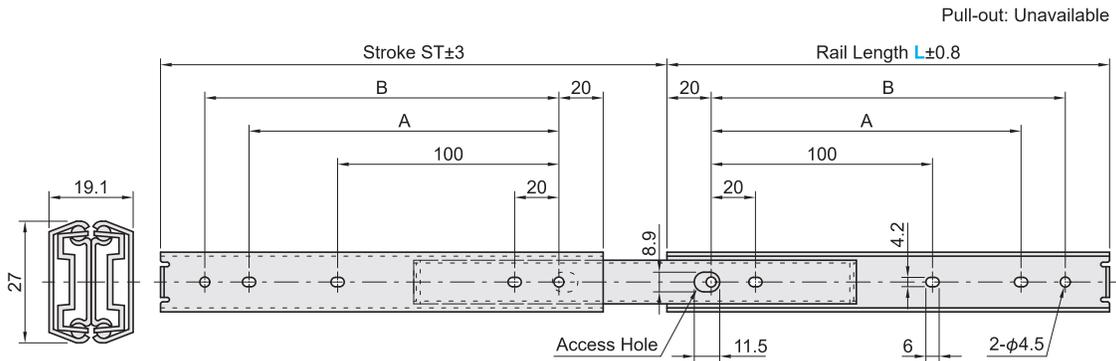

Pull-out: Unavailable

The cross-sectional shapes may be slightly different due to the production batch.

Material: Steel(Q235)
Surface Treatment: Zinc Plating

Part Number		Stroke ST	A	B	Rated Load (N/2 pcs)
Type	Rail Length L				
C-SRXY27	200	228.8	140	160	336
	250	276.2	190	210	327
	300	327.2	240	260	318
	350	376.4	290	310	300
	400	425.6	340	360	283
	450	474.8	390	410	265
	500	524.0	440	460	248

Use M4 round head screws or small clamping screws for mounting slide rails.

When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · L)
C-SRXY27200

How to search on website



By Type Search on MISUMI official website
C-SRXY27

By Keyword Step 1 Search on MISUMI official website
slide rail 3 step

Step 2 Select MISUMI economy series brand

MISUMI **MISUMI economy**

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRXY27Y16

Save Up to **30%** vs Standard Type

Shipping from 1 day



920 THB



Volume Discount

Quantity	2~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Pull-out: Unavailable

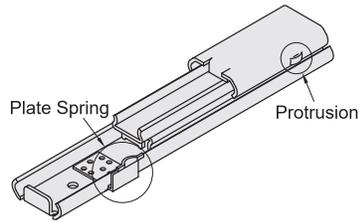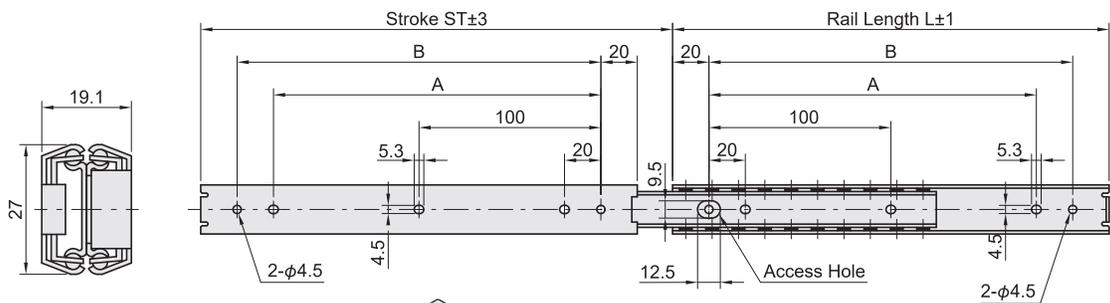

- Normally closed state holding type
- Applying force of more than 2kg/pc (reference value) in the pull-out direction can release holding.
- When storing the rails, allow the protrusions to hook the plate spring so that the slide rail may be kept in the pull-out direction. Prevent the pull-out part from opening due to vibration, etc.
- When using linear type slide rails in a vertical or inclined state, install a mechanism externally to prevent the rails from falling off.

Material: Slide Rail: SUS304
Ball: SUS440C

The cross-sectional shapes may be slightly different due to the production batch.

Part Number	Rail Length L	Stroke ST	A	B	Rated Load (N/2 pcs)
C-SSRXY27 (Without Open-Close Retention)	Y08	203.2	225.2	143.2	336
	Y10	254.0	276.0	194.0	327
	Y12	304.8	326.8	244.8	318
	Y14	355.6	377.6	295.6	300
C-SSRXC27 (With Open-Close Retention)	Y16	406.4	428.4	346.4	283
	Y18	457.2	479.2	397.2	265
	Y20	508.0	530.0	448.0	248

Use M4 round head screws or small clamping screws for mounting slide rails.

When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · Inch Length Mark)
C-SSRXY27Y16

How to search on website



By Type Search on MISUMI official website
C-SSRXY27

By Keyword Step 1 Search on MISUMI official website
slide rail 3 step

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Slide Rails Two Step Slide Medium Load Type (Width:36mm, Steel)

Representative model: C-SR36Y28

Save Up to **30%** vs Standard Type

408 THB

Shipping from 1 day




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

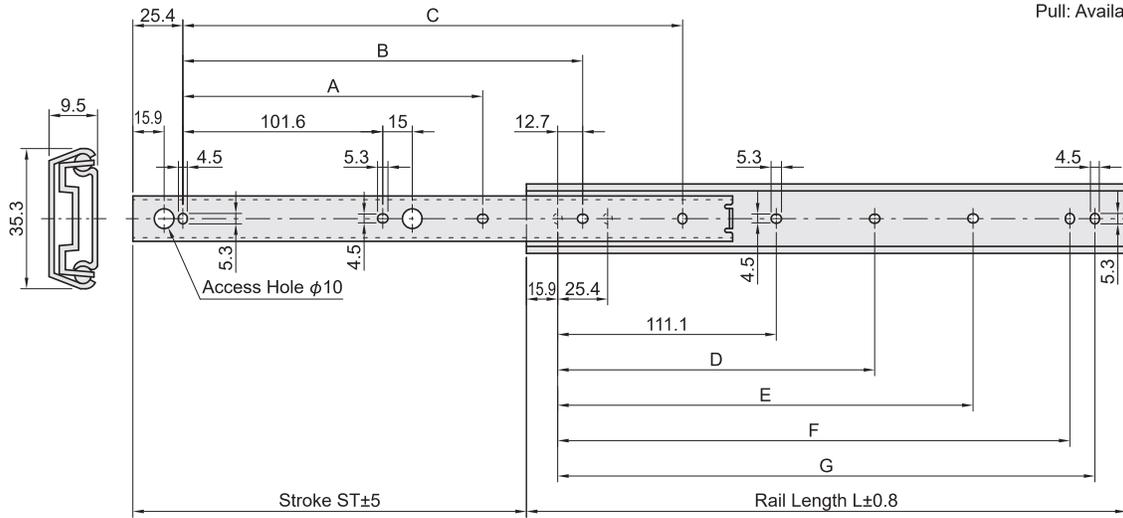

Pull: Available

The inner and outer slide rails cannot be exchanged.
The cross-sectional shapes may be slightly different due to the production batch.

Material: Steel(Q235)
Surface Treatment: Zinc Plating

Part Number		Rail Length L	Stroke ST	A	B	C	D	E	F	G	Rated Load (N/2 pcs)
Type	Inch Length Mark										
C-SR36	Y12	304.8	228.6	-	152.4	254	-	149.2	260.3	273.0	355
	Y14	355.6	279.4		203.2	304.8		200.0	311.1	323.8	327
	Y16	406.4	304.8		254	355.6		250.8	361.9	374.6	344
	Y18	457.2	330.2	203.2	304.8	406.0	212.7	301.6	412.7	425.4	326
	Y20	508.0	381.0	228.6	355.6	457.0	238.1	352.4	463.5	476.2	291
	Y22	558.8	406.4	254.0	406.0	508.0	263.5	403.2	514.3	527.0	274
	Y24	609.6	431.8	279.4	457.2	558.8	288.9	454.0	565.1	577.8	239
	Y26	660.4	482.6	304.8	508.0	609.6	314.3	504.8	615.9	628.6	212
	Y28	711.2	508.0	330.2	558.8	660.4	339.7	555.6	666.7	679.4	203

It will stop when it reaches the limit of moving distance. If you continue to pull it forcibly, the inner and outer rails can be removed. Use M4 round head screws or small damping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · Inch Length Mark)
C-SR36Y28

How to search on website



By Type Search on MISUMI official website
C-SR36

By Keyword Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
slide rail 2 step

MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRN36Y12

Save Up to **30%** vs Standard Type

Shipping from **1 day**



336 THB


Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Pull-out: Unavailable

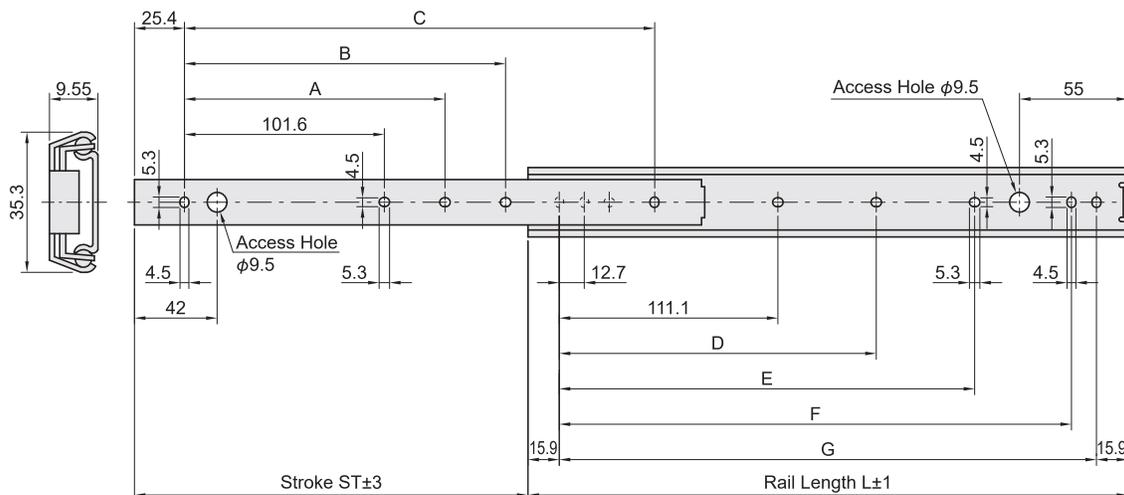

The inner and outer slide rails cannot be exchanged.
The cross-sectional shapes may be slightly different due to the production batch.

Material: Slide Rail: SUS304
Ball: SUS440C

Part Number		Rail Length L	Stroke ST	A	B	C	D	E	F	G	Rated Load (N/2 pcs)
Type	Inch Length Mark										
C-SSRN36	Y12	304.8	228.6	-	152.4	254.0	-	149.2	260.3	273.0	433
	Y14	355.6	279.4		203.2	304.8		200.0	311.1	323.8	415
	Y16	406.4	304.8		254.0	355.6		250.8	361.9	374.6	380
	Y18	457.2	330.2	203.2	304.8	406.4	212.7	301.6	412.7	425.4	362
	Y20	508.0	381.0	228.6	355.6	457.2	238.1	352.4	463.5	476.2	327
	Y22	558.8	406.4	254.0	406.4	508.0	263.5	403.2	514.3	527.0	300
	Y24	609.6	431.8	279.4	457.2	558.8	288.9	454.0	565.1	577.8	265
	Y26	660.4	482.6	304.8	508.0	609.6	314.3	504.8	615.9	628.6	239
	Y28	711.2	508.0	330.2	558.8	660.4	339.7	555.6	666.7	679.4	221

Use M4 round head screws or small clamping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · Inch Length Mark)
C-SSRN36Y12



By Type Search on MISUMI official website
C-SSRN36

By Keyword Step 1 Search on MISUMI official website
slide rail 2 step

Step 2 Select MISUMI economy series brand
MiSUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Slide Rails Three Step Slide Medium load Type (Width:36mm, Steel)

Representative model: C-SRX36Y18

Save Up to **30%**
vs Standard Type

Shipping
from
1 day

415 THB


Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Pull-out: Unavailable

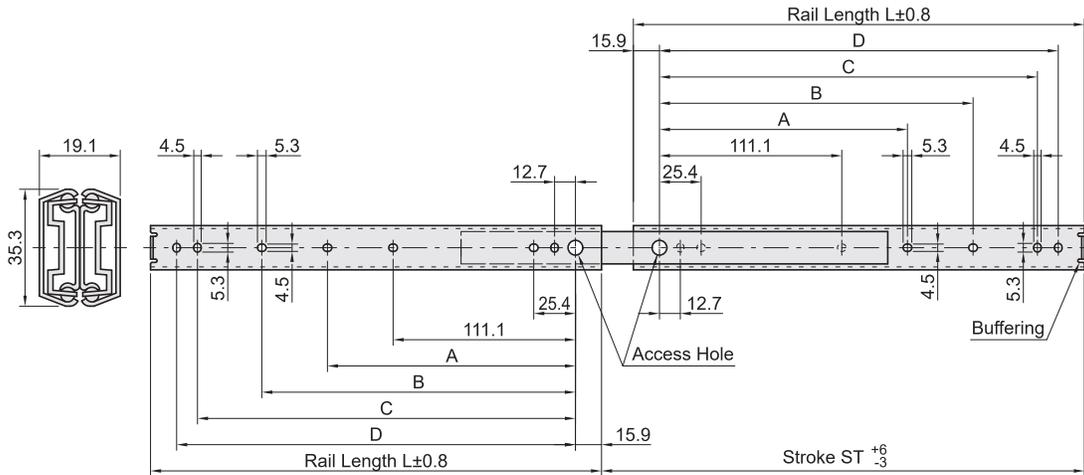

Material: Steel(Q235)
Surface Treatment: Zinc Plating

The cross-sectional shapes may be slightly different due to the production batch.

Part Number		Rail Length	Stroke	A	B	C	D	Rated Load
Type	Inch Length Mark	L	ST					(N/2 pcs)
C-SRX36	Y12	304.8	324.2	-	149.2	260.3	273.0	495
	Y14	355.6	375.4		200.0	311.1	323.8	476
	Y16	406.4	424.6		250.8	361.9	374.6	450
	Y18	457.2	475.8	212.7	301.6	412.7	425.4	415
	Y20	508.0	527.0	238.1	352.4	463.5	476.2	406
	Y22	558.8	578.2	263.5	403.2	514.3	527.0	362
	Y24	609.6	629.4	288.9	454.0	565.1	577.8	318
	Y26	660.4	678.6	314.3	504.8	615.9	628.6	300
	Y28	711.2	729.8	339.7	555.6	666.7	679.4	265

Use M4 round head screws or small clamping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · Inch Length Mark)
C-SRX36Y18



By Type Search on MISUMI official website
C-SRX36

By Keyword Step 1 Search on MISUMI official website
slide rail 3 step

Step 2 Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Representative model: C-SSRXN36Y12

Save Up to **30%** vs Standard Type

Shipping from **1 day**



721 THB


Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

Pull-out: Unavailable

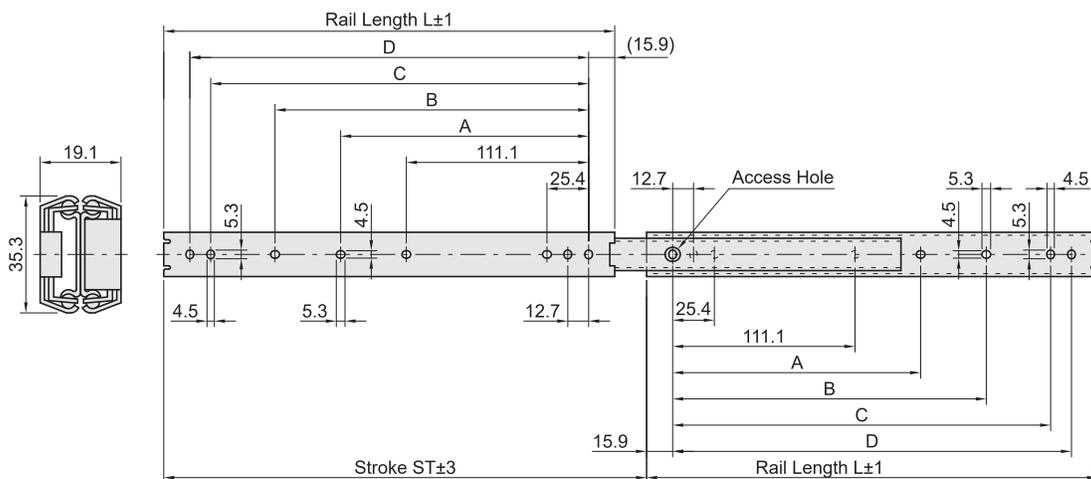

Material: Slide Rail: SUS304
Ball: SUS440C

The cross-sectional shapes may be slightly different due to the production batch.

Part Number	Rail Length	Stroke	A	B	C	D	Rated Load	
Type	Inch Length Mark	L	ST				(N/2 pcs)	
C-SSRXN36	Y12	304.8	327.2	-	149.2	260.3	273.0	529
	Y14	355.6	378.0		200.0	311.1	323.8	520
	Y16	406.4	428.4		250.8	361.9	374.6	503
	Y18	457.2	479.2	212.7	301.6	412.7	425.4	494
	Y20	508.0	530.0	238.1	352.4	463.5	476.2	476
	Y22	558.8	580.8	263.5	403.2	514.3	527.0	450
	Y24	609.6	631.6	288.9	454.0	565.1	577.8	432
	Y26	660.4	682.4	314.3	504.8	615.9	628.6	415
	Y28	711.2	733.2	339.7	555.6	666.7	679.4	397

Use M4 round head screws or small clamping screws for mounting slide rails.
When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · Inch Length Mark)
C-SSRXN36Y12

How to search on website



By Type

Search on MISUMI official website
C-SSRXN36

By Keyword

Step 1 ▶ Search on MISUMI official website
slide rail 3 step

Step 2 ▶ Select MISUMI economy series brand



MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Slide Rails Three Step Slide Heavy load Type (Width:51mm, Steel)

Representative model: C-SRH51Y12

Save Up to **30%** vs Standard Type

542

THB

Shipping from 1 day




Volume Discount

Quantity	1~3	4~5	6~
Discount	Unit Price	15%	30%



Shipping days may differ by Quantity.
Quantity of volume discount above is for representative Part No. It may differ by the Part.

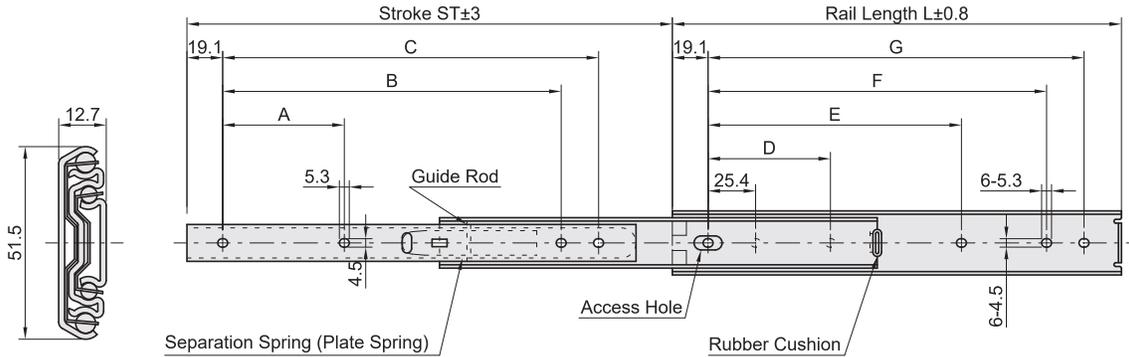

The picture above shows the Pull-out Type.

The cross-sectional shapes may be slightly different due to the production batch.

Material: Steel(Q235)

Surface Treatment: Zinc Plating

Part Number	Rail Length L	Stroke ST	Slide Unavailable Type		Slide Type		C	D	E	F	G	Rated Load (N/2 pcs)	
			A	B	A	B							
C-SRH51 (Slide Unavailable Type)	Y12	304.8	330.2	76.2	177.8	76.2	254.0	76.2	190.5	241.3	266.7	759	
	Y14	355.6	381.0	101.6	203.2	127.0	304.8	88.9	215.9	292.1	317.5	733	
	Y16	406.4	431.8	127.0	228.6	152.4	355.6	127.0	241.3	342.9	368.3	689	
	Y18	457.2	482.6	127.0	279.4	177.8	406.4	127.0	292.1	393.7	419.1	653	
C-SRRH51 (Slide Type)	Y20	508.0	533.4	152.4	304.8	152.4	457.2	152.4	317.5	444.5	469.9	635	
	Y22	558.8	584.2	177.8	330.2	177.8	469.9	508.0	342.9	495.3	520.7	617	
	Y24	609.6	635.0	177.8	381.0	177.8	520.7	558.8	393.7	546.1	571.5	591	
	Y26	660.4	685.8	203.2	406.4	203.2	571.5	609.6	203.2	419.1	596.9	622.3	565
	Y28	711.2	736.6	228.6	431.8	228.6	622.3	660.4	228.6	444.5	647.7	673.1	547

Use M4 round head screws or small clamping screws for mounting slide rails.

When it is installed horizontally, the load capacity is reduced to about 25% of the rated value (reference).

Ordering Example

Part Number (Type · Inch Length Mark)
C-SRH51Y12

How to search on website



By Type Search on MISUMI official website
C-SRH51

By Keyword Step 1 Search on MISUMI official website
slide rail 3 step

Step 2 Select MISUMI economy series brand
 MISUMI **MISUMI economy**

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Economy series LED Lighting

vs Standard Type
Saving
up to
90%

IP Assurance


Uniform Light Distribution

**Customized Brackets
for Easy Installation**



Economy series LED Lighting IP20

· Suitable for daily lighting such as electric control cabinet and work table lighting

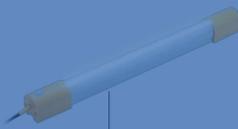

Economy series LED
Lighting IP20
With Sensing Switch



Economy series LED
Lighting IP20
Standard Type


Human body sensor **automatically lighting up**, without switch operation
lighting without glare, **and uniform illumination**

Not Available

Economy series LED Lighting IP67

Aluminum Alloy Frame Body

Better heat
dissipation provided

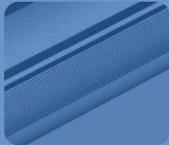


MISUMI Engraving

Genuine Logo



No strobe

 
No Ultraviolet Light-
Infrared Radiation Effect




1. Can be used in complex working environment, waterproof and dustproof, without harmful effects
2. IP assurance, with safe lighting
3. Built-in light grille to effectively prevent glare
4. Provided embedded lighting, and effectively saving space



Economy series LED
Lighting IP67
Compact Type

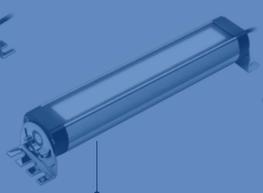

Economy series LED
Lighting IP67
Standard Type

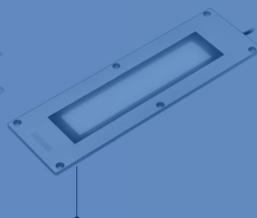

Economy series LED
Lighting IP67
Embedded Type



MISUMI Customized

Bracket, can be
applied to
a variety of
installation
environments.



Safer use

IP assurance + improved bracket fixation method

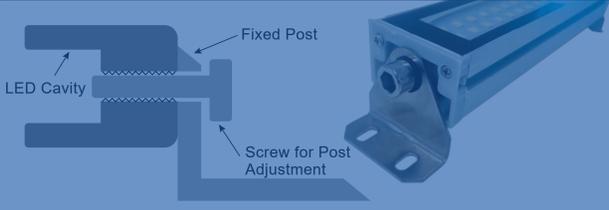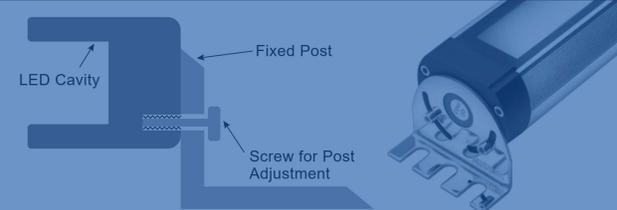	Generic products on the market *	MISUMI Economy series
Handles P.1367	The bracket fixing screws are deep inside the cavity, and in the repeated loosening and tightening of the adjustment angle, gaps are likely to appear and there is a risk of foreign matter being mixed in.	By adjusting the bracket screw fixing position, the screw will no longer penetrate into the LED cavity, so as to eliminate the risk of foreign matter mixed in, with IP assurance.
Hinges P.1383		
Magnetic Catches		

Anti Glare and No Ghosting






Significant Improvement in Light Uniformity

	Generic products on the market *	MISUMI Economy series
Locks P.1414	Lamp beads exposed, without grille 	Special light grille structure, and lamp beads unexposed 
Knobs P.1431	<p>Power on effect of generic products on the market</p> <p>There is no light grille for generic products on the market. After powering on, the LED light source presents strip distribution, and the back illuminated object has strip reflection, which affects operation judgment of workers.</p>	<p>Power on effect of MISUMI economy series</p> <p>The light grille is added in Economy series LED lighting. Light is evenly distributed after being powered on. Presenting the surface light effect, and improving the accuracy of work confirmation.</p>
Linear Slide Rails P.1448		
LED Lighting P.1466	<h1>Not Available</h1>	


* Generic products on the market are similar products randomly purchased by our company from online or offline markets.

* The test data are obtained through testing by our company, which are for reference only.


Installation Example

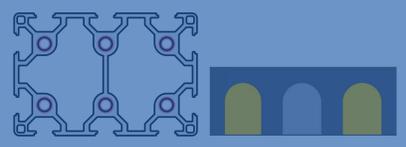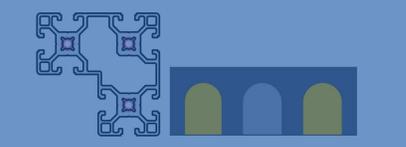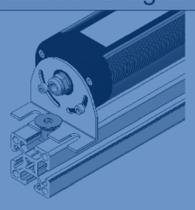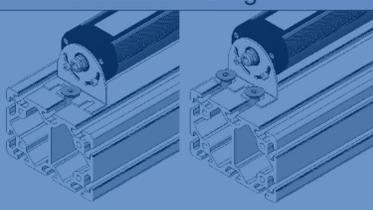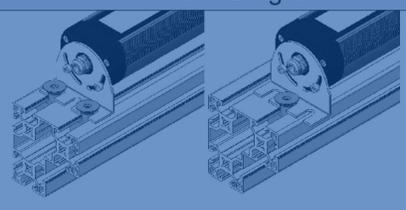	Standard Profile	Rectangle Profile	L-Type Profile, etc.
Signal Towers P.1475			
	The section of the profile is square The middle hole can be used for installation	The section of the profile is not square The hollow or two side holes can be used for installation	The section of the profile is in other shapes The hollow or two side holes can be used for installation Then adjust the light distribution angle
	Installation Diagram 	Installation Diagram 	Installation Diagram 

New Products

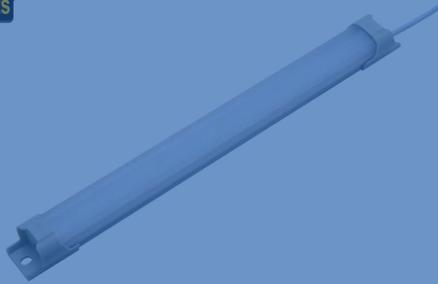

CAD 2D 3D

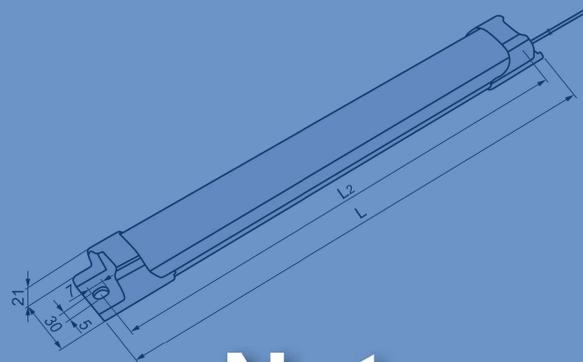

Main Body: Aluminum Alloy
Front Cover: Polycarbonate
Cable: PVC

Not Available


Part Number	Input Current (A)	Input Voltage	Total Length L	L2	Protection Rating	Power Consumption (W)	Color temperature (Kelvin K)	Light Distribution Angle	Accessories
E-LED-300	0.29A	DC 24V	300	233	IP66	7	About 6500	About 120°	Buckle×2 Self-tapping Screw×2
E-LED-500	0.5A		500	453		12			

Ordering Example

Part Number
E-LED-300



Mounting Method 1 Nut Installation

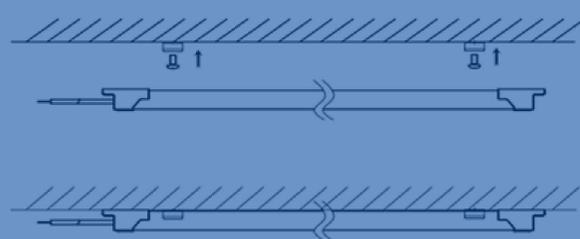

Mounting Method 2 Light Clip Installation

How to search on website



By Type

Search on MISUMI official website

E-LED-300



By Keyword

Step 1 ▶ Search on MISUMI official website

led light



Step 2 ▶ Select MISUMI economy series brand

MISUMI



MISUMI contact


Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



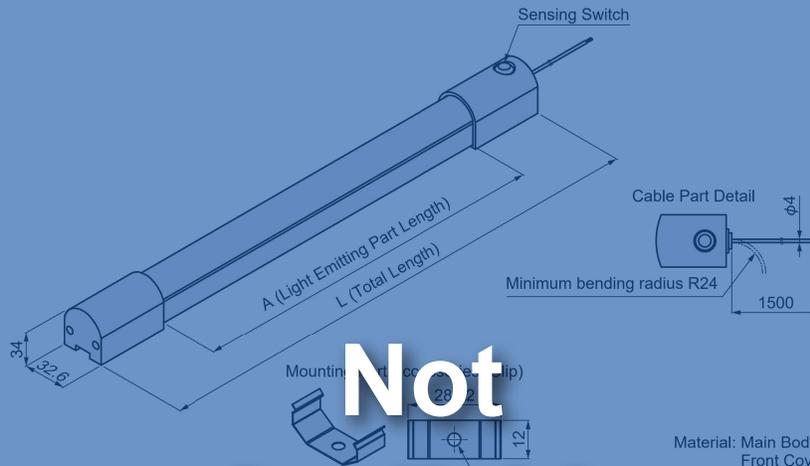

Not Available

Material: Main Body: Aluminum Alloy
 Front Cover: Polycarbonate
 Fixing Bracket: 304
 Cable: PVC
 Wire Washer: Polyolefin (Yellow)
 Surface Treatment Main Body: Clear Anodized
 Front Cover: Milky White Cover

Part Number	Power (W)	Color	L	Luminous Flux (lm)	Input Voltage (V)	Input Current (A)	Light Emitting Part Length A	Temperature Range (°C)	Color Temperature (Kelvin K)	Light Distribution Angle
1 Type	2	3								
C-LEDC	3	W (White)	385	300	DC24	0.13A	275	-10 ~ 45	About 6000	About 120°
	6		685	600		0.25A	575			
	9		985	900		0.37A	875			

* This product comes with a bayonet bracket. Please refer to the style in the size drawing. The bayonet can be mounted on the back of the light emitting part length display area.

Ordering Example

Please order after selecting part number and parameters according to the selection steps 1 to 3.

Part Number (1 Type) - Power (2) - Color (3)
 C-LEDC - 3 - W

How to search on website



By Type: Search on MISUMI official website
 C-LEDC

By Keyword: Step 1 Search on MISUMI official website
 led light

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP





*The dimension P (mounting pitch) is the distance from the washer to the next hole and cannot be used for positioning. Please be careful.
Material: Main Body: Aluminum Alloy
Front Cover: Polycarbonate
Fixing Bracket: 304
Cable: PVC
Washer: Silicon Rubber
Surface Treatment Main Body: Clear Anodized
Front Cover: Milky White Cover

Part Number ① Type	② Power (W)	③ Color	Total Length L	Mounting Pitch P	Luminous Flux (lm)	Input Voltage (V)	Input Current (A)	Light Emitting Part Length A	Temperature Range (°C)	Color Temperature (Kelvin K)	Light Distribution Angle
C-LEDZ	5	W (White)	223	215	500	DC24	0.13A	190	-10 ~ 45	About 6000	About 120°
	10		388	380	1000		0.25A	355			
	15		554	545	1500		0.37A	521			

*It is recommended to use U-shaped hole to install this product. If you use a round hole, please pay attention to the screw size.

Ordering Example Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (① Type) - ② Power - ③ Color
C-LEDZ - 5 - W

How to search on website

 

By Type: Search on MISUMI official website

By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand MISUMI MISUMI economy

MISUMI contact
Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"

Install MISUMI APP

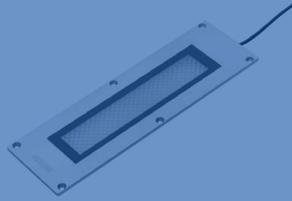

Not Available

Material Main Body: Aluminum Alloy
 Front Cover: Tempered Glass
 Waterproof Joint: 304
 Cable: PVC
 Washer: Synthetic Rubber
 Surface Treatment Main Body: Clear Anodized
 Front Cover: Matte Finish

Part Number	Power (W)	Color	Total Length L	Width W	Height H	Mounting Pitch P	Mounting Pitch Q	Mounting Pitch P1	Light Emitting Part Length A	Light Emitting Part Width B	L1	W1	H1	h
C-LEDR	10	W (White)	286	90	25	266	78	133	183	33	217	55	20	10
	12		389	80	33.5	374	65	187	301	30.6	327	52	28.5	15.5
	15		308	105	29.5	293	90	146.5	187	55	254	76	24.5	14.8

* This product is an embedded fixed product. Please confirm whether H1 height and embedded space are sufficient.

Power (W)	Luminous Flux (lm)	Input Voltage (V)	Input Current (A)	Temperature Range (°C)	Color Temperature (Kelvin K)	Light Distribution Angle
10	1000	DC24	0.43A	-10~45	About 6000	About 110°
12	1200		0.5A			
15	1500		0.62A			

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (①Type) - Power (②) - Color (③)
 C-LEDR - 10 - W

How to search on website



By Type

Search on MISUMI official website

C-LEDR

By Keyword

Step 1 ▶ Search on MISUMI official website

led light

Step 2 ▶ Select MISUMI economy series brand

MISUMI



MISUMI contact



Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



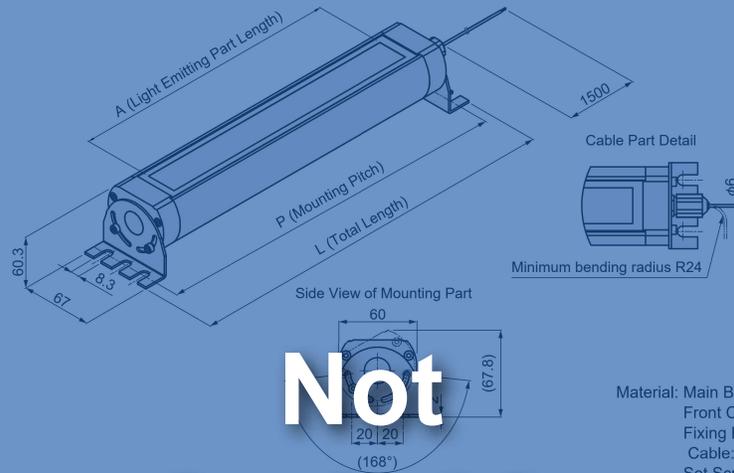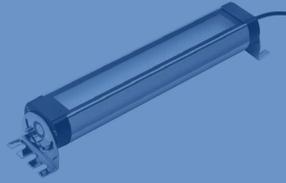

Not Available

Material: Main Body: Aluminum Alloy
 Front Cover: Tempered Glass
 Fixing Bracket: 304
 Cable: PVC
 Set Screw: 304
 Surface Treatment: Main Body: Clear Anodized
 Front Cover: Matte Finish
 Fixing Bracket: Mirror Polishing

Part Number ① Type	② Power (W)	③ Color	Total Length L	Mounting Pitch P	Luminous Flux (lm)	Input Voltage (V)	Input Current (A)	Light Emitting Part Length A	Temperature Range (°C)	Color Temperature (Kelvin K)	Light Distribution Angle
C-LEDN	9	W (White)	356	344	900	DC24	0.37A	255	-10~45	About 6000	About 110° (Light Distribution Angle Adjustable)
	13		502	490	1300		0.54A	401			
	17		560	548	1700		0.71A	459			
	20		700	688	2000		0.83A	599			
	24		805	793	2400		1.00A	704			

* It is recommended to use U-shaped hole to install this product, and multiple uniform openings can be applied to a variety of installation environments.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (① Type) - ② Power - ③ Color
 C-LEDN - 9 - W

How to search on website



By Type: Search on MISUMI official website
 C-LEDN

 
By Keyword: Step 1 Search on MISUMI official website Step 2 Select MISUMI economy series brand
 led light

MISUMI MISUMI economy

MISUMI contact


Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"




Install MISUMI APP



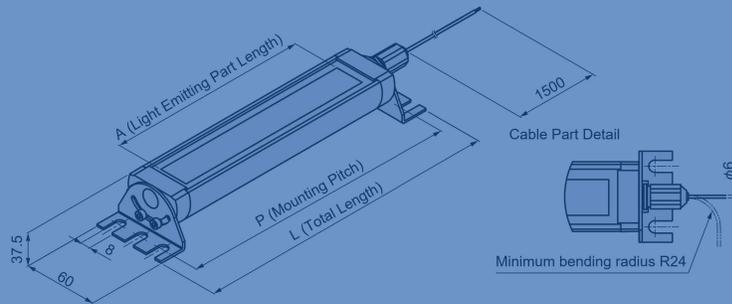

Side View of Mounting Part

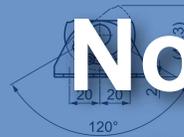

Not Available

Material: Main Body: Aluminum Alloy
 Front Cover: Tempered Glass
 Fixing Bracket: 304
 Cable: PVC
 Set Screw: 304
 Surface Treatment: Main Body: Clear Anodized
 Front Cover: Matte Finish
 Fixing Bracket: Mirror Polishing

Part Number	Power (W)	Color	Total Length L	Mounting Pitch P	Luminous Flux (lm)	Input Voltage (V)	Input Current (A)	Light Emitting Part Length A	Temperature Range (°C)	Color Temperature (Kelvin K)	Light Distribution Angle
① Type	②	③									
C-LEDT	5	W (White)	251	235	500	DC24	0.2A	166	-10~45	About 6000	About 110° (Light Distribution Angle Adjustable)
	10		337	321	1000		0.42A	252			
	12		459	443	1200		0.5A	374			
	15		549	533	1500		0.62A	464			
	18		635	619	1800		0.75A	550			

* It is recommended to use U-shaped hole to install this product, and multiple uniform openings can be applied to a variety of installation environments.

Ordering Example

Please order after selecting part number and parameters according to the selection steps ① to ③.

Part Number (① Type) - Power (②) - Color (③)
 C-LEDT - 5 - W

How to search on website



By Type: Search on MISUMI official website
 C-LEDT

 
By Keyword: Step 1 ▶ Search on MISUMI official website
 led light

Step 2 ▶ Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
 Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



Buy more Save more!

Purchase products with "Volume Discount" to save more, just simply order products up to specific quantity and instantly get special price.



Example product with volume discount

Caster With Leveling Mounts Swivel Type

Part No : C-FMJ120-N

STOCK

Quantity	Standard Unit Price
1-3	฿ 924.68
4-5	฿ 785.98
≥6	฿ 647.00




How to find volume discount product

Intouch C. Login to see volume discount information

Volume Discount Volume discount symbol

Volume discount table

จำนวน	ราคาต่อหน่วย
1 - 3	฿ 924.68
4 - 5	฿ 785.98
6 - 934	฿ 647.00
≥ 935	฿ 647.00

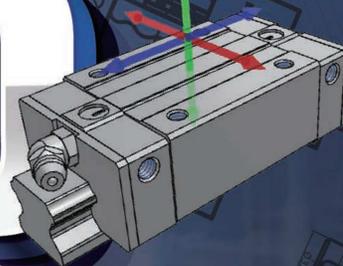

Economy series Signal Towers

New
Products



Advantage 1

Full range of specifications, suitable for a variety of installation angles



Advantage 2

Moderate luminosity, suitable for FA industries

Generic products on the market *

MISUMI Economy series

Not
Available

Advantage 3

Generic products on the market *

Electromagnetic Buzzer

Unstable decibels

MISUMI Economy series

Piezoelectric Buzzer

Stable decibels

Advantage 4

Generic products on the market *

Single-diameter mounting
holes; Multiple silicone wires,
with inconvenient wiring

MISUMI Economy series


Multiple mounting hole
diameters for side mounting;
Insulated wrap, with
convenient wiring

* Generic products on the market are similar products randomly purchased by our company from online or offline markets.

New Products



CAD 2D 3D

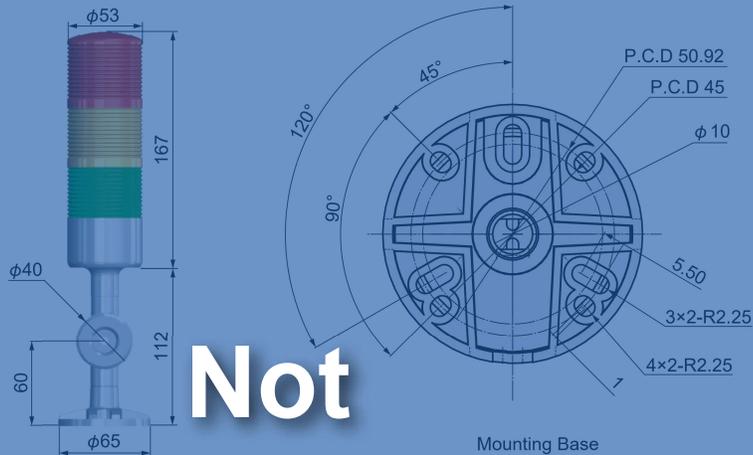

Not Available


Model	Lampshade Dia. (mm)	Rated Voltage	Number of Layers	Lampshade Color	Color (From the Top Layer)	Base Folding	Buzzer	Total Height (mm)
E-MSM280RYG-C	53	DC 24V	3	Transparent	Red · Yellow · Green	Foldable	Available	280
E-MSM280RYG-T								

Ordering Example

Model
E-MSM280RYG-C

Installation Method

Wiring Diagram

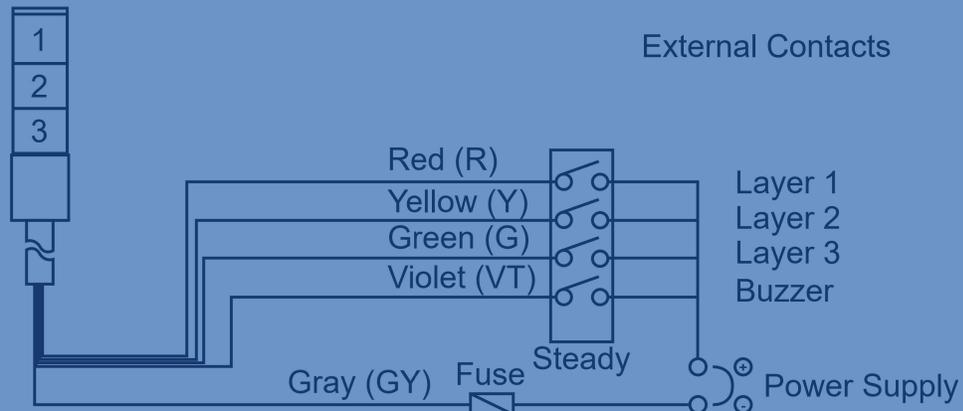

How to search on website



By Type: Search on MISUMI official website
E-MSM280RYG-C

 
By Keyword: Step 1 Search on MISUMI official website
signal tower

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP



P.1367

P.1383

P.1405

P.1414


P.1431

P.1448


P.1466

P.1475


New Products

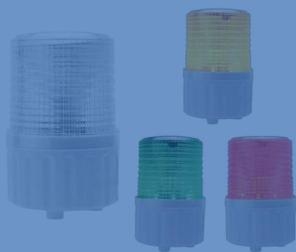

CAD 2D 3D

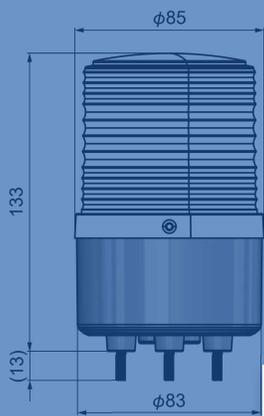

Dimensional Drawing

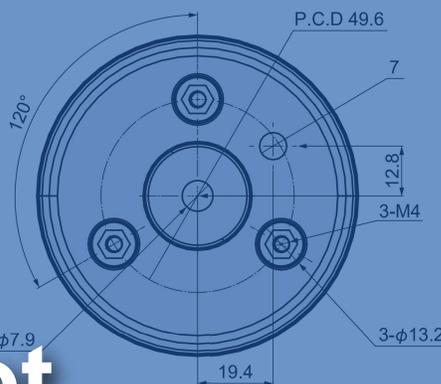

Mounting Base

Not Available


Model	Lampshade Dia. (mm)	Voltage	Number of Lights	Color	Buzzer	Total Height (mm)
E-MSM150RYG-S	φ85	DC 24V	1	Transparent	Available	135

Ordering Example

Model
E-MSM150RYG-S

Installation Method

Wiring Diagram

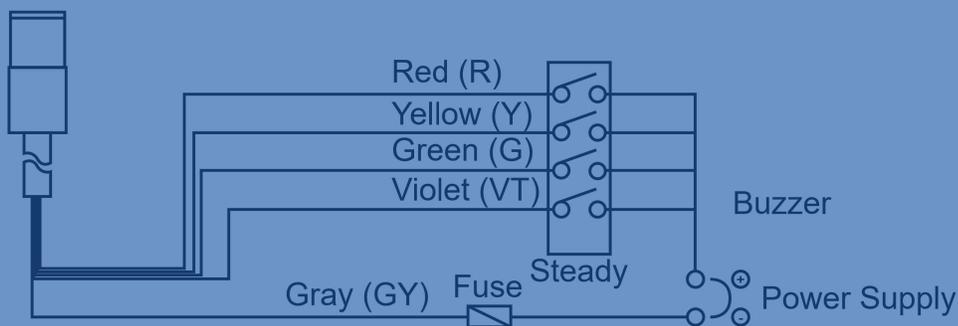

How to search on website



By Type
Search on MISUMI official website
E-MSM150RYG-S

By Keyword
Step 1 Search on MISUMI official website
signal tower

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"




Install MISUMI APP



New Products



CAD 2D 3D

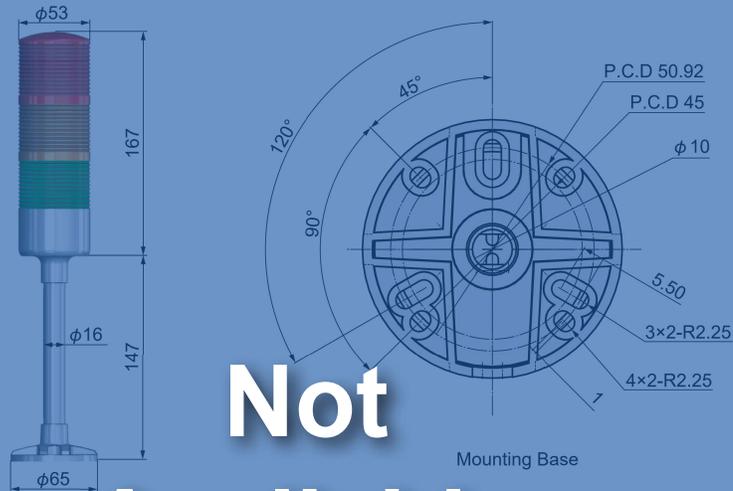

Not Available


Model	Lampshade Dia. (mm)	Rated Voltage	No. of Layers	Color	Base	Buzzer	Total Height (mm)
E-MSM320RYG-C	$\phi 53$	DC 24V	3	Red · Yellow · Green	Round Base	Available	320

Ordering Example

Model
E-MSM320RYG-C

Installation Method

Wiring Diagram

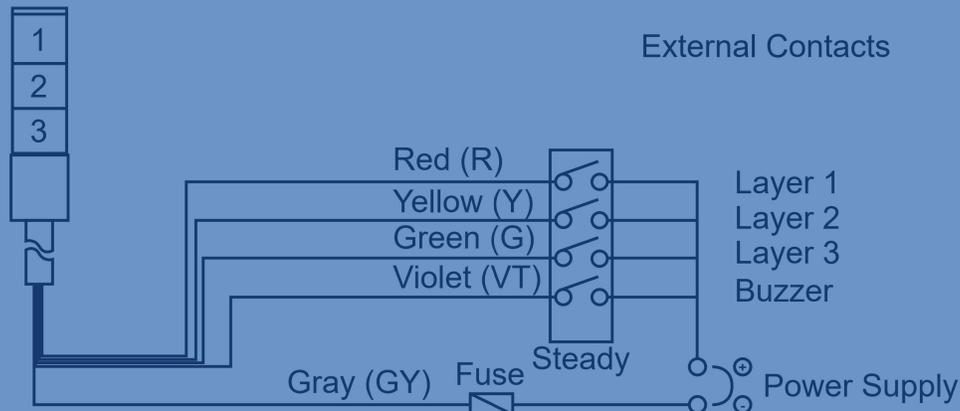

How to search on website



By Type
Search on MISUMI official website
E-MSM320RYG-C

 
By Keyword
Step 1 Search on MISUMI official website
signal tower

Step 2 Select MISUMI economy series brand
 MISUMI MISUMI economy

MISUMI contact

Tel: 038-959200 or 1382
Email: cs@misumi.co.th

MISUMI WEB "Chat"



Install MISUMI APP

