


Timing Belts (MXL, XL, L, H)

Timing Belts MXL, XL, L, H are compatible with the Timing Pulleys MLX, XL, L, H on **P.1389~P.1396.**



TBN (Rubber)
TUN (Polyurethane)

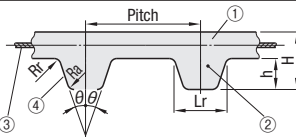

Type	Material
TBN	① Back Rubber: Chloroprene Rubber ② Tooth Rubber: Fiberglass Cord S/Z Alternately Twisted Continuous ③ Core Wire: Nylon Cloth ④ Tooth Fabric: Polyurethane
TUN	① Main Body: Polyurethane ② Core Wire: MXL: Kevlar XL, L: Steel Cord

- Operating Temp. Rubber: -30~90°C, Polyurethane: 0~80°C (Reference Value)
- Although some belt fabrics for MXL and XL rubber belts (TBN) are changed from black to brown to prevent rubber-dust generation, it does not affect the performance.
- Note: The figures of belt number have different meanings depending on its type.
- Belt No. is the number of belt teeth for MXL, and is the belt circumference length for XL, L and H.
- Belt Circumference Length is the length of Core Wire.
- TUN - Polyurethane Type - cannot be used with tension from back side.
- Features and Cautions **P.1375** How to select products, **P.2253**

Type	Pitch	2θ	Lr	h	H	Rr	Ra	Unit Mass g/m (Width: 10mm)
MXL (Rubber)	2.032	40°	1.14	0.51	1.11	0.13	0.13	11.0
MXL (Polyurethane)	2.032	60°	-	0.46	1.22	-	-	10.0
XL	5.08	50°	2.57	1.27	2.27	0.38	0.38	22.0(20.0)
L	9.525	40°	4.65	1.91	3.61	0.51	0.51	32.0(30.0)
H	12.7	40°	6.12	2.29	4.59	1.00	1.00	40.0

Type: MXL (Pitch: 2.032mm)

Type	Part Number	Belt Number	Belt Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price					
						TBN			TUN		
						019	025	037	050	025	037
TBN (Rubber)	45MXL	45	91.44								
	46MXL	46	97.54								
	50MXL	50	101.6								
	52MXL	52	105.66								
	53MXL	53	107.7								
	54MXL	54	109.73								
	55MXL	55	111.76								
	56MXL	56	113.79								
	57MXL	57	115.82								
	59MXL	59	119.89								
	60MXL	60	121.92								
	61MXL	61	123.95								
	63MXL	63	128.02								
	65MXL	65	132.08								
	67MXL	67	136.14								
	68MXL	68	138.18								
	70MXL	70	142.24								
	71MXL	71	144.27								
	72MXL	72	146.3								
	73MXL	73	148.34								
	75MXL	75	152.4								
	76MXL	76	154.43								
	77MXL	77	156.46								
	78MXL	78	158.5								
	79MXL	79	160.53								
	80MXL	80	162.56								
	82MXL	82	166.62								
	83MXL	83	168.66								
	85MXL	85	172.72								
	87MXL	87	176.78								
	88MXL	88	178.82								
	89MXL	89	180.85								
	90MXL	90	182.88								
	91MXL	91	184.91								
	92MXL	92	186.94								
	93MXL	93	188.98								
	94MXL	94	191.01								
	95MXL	95	193.04								
	96MXL	96	195.07								
	97MXL	97	197.1								
	98MXL	98	199.14								
	99MXL	99	201.17								
	100MXL	100	203.2								
	101MXL	101	205.23								
	102MXL	102	207.26								
	103MXL	103	209.3								
	104MXL	104	211.33								
	105MXL	105	213.36								
	106MXL	106	215.39								
	108MXL	108	219.46								
	110MXL	110	223.52								
	112MXL	112	227.58								
	114MXL	114	231.65								
	115MXL	115	233.68								
	118MXL	118	239.78								
	120MXL	120	243.84								
	121MXL	121	245.87								
	122MXL	122	247.9								
	123MXL	123	249.94								
	124MXL	124	251.97								
	125MXL	125	254								
	126MXL	126	256.03								
	127MXL	127	258.06								
	128MXL	128	260.1								
	129MXL	129	262.13								
	130MXL	130	264.16								
	131MXL	131	266.19								
	132MXL	132	268.22								
	134MXL	134	272.29								
	135MXL	135	274.32								
	138MXL	138	280.42								
	140MXL	140	284.48								
	142MXL	142	288.54								
	144MXL	144	292.61								
	145MXL	145	294.64								
	146MXL	146	296.67								
	148MXL	148	300.74								
	150MXL	150	304.8								
	155MXL	155	314.96								
	158MXL	158	321.06								
	160MXL	160	325.12								
	162MXL	162	329.18								

Type	Part Number	Belt Number	Belt Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price					
						TBN			TUN		
						019	025	037	050	025	037
TBN (Rubber)	165MXL	165	335.28								
	170MXL	170	345.44								
	175MXL	175	355.6								
	180MXL	180	365.76								
	184MXL	184	373.89								
	190MXL	190	386.08								
	192MXL	192	390.14								
	195MXL	195	396.24								
	200MXL	200	406.4								
	210MXL	210	426.72								
	212MXL	212	430.78								
	221MXL	221	449.07								
	222MXL	222	451.1								
	224MXL	224	455.17								
	226MXL	226	459.23								
	228MXL	228	463.3								
	230MXL	230	467.36								
	232MXL	232	471.42								
	235MXL	235	477.52								
	236MXL	236	479.55								
	239MXL	239	485.65								
	240MXL	240	487.68								
	245MXL	245	497.84								
	248MXL	248	503.94								
	249MXL	249	505.97								
	250MXL	250	508								
	256MXL	256	520.19								
	260MXL	260	528.32								
	262MXL	262	532.38								
	265MXL	265	538.48								
	273MXL	273	554.74								
	275MXL	275	558.8								
	277MXL	277	562.86								
	280MXL	280	568.96								
	281MXL	281	570.99								
	285MXL	285	579.12								
	288MXL	288	585.22								
	290MXL	290	589.28								
	295MXL	295	599.44								
	296MXL	296	601.47								
	297MXL	297	603.5								
	300MXL	300	609.6								
	305MXL	305	619.76								
	310MXL	310	629.92								
	312MXL	312	633.98								
	315MXL	315	640.08								
	318MXL	318	646.18								
	320MXL	320	650.24								
	330MXL	330	670.56								
	332MXL	332	674.62								
	334MXL	334	678.69								
	336MXL	336	682.75								
	337MXL	337	684.78								
	340MXL	340	690.88								
	347MXL	347	705.1								
	350MXL	350	711.2								
	355MXL	355	721.36								
	358MXL	358	727.46								
	359MXL	359	729.49								
	360MXL	360	731.52								
	364MXL	364	739.65								
	365MXL	365	741.68								
	370MXL	370	751.84								
	372MXL	372	755.9								
	380MXL	380	772.16								
	390MXL	390	792.48								
	397MXL	397	806.7								
	400MXL	400	812.8								
	405MXL	405	822.96								