

Toggle Clamps

- Hold Down - Horizontal Handle, Standard Handle -

Stock



Reduced
Production
Time

Stock



Reduced
Production
Time

■ Features: MC01-2B is the size between MC01-2 and MC01-3.



Ordering
Example

Part Number

MC01-1

■ Hold Down, Horizontal Handle (264N)



(Clamp Condition)




RoHS

MC01-1
MC01-S1 (Stainless Steel)

1N=0.101972kgf

*Not a bolt with rubber.

Part Number	MC01-1	MC01-S1
Body Material	SS400	SUS304
Handle	PVC (polyvinyl chloride)	
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	264	
Weight (g)	30	
Open-Close Angle of Arm	90°	
Open-Close Angle of Handle	75°	
Accessory	* Nylon Bolt Stainless Steel Bolt	
Recommended Mounting Screw	M4	

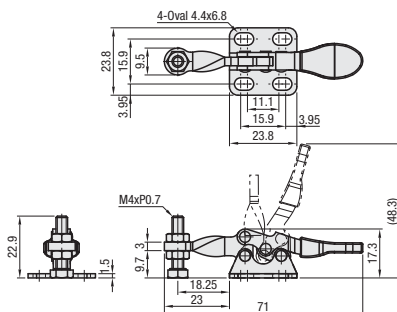

■ Hold Down, Horizontal Handle (264N)



(Clamp Condition)




RoHS

MC01-2
MC01-S2 (Stainless Steel)

*Not a bolt with rubber.

Part Number	MC01-2	MC01-S2
Body Material	SS400	SUS304
Handle	PVC (polyvinyl chloride)	
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	264	
Weight (g)	35	
Open-Close Angle of Arm	90°	
Open-Close Angle of Handle	75°	
Accessory	* Nylon Bolt Stainless Steel Bolt	
Recommended Mounting Screw	M4	

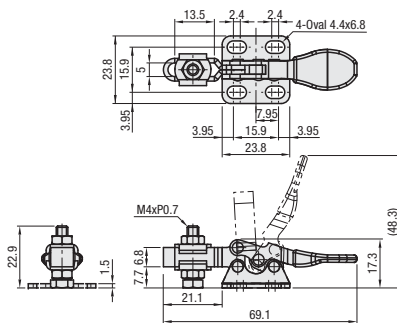

■ Hold Down, Horizontal Handle (400N)




(Clamp Condition)



RoHS

MC01-2B

Part Number	MC01-2B
Body Material	SS400
Handle	PVC (polyvinyl chloride)
Surface Treatment	Trivalent Chromate
Tightening Force (N)	400
Weight (g)	60
Open-Close Angle of Arm	90°
Open-Close Angle of Handle	75°
Accessory	Bolts with Rubber Material: NBR Hardness: Shore A70
Recommended Mounting Screw	M4

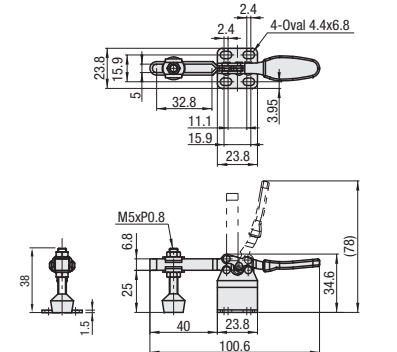

■ Hold Down, Horizontal Handle (882N)




(Clamp Condition)



RoHS

MC01-3
MC01-S3 (Stainless Steel)

Part Number	MC01-3	MC01-S3
Body Material	SS400	SUS304
Handle	PVC (polyvinyl chloride)	
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	882	
Weight (g)	130	
Open-Close Angle of Arm	85°	
Open-Close Angle of Handle	73°	
Accessory	Bolts with Rubber Material: NBR Hardness: Shore A70	
Recommended Mounting Screw	M5	

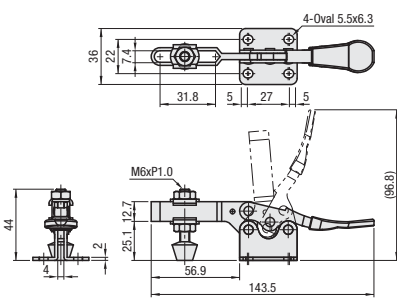

■ Hold Down, Horizontal Handle (2352N)



(Clamp Condition)



RoHS

■ Hold Down, Horizontal Handle (196N)



(Clamp Condition)



RoHS

■ Hold Down, Horizontal Handle (196N)



(Clamp Condition)



RoHS

■ Hold Down, Horizontal Handle (294N)




(Clamp Condition)




RoHS

MC01-4
MC01-S4 (Stainless Steel)

Part Number	MC01-4	MC01-S4
Body Material	SS400	SUS304
Handle	PVC (polyvinyl chloride)	
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	2352	
Weight (g)	265	
Open-Close Angle of Arm	90°	
Open-Close Angle of Handle	65°	
Accessory	Bolts with Rubber Material: NBR Hardness: Shore A70	
Recommended Mounting Screw	M6	

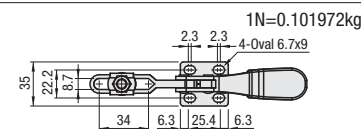


1N=0.101972kgf

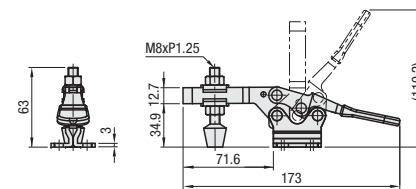


MC01-5

Part Number	MC01-5
Body Material	SS400
Handle	PVC (polyvinyl chloride)
Surface Treatment	Trivalent Chromate
Tightening Force (N)	196
Weight (g)	30
Open-Close Angle of Arm	71°
Open-Close Angle of Handle	72°
Accessory	Steel Bolt
Recommended Mounting Screw	M4

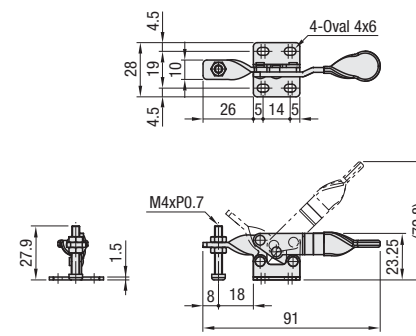


MC01-6
MC01-S6 (Stainless Steel)

Part Number	MC01-6	MC01-S6
Body Material	SS400	SUS304
Handle	PVC (polyvinyl chloride)	
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	196	
Weight (g)	30	
Open-Close Angle of Arm	75°	
Open-Close Angle of Handle	82°	
Accessory	Steel Bolt Stainless Steel Bolt	
Recommended Mounting Screw	M4	

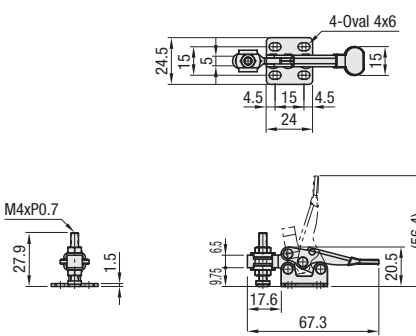

MC01-7

Part Number	MC01-7
Body Material	SS400
Handle	PVC (polyvinyl chloride)
Surface Treatment	Trivalent Chromate
Tightening Force (N)	294
Weight (g)	100
Open-Close Angle of Arm	72°
Open-Close Angle of Handle	74°
Accessory	Steel Bolt
Recommended Mounting Screw	M4

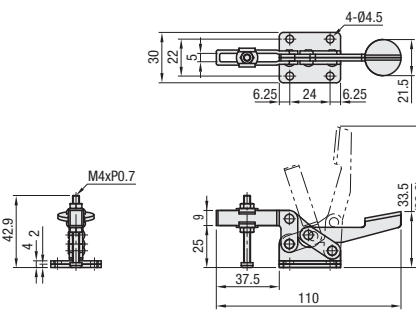

Days to Ship



Stock

☺ Stock lineup may vary by country.

☺ Same day shipping available upon request.

Order by THA: 16:00, SGP: 12:00, MYS: 15:00 P.75

Order Quantity	Standard Service	Non-Standard Service
Quantity	Regular Quantity	Large Quantity
Days to ship	1~100	101~
	Standard	To be quoted