

PCS Half Pitch Connector Included Cable

More cables of different lengths are available through the website!!

Information on Components Used

Other Components Used

When Selecting SMD*, PMD*



Cable	
Manufacturer	—
Model Number	—
Remarks	Mold Type Mini DIN Connector Cream Color Not in Catalog

When Selecting SRJ



Cable	
Manufacturer	—
Cable Model Number	NETSTAR-C5EPC
Cable Specification	AWG24 x 4P, No Shield
Connector Specification	RJ11
Remarks	Light Blue Outer Diameter 5.5 mm Not in Catalog

HDRA/HDR Connector Included Cable

Information on Components Used

Connector / Hood


HDRA / HDR



Connector	
Manufacturer	Honda Tsushin Kogyo Co., LTD.
Model Number	HDR-E**MAG1+ HDRA-E68MA+ HDRA-E100MA1+
Rated Current	HDR 0.5A HDRA 0.3A
Rated Voltage	HDR 125 VAC HDRA 30 VAC
More Information	OP.1071

Hood	
Manufacturer	Honda Tsushin Kogyo Co., LTD.
Model Number	HDR-E**LPA5 HDRA-E68LKPA HDRA-E100LPWC
More Information	OP.1071

When Selecting PP96S

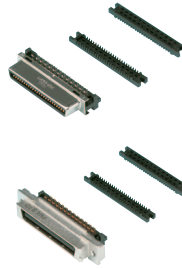

Connector	
Manufacturer	Honda Tsushin Kogyo Co., LTD.
Model Number	PCR-E96FA+
Rated Current	1A
Rated Voltage	250 VAC
More Information	OP.90

Hood	
Manufacturer	Honda Tsushin Kogyo Co., LTD.
Model Number	PCS-E96LKPA
More Information	OP.90

When Selecting PD37PB



Connector	
Manufacturer	DDK
Model Number	17JE-23370-02(D8C)-CG
Rated Current	5A
Rated Voltage	300 VAC
Remarks	With Shielding Hood Not in Catalog

Crimp Terminal



Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F0.3-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.468




Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F0.08-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.468

Multi-Core Cable

A Cable	
Manufacturer	—
Model Number	UL20276SB
Standard Acquired	UL20276
UL File No.	—
Rated Voltage	30V
Rated Temperature	80°C
Flame Retardance	VW-1
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 6
Bending Radius mm (Moving Parts)	—
Remarks	Not in Catalog

Ground Wire / Ground Terminal

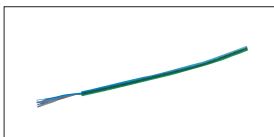

Single-Core Wire for Ground (Common for All Model Numbers)	
Model Number	UL1007-16-GN Equivalent
Standard Acquired	UL1007
Bending Radius	Finished Outer Diameter x 8
More Information	OP.1375 (Similar Specifications)



Crimp Terminal for Ground	
Model Number	RBA1.25-3.5RE Equivalent
Size	3.7mm
Outer Width	6.6mm
Rated Voltage	300V
More Information	OP.472

D-sub Connector Included Cable
MIL Socket Connector Included Cable
FCN Connector Included Cable
Connector Included Conversion/Branch Cable
Centronics Connector Included Cable
Cable with IEEE 1284 Half Pitch Connector
MR Connector Included Cable
PCR Half Pitch Connector Included Cable
PCS Half Pitch Connector Included Cable
HDRA/HDR Connector Included Cable
DX31 Half Pitch Connector Included Cable
8840 Half Pitch Connector Included Cable
Cable with Han Waterproof Connector