

RTBS-2.5TB-G-10P

2D CAD
可从网页下载

特长 通用型螺丝固定接线端子

- 侧面接线型, 2通道产品。
- 1袋10个装, 可根据不同需求自由组合。
- 材料: PA66 (UL94-V0)。
- 产品RTBS-2.5TB-*和RTBS-5TB-*的跨接件在 [▶1115页](#)。
- 适合安装于DIN导轨 ([▶1598页](#))。

发货日期	
1~10袋	次日(当日)
11袋~	另定

17:00前订购的库存品可当日发货。



折扣表	
1~9袋	标准单价
10~19袋	19% off
20袋~	24% off

Order
订货范例

型号
RTBS-3TB-G-10P

规格表

1袋起接受订购!


型号	每袋装	颜色	额定电压		额定电流			额定截面积	
			UL/CSA额定	IEC额定	UL额定	CSA额定	IEC额定	UL/CSA额定	软导线
RTBS-2.5TB-G-10P	10个	灰色	AC300V	AC690V	20A	20A	32A	AWG24~14	0.2~2.5mm ²
RTBS-3TB-G-10P									
RTBS-5TB-G-10P									
RTBS-10TB-G-10P		蓝色	AC600V	AC800V	30A	40A	41A	AWG24~10	0.2~5.5mm ²
RTBS-2.5TB-BE-10P									
RTBS-5TB-BE-10P									
RTBS-10TB-BE-10P					65A	65A	76A	AWG24~6	0.2~13.3mm ²

附件表


接线端子	接地端子 ▶1113页	盖板/隔板 ▶1114页	固定件 ▶1114页	记号板 ▶1115页	DIN导轨
RTBS-2.5TB-G-10P	RTBS-2.5TB-GY-10P	RTBS-2.5EI-G-10P	MAES-35S-10P	RTBS-5MC-10P	▶1598页
RTBS-3TB-G-10P	RTBS-3TB-GY-10P	RTBS-3EI-G-10P		RTBS-3MC-10P	
RTBS-5TB-G-10P	RTBS-5TB-GY-10P			RTBS-5MC-10P	
RTBS-10TB-G-10P	RTBS-10TB-GY-10P			RTBS-10MC-10P	
RTBS-2.5TB-BE-10P	RTBS-2.5TB-GY-10P	RTBS-2.5EI-OR-10P		RTBS-5MC-10P	
RTBS-5TB-BE-10P	RTBS-5TB-GY-10P	RTBS-3EI-OR-10P		RTBS-5MC-10P	
RTBS-10TB-BE-10P	RTBS-10TB-GY-10P		RTBS-10MC-10P		

尺寸图


(单位: mm)

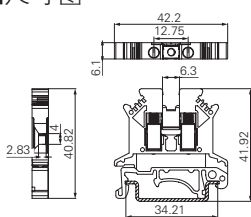


RTBS-2.5TB-* -10P

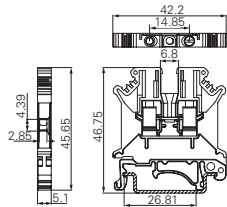

RTBS-3TB-G-10P

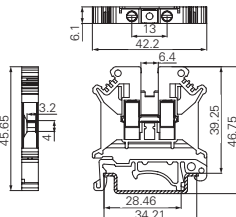

RTBS-5TB-* -10P

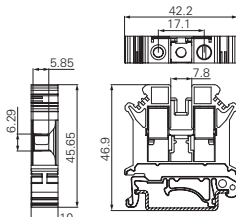

RTBS-10TB-* -10P

注: "*" 代表颜色(G、BE)