

Phillips Round Flat Head Screws / Ornamental Screws / Washers for Ornamental Screw


Phillips Binding Head Screws

Phillips Round Flat Head Screws



RoHS 10

Type	Material	Surface Treatment
MSARA	SWCH Equivalent	Trivalent Chromate
MSARAS	SUS304 Equivalent	-

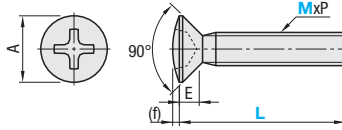

MxP (Coarse)	A	(f)	E	Phillips No.
3x0.5	6	0.7	1.75	2
4x0.7	8	0.9	2.3	2
5x0.8	10	1.2	2.8	2
6x1.0	12	1.4	3.4	3

MSARA (Trivalent Chromate)

Part Number	Unit Price	Volume Discount Rate
Type	M - L	1 ~ 29 pc(s), 30 ~ 99 pcs., 100 ~ 299 pcs., 300 ~ 500 pcs.
MSARA	3 - 5	
	6	
	8	
	10	
	12	
	4 - 6	
	8	
	10	
	12	
	15	
	5 - 8	
	10	
12		
15		
20		
6 - 10		
12		
15		
20		

MSARAS (Stainless Steel)

Part Number	Unit Price	Volume Discount Rate
Type	M - L	1 ~ 29 pc(s), 30 ~ 99 pcs., 100 ~ 299 pcs., 300 ~ 500 pcs.
MSARAS	3 - 5	
	6	
	8	
	10	
	12	
	4 - 6	
	8	
	10	
	12	
	15	
	5 - 8	
	10	
12		
15		
20		
6 - 10		
12		
15		
20		

Ordering Example
Part Number
MSARAS4-8



Ornamental Screws Washers for Ornamental Screw



RoHS 10

VIS (Brass)
VISS (Stainless Steel)

  VISZ (Brass)
VIZS (Stainless Steel)



Type	Material	Surface Treatment
VIS	C2700W	Nickel Plating
VISS	SUS304 Equivalent	-
VISZ	C2700W	Nickel Plating
VIZS	SUS303	-

M (Coarse)	P (Pitch)	D
3	0.5	6
4	0.7	8
5	0.8	10
6	1.0	12

Ornamental Screws

Part Number	Unit Price	Volume Discount Rate
Type	M-L	1 - 99 pc(s), 100 - 500 pcs.
VIS (Brass)	3-10	
	15	
	20	
	25	
	30	
	35	
	40	
	45	
	50	
	4-10	
	15	
	20	
	30	
	35	
	40	
	45	
	50	

Part Number	Unit Price	Volume Discount Rate
Type	M-L	1 - 99 pc(s), 100 - 500 pcs.
VIS (Brass)	5-10	
	15	
	20	
	25	
	30	
	35	
	40	
	45	
	50	
	6-10	
	15	
	20	
	25	
	30	
	35	
	40	
	45	
	50	

Part Number	Unit Price	Volume Discount Rate
Type	M-L	1 - 99 pc(s), 100 - 500 pcs.
VISS (Stainless Steel)	3-10	
	15	
	20	
	25	
	30	
	4-10	
	15	
	20	
	25	
	30	
	5-10	
	15	
	20	
	25	
	30	
	6-10	
	15	
	20	
25		
30		

Washers for Ornamental Screw


Part Number	D	t	Unit Price	Volume Discount Rate	* Quantity
Type	d		* Less than	* or More	
VISZ (Brass)	3	10	2		2500
	4	12	2.5		1400
	5	14	3		800
	6	16	3.5		500
VIZS (Stainless Steel)	3	10	2		500
	4	12	2.5		400
	5	14	3		300
	6	16	3.5		200

Ordering Example
Part Number
VIS5-30
VISZ4



RoHS 10

Type	Material	Surface Treatment
BDJ	SWCH Equivalent	Trivalent Chromate
BDJS	SUS304 Equivalent	-

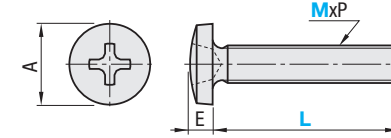

MxP (Coarse)	A	E	Phillips No.
3x0.5	6.3	1.9	2
4x0.7	8.3	2.5	2
5x0.8	10.3	3.1	2
6x1.0	12.4	3.7	3

BDJ (Trivalent Chromate)

Part Number	Unit Price	Volume Discount Rate
Type	M - L	1 ~ 9 pc(s), 10 ~ 29 pcs., 30 ~ 49 pcs., 50 ~ 500 pcs.
BDJ	3 - 5	
	6	
	8	
	10	
	12	
	15	
	20	
	25	
	30	
	4 - 6	
	8	
	10	
	12	
	15	
	20	
	25	
	30	
	5 - 8	
10		
12		
15		
20		
25		
30		
6 - 10		
12		
15		
20		
25		
30		

BDJS (Stainless Steel)

Part Number	Unit Price	Volume Discount Rate
Type	M - L	1 ~ 9 pc(s), 10 ~ 29 pcs., 30 ~ 49 pcs., 50 ~ 500 pcs.
BDJS	3 - 5	
	6	
	8	
	10	
	12	
	15	
	20	
	25	
	30	
	4 - 6	
	8	
	10	
	12	
	15	
	20	
	25	
	30	
	5 - 8	
10		
12		
15		
20		
25		
30		
6 - 10		
12		
15		
20		
25		
30		

Ordering Example
Part Number
BDJ5-10