


# Antislip Covers / Sealing Covers / Protection Covers / Panel Spacers / Magnetic Catch with Adhesive Tape

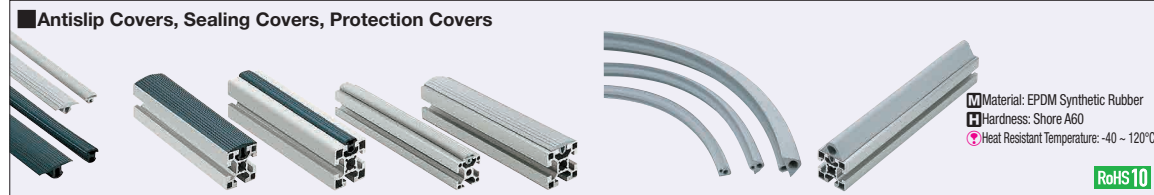

### Antislip Covers

For HFS5 Series	For HFS6 Series	For HFS8 Series	For HFS8-45 Series
HSCG5 HSCGF5	HSCG6 HSCGF6	HSCG8 HSCGF8	HSCG845 HSCGF845

### Sealing Covers

For HFS5 Series	For HFS6 Series	For HFS8, HFS8-45 Series
HSCK5 HSCKF5	HSCK6 HSCKF6	HSCK8 HSCKF8

### Protection Covers


For HFS5 Series	For HFS6 Series	For HFS8, HFS8-45 Series	For HFS6 (30mm Angle) Series	For HFS8 (40mm Angle) Series
HSCD5 HSCDF5	HSCD6 HSCDF6	HSCD8 HSCDF8	HSCWF6	HSCWF8

#### Standard Length

Part Number	No.	Color	Length mm	Extrusion (Type)	Unit Price	Volume Discount Rate
HSCG	5	B (Black)	12	HFS5	1 - 8 pc(s)	9 - 50
	6			HFS6		
	8			HFS8		
HSCK	5	S (Light Gray)	12	HFS5		
	6			HFS6		
	8			HFS8, HFS8-45		
HSCD	5	S (Light Gray)	12	HFS5		
	6			HFS6		
	8			HFS8, HFS8-45		

#### Configurable Length

Part Number	No.	Color	Length 1mm Increment	Extrusion (Type)	Unit Price/m
HSCGF	5	B (Black)	50-3000	HFS5	1 - 50 pc(s)
	6			HFS6	
	8			HFS8	
HSCKF	5	S (Light Gray)	50-3000	HFS5	
	6			HFS6	
	8			HFS8, HFS8-45	
HSCDF	5	S (Light Gray)	50-3000	HFS5	
	6			HFS6	
	8			HFS8, HFS8-45	
HSCWF	5	S (Light Gray)	50-2000	HFS5	
	6			HFS6	
	8			HFS8	

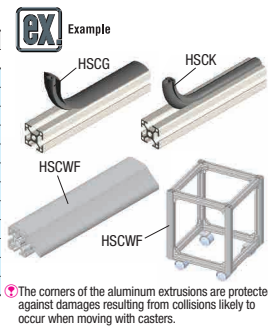

Only light gray color is available for protection covers.  
For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number - Color - Length  
HSCG6 - B - 12  
HSCGF845 - S - 1520

### Panel Spacers

Color: Outgas Testing Results of S Panel Spacer

Measuring Method	GCMS	GCMS	GCMS	GCMS	Type	Color	Material	Heat Resistance Temperature
Outgas	Acetaldehyde	1-Trimethylpentene	Dimethylheptane	Xylene	HSCS HSCSF	Light Gray Economy	EPDM	-40 ~ 120°C
60°C 60min.	Below Detection Limit	Below Detection Limit	Below Detection Limit	Below Detection Limit		Light Gray	Olefin Type Elastomer	-20 ~ 80°C
Detection Limit	0.01µg/g	0.01µg/g	0.01µg/g	0.01µg/g				

#### Standard Length


Part Number	No.	Color	Length m	Extrusion (Series)	B (Black)	SE (Light Gray Economy)	S (Light Gray)
HSCS	5	B (Black) SE (Light Gray Economy) S (Light Gray)	12	HFS5	1 - 8 pc(s)	9 - 50	1 - 8 pc(s)
	6			HFS6			
	8			HFS8 HFS8-45			

#### Configurable Length

Part Number	No.	Color	Length 1mm Increment	Extrusion (Series)	B (Black)	SE (Light Gray Economy)	S (Light Gray)
HSCSF	5	B (Black) SE (Light Gray Economy) S (Light Gray)	100-3000	HFS5	1 ~ 50 pc(s)	1 ~ 50 pc(s)	1 ~ 50 pc(s)
	6			HFS6			
	8			HFS8 HFS8-45			

For orders larger than indicated quantity, please request a quotation.

Ordering Example: Part Number - Color - Length  
HSCS5 - B - 12  
HSCSF5 - SE - 1520

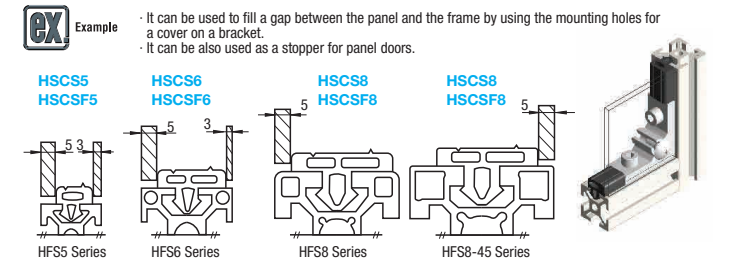

### Magnetic Catch with Adhesive Tape

RoHS 10


Type	Material	Heat Resistance Temperature
HSMG	① Sponge ② Magnet	50°C

For HFS6 Series: HSMG6  
For HFS8, HFS8-45 Series: HSMG8

① N Pole is marked. For mounting, refer to the Example.

Part Number	No.	Color	Length mm	Extrusion (Type)	Magnet Type	Attraction Force per 100mm (g)	Surface Magnetic Flux Density Gauss (G)	Unit Price	Volume Discount Rate
HSMG	6	B (Black)	1000	HFS6	Anisotropic Ferrite Magnet (Plastic Magnet)	75	500	1 ~ 4 pc(s)	5 - 50
	8			HFS8(-45)					

Ordering Example: Part Number - Color  
HSMG6 - B

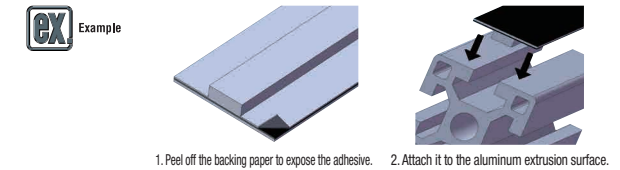

Attraction force is reference value at normal temperature (20°C). Can be attached on door frames and can be used as simplified magnetic catch.  
The attraction force is a reference value gained when two HSMG attracted each other.  
Can be cut with scissors.  
For orders larger than indicated quantity, please check with WOS.