


■ Synthetic Round Sling
(Endless type)

S-RSL

 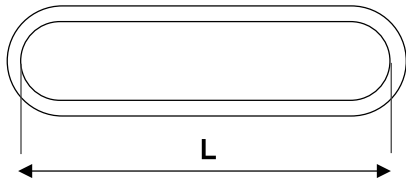


⚠ Safety factor 1:7

Part Number	Width (mm)	WLL (t)	Color	Total Length (m)
S-RSL25-1	25	1	Purple	1
S-RSL25-2				2
S-RSL25-3				3
S-RSL25-4				4
S-RSL25-5				5
S-RSL50-1	50	2	Green	1
S-RSL50-2				2
S-RSL50-3				3
S-RSL50-4				4
S-RSL50-5				5
S-RSL75-1	75	3	Yellow	1
S-RSL75-2				2
S-RSL75-3				3
S-RSL75-4				4
S-RSL75-5				5
S-RSL100-1	100	4	Grey	1
S-RSL100-2				2
S-RSL100-3				3
S-RSL100-4				4
S-RSL100-5				5
S-RSL125-1	125	5	Red	1
S-RSL125-2				2
S-RSL125-3				3
S-RSL125-4				4
S-RSL125-5				5

■ Synthetic Webbing Sling
(Eye to eye type)

S-WSL



⚠ Safety factor 1:6

Part Number	Width (mm)	WLL (t)	Color	Total Length (m)
S-WSL25-1	25	1	Purple	1
S-WSL25-2				2
S-WSL25-3				3
S-WSL25-4				4
S-WSL25-5				5
S-WSL50-1	50	2	Green	1
S-WSL50-2				2
S-WSL50-3				3
S-WSL50-4				4
S-WSL50-5				5
S-WSL75-1	75	3	Yellow	1
S-WSL75-2				2
S-WSL75-3				3
S-WSL75-4				4
S-WSL75-5				5
S-WSL100-2	100	4	Grey	2
S-WSL100-3				3
S-WSL100-4				4
S-WSL100-5				5
S-WSL125-2	125	5	Red	2
S-WSL125-3				3
S-WSL125-4				4
S-WSL125-5				5



Order

Part Number

S-RSL100-1

S-WSL50-1



Days to Ship

Quotation



Price

Quotation