


NEW

SYNTHETIC SLING

■ Synthetic Round Sling
(Endless type)

S-RSL

 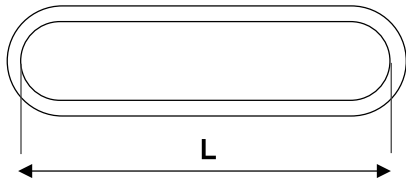


⚠ Safety factor 1:7

| Part Number | Width (mm) | WLL (t) | Color | Total Length (m) |
|-------------|------------|---------|--------|------------------|
| S-RSL25-1 | 25 | 1 | Purple | 1 |
| S-RSL25-2 | | | | 2 |
| S-RSL25-3 | | | | 3 |
| S-RSL25-4 | | | | 4 |
| S-RSL25-5 | | | | 5 |
| S-RSL50-1 | 50 | 2 | Green | 1 |
| S-RSL50-2 | | | | 2 |
| S-RSL50-3 | | | | 3 |
| S-RSL50-4 | | | | 4 |
| S-RSL50-5 | | | | 5 |
| S-RSL75-1 | 75 | 3 | Yellow | 1 |
| S-RSL75-2 | | | | 2 |
| S-RSL75-3 | | | | 3 |
| S-RSL75-4 | | | | 4 |
| S-RSL75-5 | | | | 5 |
| S-RSL100-1 | 100 | 4 | Grey | 1 |
| S-RSL100-2 | | | | 2 |
| S-RSL100-3 | | | | 3 |
| S-RSL100-4 | | | | 4 |
| S-RSL100-5 | | | | 5 |
| S-RSL125-1 | 125 | 5 | Red | 1 |
| S-RSL125-2 | | | | 2 |
| S-RSL125-3 | | | | 3 |
| S-RSL125-4 | | | | 4 |
| S-RSL125-5 | | | | 5 |

■ Synthetic Webbing Sling
(Eye to eye type)

S-WSL



⚠ Safety factor 1:6

| Part Number | Width (mm) | WLL (t) | Color | Total Length (m) |
|-------------|------------|---------|--------|------------------|
| S-WSL25-1 | 25 | 1 | Purple | 1 |
| S-WSL25-2 | | | | 2 |
| S-WSL25-3 | | | | 3 |
| S-WSL25-4 | | | | 4 |
| S-WSL25-5 | | | | 5 |
| S-WSL50-1 | 50 | 2 | Green | 1 |
| S-WSL50-2 | | | | 2 |
| S-WSL50-3 | | | | 3 |
| S-WSL50-4 | | | | 4 |
| S-WSL50-5 | | | | 5 |
| S-WSL75-1 | 75 | 3 | Yellow | 1 |
| S-WSL75-2 | | | | 2 |
| S-WSL75-3 | | | | 3 |
| S-WSL75-4 | | | | 4 |
| S-WSL75-5 | | | | 5 |
| S-WSL100-2 | 100 | 4 | Grey | 2 |
| S-WSL100-3 | | | | 3 |
| S-WSL100-4 | | | | 4 |
| S-WSL100-5 | | | | 5 |
| S-WSL125-2 | 125 | 5 | Red | 2 |
| S-WSL125-3 | | | | 3 |
| S-WSL125-4 | | | | 4 |
| S-WSL125-5 | | | | 5 |



Order

Part Number

S-RSL100-1

S-WSL50-1



Days to Ship

Quotation



Price

Quotation