

NEW

WATER FLOW CHECKERS (SUS)

# SIMPLE FLOW METER (STAINLESS STEEL)

■ Application Use for simple flow checks.



## ■ Features

- A simple flow meter made of stainless steel.

Material Polyamide / stainless steel

Operating temperature (oil) (°C) 120 or less




Operating temperature (water) (°C) 80 or less

Allowable pressure (MPa) 0.98

Max. flow rate (l/min) 10

M-FLM-SUS-S-33

M-FLM-SUS-T-33

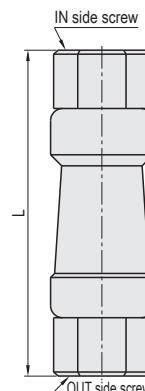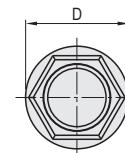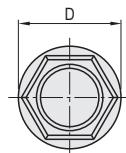

L	D	IN side screw	OUT side screw	Type	Part Number		Unit Price 1~9 pcs
					Type	No.	
81	25.3	RC(PT)3/8	RC(PT)3/8	Straight	M-FLM-SUS	S-33	Quotation
				Taper		T-33	



Part Number
M-FLM-SUS-S-33
M-FLM-SUS-T-33



Days to Ship

Quotation



Price

Quotation

COMPONENTS FOR MOLD COOLING AND TEMPERATURE CONTROLLING SYSTEMS