


ミスミ

SOLID CARBIDE DRILLS


超硬ドリル

● ストレートシャンク / スタブ -STRAIGHT SHANK / STUB LENGTH-

C-SDB

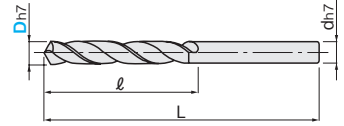

S形シンニング / スリレーキ / 直線切刃

 

● シャンク径 (d) は直径 (D) と同じです。

材質	超硬		
仕様	先端角 118°	スタブ	再研磨

直径D、シャンク径d	公差 (h7)
0.5~3	0 -0.010
3.1~6	0 -0.012
6.1~8	0 -0.015

一般鋼 (SS-SC材)	合金鋼 (SCM)	調質鋼 (~45HRC)	高硬度鋼 (50HRC~)	工具鋼 (SKD, SKS)	ステンレス鋼 (SUS)	鋳鉄 (FC, FCD)	アルミ (Al)	銅 (Cu)	樹脂
○	○			○		○	○	○	

○=適

型番 C-SDB 1本単位

直径 D	溝長 ℓ	全長 L	¥通常単価 30本以上はお見積り		
			1~4本	5~9本	10~29本
0.5	3	20	1,130	1,000	980
0.6	3.5	21	1,130	1,000	980
0.7	4.5	23	1,130	1,000	980
0.8	5	24	1,130	1,000	980
0.9	5.5	25	1,130	1,000	980
1	6	26	900	800	780
1.1	7	28	900	800	780
1.2	8	30	960	840	830
1.3	8	30	960	840	830
1.4	9	32	1,020	900	880
1.5	9	32	1,020	900	880
1.6	10	34	1,070	940	920
1.7	10	34	1,070	940	920
1.8	11	36	1,070	940	920
1.9	11	36	1,070	940	920
2	12	38	1,280	1,130	1,100
2.1	12	38	1,290	1,130	1,110
2.2	13	40	1,290	1,130	1,110
2.3	13	40	1,290	1,130	1,110
2.4	14	43	1,430	1,260	1,240
2.5	14	43	1,430	1,260	1,240
2.6	14	43	1,430	1,260	1,240
2.7	16	46	1,730	1,520	1,490
2.8	16	46	1,730	1,520	1,490
2.9	16	46	1,750	1,540	1,510
3	16	46	1,740	1,530	1,500
3.1	18	49	1,820	1,680	1,640
3.2	18	49	1,930	1,780	1,750
3.3	18	49	1,930	1,780	1,750
3.4	20	52	2,180	2,020	1,980
3.5	20	52	2,120	1,960	1,920

直径 D	溝長 ℓ	全長 L	¥通常単価 30本以上はお見積り		
			1~4本	5~9本	10~29本
3.6	20	52	2,300	2,120	2,080
3.7	20	52	2,300	2,120	2,080
3.9	22	55	2,450	2,260	2,210
4	22	55	2,550	2,360	2,310
4.1	22	55	2,650	2,440	2,390
4.2	22	55	2,650	2,440	2,390
4.3	24	58	2,930	2,710	2,650
4.4	24	58	2,930	2,710	2,650
4.5	24	58	2,860	2,640	2,580
4.6	24	58	2,930	2,710	2,650
4.9	26	62	3,140	2,900	2,840
5	26	62	3,080	2,840	2,780
5.1	26	62	3,210	2,970	2,910
5.3	26	62	4,140	3,820	3,740
5.4	28	66	4,280	3,960	3,880
5.5	28	66	4,280	3,960	3,880
5.7	28	66	4,640	4,290	4,200
5.8	28	66	4,640	4,290	4,200
5.9	28	66	4,710	4,360	4,270
6	28	66	4,640	4,290	4,200
6.1	31	70	5,860	5,410	5,300
6.2	31	70	5,860	5,410	5,300
6.5	31	70	5,430	5,010	4,910
6.6	31	70	6,860	6,330	6,200
6.7	31	70	6,860	6,330	6,200
6.8	34	74	6,860	6,330	6,200
7	34	74	6,140	5,670	5,560
7.5	34	74	7,080	6,540	6,400
8	37	79	7,570	6,990	6,850

切削条件 P.762

Order 注文例

C-SDB 5
型番 直径 (D)

Delivery 出荷日

在庫品 巻末-3
ご希望によりPM6 : 00迄、当日出荷受付致します。

5が特長!

●汎用の超硬ドリルで幅広い用途に対応できます。