


ミスミ

HSS HIGH HERICAL REAMER

ハイス鋼ハイヘリカルリーマ (国内メーカー標準品)

●右刃左ねじれ60°・ストレートシャンク 0.1mm単位指定タイプ

HHHR

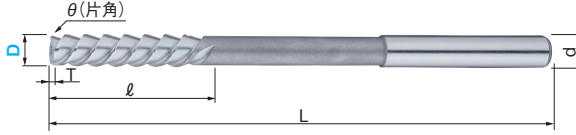

材質



◎突出センチあり(D≤2.9)
◎d=Dとなります。

刃径D	公差	シャンク径d	公差
2 ~ 2.6	+0.005 +0.001	2~14	h7
2.7~ 5.9	+0.006 +0.002		
6 ~14	+0.007 +0.003		
刃径D	食付角θ		
2 ~ 3.9	2°		
3.9~14	1°30'		

型番 HHHR

1本単位

刃径 D	食付長 T	刃長 ℓ	全長 L	刃数	¥通常単価 1~4本	刃径 D	食付長 T	刃長 ℓ	全長 L	刃数	¥通常単価 1~4本	刃径 D	食付長 T	刃長 ℓ	全長 L	刃数	¥通常単価 1~4本
2	5.7	15	60	2	2,340	6.1	7.6	30	100	3	2,340	10.1	9.5	40	150	3	3,100
2.1	5.7	15	60	2	2,340	6.2	9.5	30	100	3	2,340	10.2	9.5	40	150	3	3,100
2.2	5.7	15	60	2	2,340	6.3	9.5	30	100	3	2,340	10.3	9.5	40	150	3	3,100
2.3	5.7	15	60	2	2,340	6.4	9.5	30	100	3	2,340	10.4	9.5	40	150	3	3,100
2.4	5.7	15	60	2	2,340	6.5	9.5	30	110	3	2,340	10.5	9.5	40	155	3	3,100
2.5	5.7	15	60	2	2,340	6.6	9.5	30	110	3	2,340	10.6	9.5	40	155	3	3,100
2.6	5.7	15	60	2	2,340	6.7	9.5	30	110	3	2,340	10.7	9.5	40	155	3	3,100
2.7	5.7	15	60	2	2,340	6.8	9.5	30	110	3	2,340	10.8	9.5	40	155	3	3,100
2.8	5.7	15	60	2	2,340	6.9	9.5	30	110	3	2,340	10.9	9.5	40	155	3	3,100
2.9	5.7	15	60	2	2,340	7	9.5	30	110	3	2,110	11	9.5	40	155	3	3,100
3	5.7	22	70	2	2,010	7.1	9.5	30	110	3	2,620	11.1	9.5	40	155	3	4,140
3.1	5.7	22	70	2	2,170	7.2	9.5	30	110	3	2,620	11.2	9.5	40	155	3	4,140
3.2	5.7	22	70	2	2,170	7.3	9.5	30	110	3	2,620	11.3	9.5	40	155	3	4,140
3.3	5.7	22	70	2	2,170	7.4	9.5	30	110	3	2,620	11.4	9.5	40	155	3	4,140
3.4	5.7	22	70	2	2,170	7.5	9.5	30	110	3	2,620	11.5	9.5	40	160	3	4,140
3.5	5.7	24	80	2	2,170	7.6	9.5	30	110	3	2,620	11.6	9.5	40	160	3	4,140
3.6	5.7	24	80	2	2,170	7.7	9.5	30	110	3	2,620	11.7	9.5	40	160	3	4,140
3.7	5.7	24	80	2	2,170	7.8	9.5	30	110	3	2,620	11.8	9.5	40	160	3	4,140
3.8	5.7	24	80	2	2,170	7.9	9.5	30	110	3	2,620	11.9	9.5	40	160	3	4,140
3.9	5.7	24	80	2	2,170	8	9.5	35	125	3	2,360	12	9.5	40	160	3	4,140
4	6.55	24	80	2	1,940	8.1	9.5	35	125	3	2,700	12.1	9.5	40	160	3	4,380
4.1	7.6	24	80	2	2,170	8.2	9.5	35	125	3	2,700	12.2	9.5	40	160	3	4,380
4.2	7.6	24	80	2	2,170	8.3	9.5	35	125	3	2,700	12.3	9.5	40	160	3	4,380
4.3	7.6	24	80	2	2,170	8.4	9.5	35	125	3	2,700	12.4	9.5	40	160	3	4,380
4.4	7.6	24	80	2	2,170	8.5	9.5	35	135	3	2,700	12.5	9.5	45	165	3	4,380
4.5	7.6	25	90	2	2,170	8.6	9.5	35	135	3	2,700	12.6	9.5	45	165	3	4,380
4.6	7.6	25	90	2	2,170	8.7	9.5	35	135	3	2,700	12.7	9.5	45	165	3	4,380
4.7	7.6	25	90	2	2,170	8.8	9.5	35	135	3	2,700	12.8	9.5	45	165	3	4,380
4.8	7.6	25	90	2	2,170	8.9	9.5	35	135	3	2,700	12.9	9.5	45	165	3	4,030
4.9	7.6	25	90	2	2,170	9	9.5	35	135	3	2,470	13	9.5	45	165	3	4,380
5	7.6	25	90	2	1,940	9.1	9.5	35	135	3	2,980	13.1	9.5	45	165	3	4,570
5.1	7.6	25	90	2	2,170	9.2	9.5	35	135	3	2,980	13.2	9.5	45	165	3	4,570
5.2	7.6	25	90	2	2,170	9.3	9.5	35	135	3	2,980	13.3	9.5	45	165	3	4,570
5.3	7.6	25	90	2	2,170	9.4	9.5	35	135	3	2,980	13.4	9.5	45	165	3	4,570
5.4	7.6	25	90	2	2,170	9.5	9.5	40	150	3	2,980	13.5	9.5	45	170	3	4,570
5.5	7.6	30	100	2	2,170	9.6	9.5	40	150	3	2,980	13.6	9.5	45	170	3	4,570
5.6	7.6	30	100	2	2,170	9.7	9.5	40	150	3	2,980	13.7	9.5	45	170	3	4,570
5.7	7.6	30	100	2	2,170	9.8	9.5	40	150	3	2,980	13.8	9.5	45	170	3	4,570
5.8	7.6	30	100	2	2,170	9.9	9.5	40	150	3	2,980	13.9	9.5	45	170	3	4,570
5.9	7.6	30	100	2	2,170	10	9.5	40	150	3	2,850	14	9.5	45	170	3	4,780
6	7.6	30	100	3	2,170												

Order 注文例

HHHR - 10.1
型番 刃径(D)

Price 価格

■数量スライド価格(◎1円未満切捨て)

数量	1~4	5~9	10~49	50~99	100~
値引率		5%	10%	15%	

切削条件 P.996

Delivery 出荷日

3 日目出荷

お見積り