

Tapered Revolving Handles / Revolving Handles with Hex Socket / Fold-Down Revolving Handles

Flat Revolving Handles / Miniature Revolving Handles / Miniature Revolving Handles - Stainless Steel / Revolving Ball Knobs


Tapered Revolving Handles



RoHS 10

Type	①Handle	②Screw	③Nut
	M Material	M Material S Surface Treatment	M Material S Surface Treatment
GRC	Nylon6 (Black)	SWRM Trivalent Chromate	SUM24L Chrome Plating

Only the plastic grip rotates after attached to a handwheel.

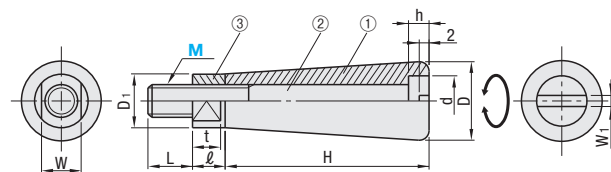

How to Mount




Part Number		D	D1	d	H	h	l	t	W	W1	L	Mass (g)	Unit Price
Type	M (Coarse)												
GRC	8	20	13	12	55	5.5	8	6.5	10	2	11	40	
	10	25	16	15	68		10	8	14		18	100	
	12	30	21	20	85	10	13	9.5	17	2.5	23	180	

Revolving Handles With Hex Socket




RoHS 10

Type	Handle	Screw
	M Material	M Material S Surface Treatment
GRW	Phenol	SUM21 Trivalent Chromate

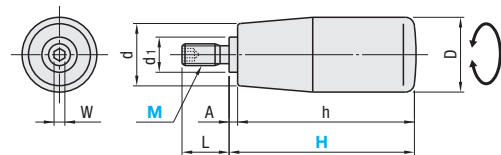

How to Mount

 


Part Number		D	d	d1	h	W	L	A	Mass (g)	Unit Price
Type	M (Coarse) - H									
GRW	6-28.5	14	11	8	28		10	0.5	13	
	6-42.5	18	15	10	40	3	12	2.5	29	
	6-52.5	21	17		50		13	2.5	42	
	8-40			10	39	4	12		24	
	8-55	20	17		54				44	
	10-67	23	20	12	66	5			74	
	10-75	23	20	12	74	5	16		77	

Fold-Down Revolving Handles



RoHS 10

Type	Handle	Screw	Lock Nut
	M Material	M Material S Surface Treatment	M Material S Surface Treatment
GRMBM	Nylon	S45C Chrome Plating	S45C Chrome Plating

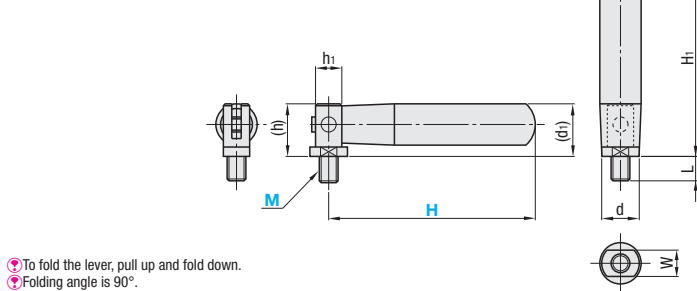

To fold the lever, pull up and fold down.
Folding angle is 90°.

Part Number		H	D	d	(h)	L	h1	H1	(d1)	W	Mass (g)	Unit Price
Type	M (Coarse)											
GRMBM	8	55	19.6	16	20.9	12.5	9	55.5	23.3	12	42	
	81	19.7	16	27.6	12.5	9	80	29.45			80	
	10	104	22.6	19	27.8	16	11	103.5	31.1	14	155	


Ordering Example
Part Number - H
GRC8 - 40
GRW8 - 55
GRMBM8 - 55

Flat Revolving Handles



Type	Handle	Screw	Included Screw
	M Material	M Material S Surface Treatment	M Material S Surface Treatment
GRMLM	Phenol Resin	SS400 Trivalent Chromate	Structural Alloy Steel Trivalent Chromate

To fold the lever, pull up and fold down.
There is a locating hole of Ø2.5 and 2.5mm in depth.

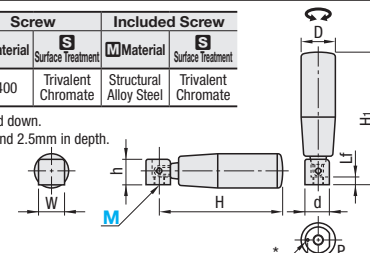

Part Number		H	D	d	h	Lf	H1	W	P	Included Screw	Mass (g)	Unit Price
Type	M (Coarse)											
GRMLM	5	53	18	15.5	15	5	57	17	5.25	M5x10	55	
	6	80	23	18.5	19.5	6	87	20	6.5	M6x10	115	
	8	95	26	18.5	19.5	6	102	20	7	M8x14	137	

Ordering Example
Part Number
GRMLM6

Miniature Revolving Handles




RoHS 10


Type	Shape	Handle	Screw
		M Material	M Material S Surface Treatment
GRH	Threaded	Nylon 6	SUM22L Black Oxide
GRF	Tapped		

Only the plastic grip rotates after attached to a handwheel.

Threaded GRH

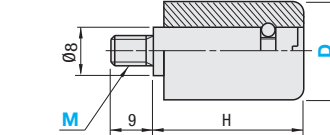

Tapped GRF

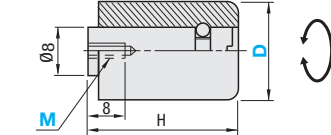

Part Number		Handle Color	H	Mass (g)	Unit Price
Type	M (Coarse) - D				
Threaded GRH	6-13	B (Black)	18.8	13	
	6-14	W (White)	20.8	14	
	6-16		23.8	16	


Part Number		Handle Color	H	Mass (g)	Unit Price
Type	M (Coarse) - D				
Tapped GRF	5-13	B (Black)	18.8	8	
	5-14		20.8	9	
	5-16		23.8	10	

Miniature Revolving Handles - Stainless Steel



RoHS 10

Type	Material	Surface Treatment
GRMSM	SUS304	Electrolytic Polishing

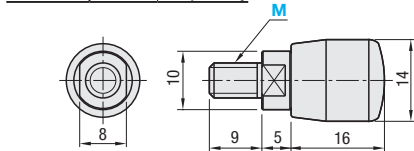



Part Number		Mass (g)	Unit Price
Type	M (Coarse)		
GRMSM	6	21	

Revolving Ball Knobs



RoHS 10

Type	Ball	Screw
	M Material	M Material S Surface Treatment
PBG	Phenol Resin Brass (Insert)	SUM23 Electroless Nickel Plating

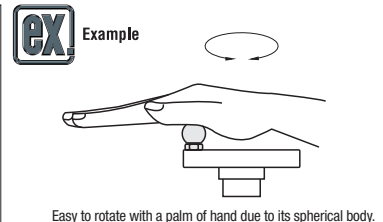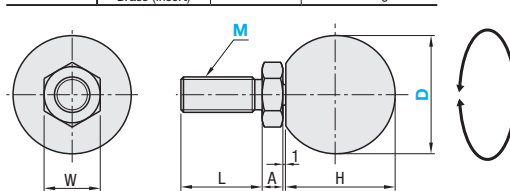

Part Number		D	H	L	W	A	Mass (g)	Unit Price
Type	M (Coarse)							
PBG	6	20	18				12	
		25	23				17	
		30	28				25	
	8	20	18	7	10	3.6	19	
		25	23				25	
		30	28				33	
	10	20	18				49	
		25	23	8	13	5		
		30	28					
		28		10	17	6		

Ordering Example
Part Number - D - Handle Color
GRMLM5 - 13 - W
GRH6 - 16 - B
GRF5 - 25 - B
GRMSM6 - 25 - B
PBG8 - 25 - B