

NEW

WATER FLOW CHECKERS

SIMPLE FLOW METER

—TAPERED—

■ **Application** Use to perform simple flow rate check.



■ Features

- M-FLM-T-33R-TM is equipped with a simple thermometer.
- The resin part is hexagonal; to hook onto the tool.

■ **Material:** Polyamide/Brass







Usable temperature (Oil) (°C)	: 120 or less
Usable temperature (Water) (°C)	: 80 or less
Allowable pressure (MPa)	: 0.98
Max. flow rate (ℓ/min)	: 10

M-FLM-T-33

M-FLM-T-22

M-FLM-T-3R3

M-FLM-T-33R-TM

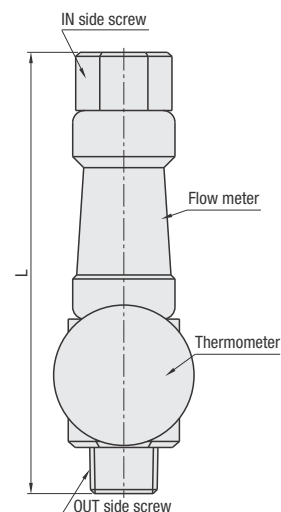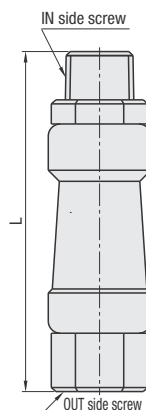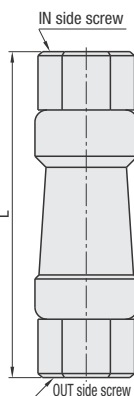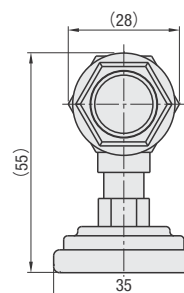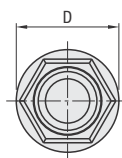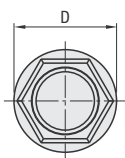

COMPONENTS FOR MOLD COOLING AND
TEMPERATURE CONTROLLING SYSTEMS

L	D	IN side screw	OUT side screw	Part Number	Unit Price
81	25.5	RC(PT)1/4	RC(PT)1/4	M-FLM-T-22	Quotation
85		RC(PT)3/8	RC(PT)3/8	M-FLM-T-33	
110	—	R(PT)3/8	R(PT)3/8	M-FLM-T-3R3	
		RC(PT)3/8	R(PT)3/8	M-FLM-T-33R-TM	



Order

Part Number

M-FLM-T-33



Days
to Ship

Quotation



Price

Quotation