


CAM STOPPERS

SILENCER URETHANES / URETHANE STOPPERS

RoHS

CCS

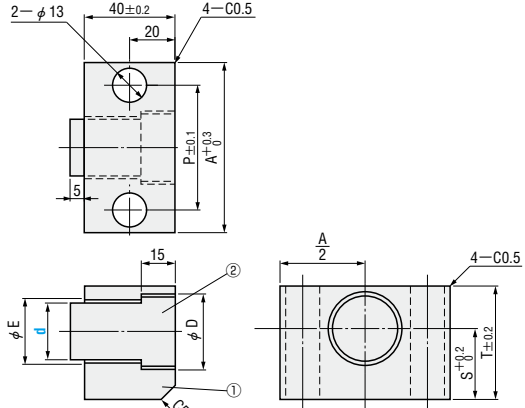


① SS400

② Urethane spring

Shore A90

A	T	D	S	E	P	F Max. load N (kgf)	Catalog No. Type	d
70	60	35	40	30	50	5100 (520)	CCS	27
80	70	45	45	40	60	9610 (980)		36

exExample

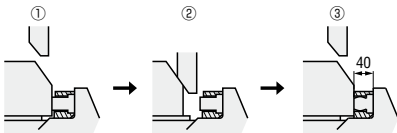

Order

Catalog No.

CCS 36


Days to Ship

Quotation

Price

Quotation

CSTO

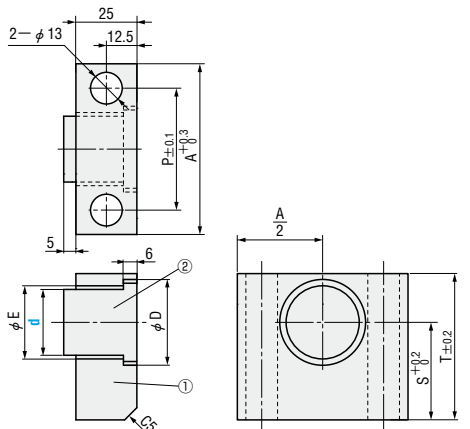

① SS400

② Urethane spring

Shore A90

A	T	D	S	E	P	F Max. load N (kgf)	Catalog No. Type	d
70	60	35.2	40	30	50	2100 (214)	CSTO	27
80	70	45.2	45	40	60	4200 (428)		36

Order

Catalog No.

CSTO 36

Days to Ship

Quotation



Price

Quotation

Silencer urethanes


RoHS

CCUC (Block type)

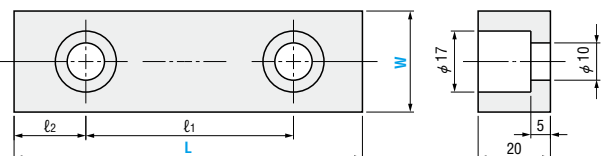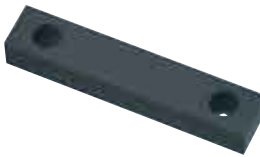

Urethane
Shore A90
Special mounting screw

CCUR (Round type)

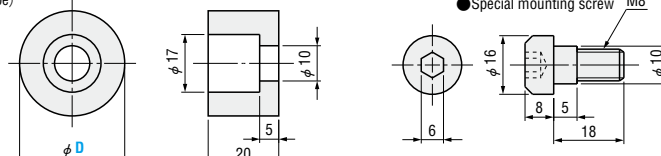


Special mounting screw M8
Special installation bolt
SCM 435
33~38HRC

Block type (with 2 special installation bolts)

ℓ ₁	ℓ ₂	Catalog No. Type	W	L
60	20	CCUC	30	100
110	20			150
140	30			200

exExample

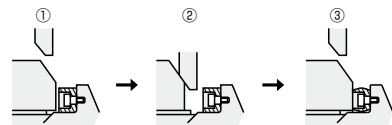

Round type (with 1 special installation bolt)

Catalog No.	D
CCUR	30

Order

Catalog No.

CCUC 30 — L

Days to Ship


Quotation

Price

Quotation

Urethane stoppers

CSTTU

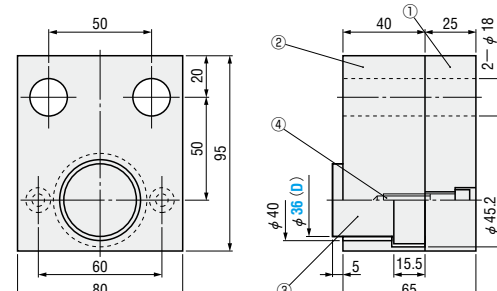

① Fixed plate

② Base plate

③ Urethane stoppers

④ Hexagon socket head cap screw

Table of Components

No.	Name	Quantity	Material, Remarks
①	Fixed plate	1	SS400
②	Base plate	1	SS400
③	Urethane stoppers	1	Urethane Shore A90
④	Hexagon socket head cap screw	2	SCM435 M6×30

* Load is 9800N when the urethane deformation is 5mm.

Catalog No.	(D)
CSTTU	36

Order

Catalog No.

CSTTU 36

Days to Ship

Quotation

Price

Quotation