

NEW

FIX AIR NIPPERS

FIX TYPE AIR NIPPERS

-HORIZONTAL FIX TYPE-


Blade sold separately

■ Fix Type



⚠ The blade is sold separately. Note that there are a regular blade and a reverse blade.

MGT-NF□□

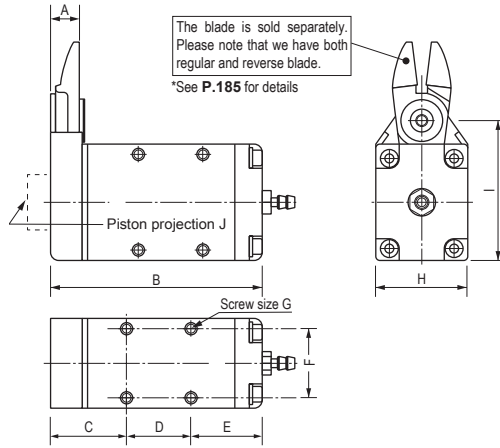

Capacity φ (mm)		Air consumption (cm ³ /time)	Weight (g)	Part dimension (mm)										Tube Outer × Inner	Hose Port	Part Number	Unit Price
Soft resin	Hard resin			A	B	C	D	E	F	G	H	I	J				
3	2	43	101	8.6	59.9	21.9	17	21	18	M3	23	39.5	3	4 × 2.5 Hose nipple	MGT-NF05	Quotation	
3.5	2.3	63	143	8.8	65.1	23.1	20	22	22	M3.5	28	43.5	5		MGT-NF10		
4	2.6	128	219	10.2	73	25	25	23	26	M4	33	48.5	5		MGT-NF15		

• Operating air pressure: 0.4-0.5 MPa

⚠ For quantities not displayed here, refer to our MISUMI website for more information.



Order

Part Number
MGT-NF05



Days to Ship

Quotation



Price

Quotation