



Part Number		Shape	Tip shape	Size	Length	Type	Unit Price (10 pcs per set)	
Type	No.							1-3 sets
M-LS	SA	Square	45° one side	3.0×3.0	150	Soft	Quotation	
	HA					Hard		
	SB	Rectangle		3.0×7.0		Soft		
	HB					Hard		
	SF	Square		6.5×6.5		Soft		
	HF					Hard		
	SG					Soft		
	HG	Rectangle		4.5×4.5		Hard		
	SH					Soft		
	HH					Hard		
	SI	Rectangle		8×12.5		Soft		
	HI					Hard		
	SJ	Round		Cone		φ 3.0		Soft
	HJ							Hard
	SK					φ 4.5		Soft
	HK							Hard
SL	φ 6.5		Soft					
HL			Hard					

- Features
- The hard type is for roughing and is ideal for finishing hard metal and edging corners.
  - The soft type is for semi-finishing and final finishing.


Order **Part Number** **M-LSSA** Days to Ship **Quotation**

Price **Quotation**



- Features
- A brass brush unlikely to damage the workpiece.
  - Wire dia.: φ 0.1
  - Allowable rotational speed: 10000 rpm

Part Number		Shape	Brush tip width	Brush length	Unit Price (10 pcs per set)
Type	No.				
M-WKBB	5	Brush	5	8	Quotation
	8		8	10	
	C	Cup	13	8	

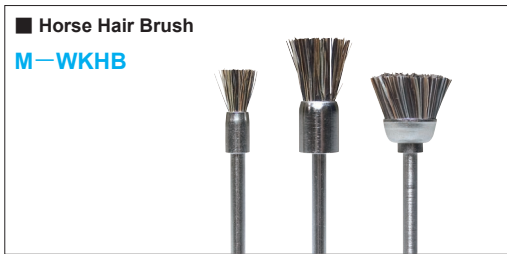

- Features
- A soft horse hair brush unlikely to damage the workpiece.

Part Number		Shape	Brush tip width	Brush length	Unit Price (10 pcs per set)
Type	No.				
M-WKHB	5	Brush	5	8	Quotation
	8		8	10	
	C	Cup	13	8	



- Features
- A brush that can be used for various applications.

Part Number		Shape	Brush tip width	Brush length	Unit Price (10 pcs per set)
Type	No.				
M-WKPB	5	Brush	5	8	Quotation
	8		8	10	
	C	Cup	13	8	

■ Bristle quality  
 [Hard] Brass > Pig Hair > Horse Hair [soft]

Order **Part Number** **M-WKBB5** **M-WKHB5** **M-WKPB5** Days to Ship **Quotation**

Price **Quotation**

MOLD MAINTENANCE RELATED PRODUCTS