




●右刃左ねじれ60°・ストレートシャンク 0.01mm単位指定タイプ

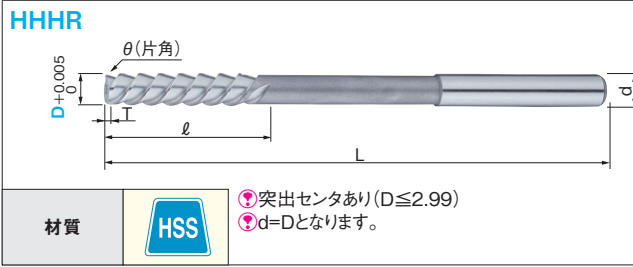

刃径D	公差	シャンク径d	公差
2.01~13.99	+0.005 0	2.01~13.99	h7
刃径D	食付角θ		
2.01~13.99	1°30'		

材質



- 突出センチあり(D≤2.99)
- d=Dとなります。

型番 **HHHR**

1本単位

刃径 D	食付長 T	刃長 l	全長 L	刃数	¥通常単価 1~4本	刃径 D	食付長 T	刃長 l	全長 L	刃数	¥通常単価 1~4本	刃径 D	食付長 T	刃長 l	全長 L	刃数	¥通常単価 1~4本
2.01 ~ 2.09	5.7	15	60	2	3,000	6.01 ~ 6.09	7.6	30	100	3	2,400	10.01 ~ 10.09	9.5	40	150	3	3,500
2.11 ~ 2.19	5.7	15	60	2	3,000	6.11 ~ 6.19	9.5	30	100	3	2,500	10.11 ~ 10.19	9.5	40	150	3	3,500
2.21 ~ 2.29	5.7	15	60	2	3,000	6.21 ~ 6.29	9.5	30	100	3	2,500	10.21 ~ 10.29	9.5	40	150	3	3,500
2.31 ~ 2.39	5.7	15	60	2	3,000	6.31 ~ 6.39	9.5	30	100	3	2,500	10.31 ~ 10.39	9.5	40	150	3	3,500
2.41 ~ 2.49	5.7	15	60	2	3,000	6.41 ~ 6.49	9.5	30	110	3	2,500	10.41 ~ 10.49	9.5	40	155	3	3,500
2.51 ~ 2.59	5.7	15	60	2	3,000	6.51 ~ 6.59	9.5	30	110	3	2,800	10.51 ~ 10.59	9.5	40	155	3	3,700
2.61 ~ 2.69	5.7	15	60	2	3,000	6.61 ~ 6.69	9.5	30	110	3	2,800	10.61 ~ 10.69	9.5	40	155	3	3,700
2.71 ~ 2.79	5.7	15	60	2	3,000	6.71 ~ 6.79	9.5	30	110	3	2,800	10.71 ~ 10.79	9.5	40	155	3	3,700
2.81 ~ 2.89	5.7	15	60	2	3,000	6.81 ~ 6.89	9.5	30	110	3	2,800	10.81 ~ 10.89	9.5	40	155	3	3,700
2.91 ~ 2.99	5.7	22	70	2	3,000	6.91 ~ 6.99	9.5	30	110	3	2,800	10.91 ~ 10.99	9.5	40	155	3	3,700
3.01 ~ 3.09	5.7	22	70	2	2,500	7.01 ~ 7.09	9.5	30	110	3	2,800	11.01 ~ 11.09	9.5	40	155	3	3,700
3.11 ~ 3.19	5.7	22	70	2	2,500	7.11 ~ 7.19	9.5	30	110	3	2,800	11.11 ~ 11.19	9.5	40	155	3	3,700
3.21 ~ 3.29	5.7	22	70	2	2,500	7.21 ~ 7.29	9.5	30	110	3	2,800	11.21 ~ 11.29	9.5	40	155	3	3,700
3.31 ~ 3.39	5.7	22	70	2	2,500	7.31 ~ 7.39	9.5	30	110	3	2,800	11.31 ~ 11.39	9.5	40	155	3	3,700
3.41 ~ 3.49	5.7	24	80	2	2,500	7.41 ~ 7.49	9.5	30	110	3	2,800	11.41 ~ 11.49	9.5	40	160	3	3,700
3.51 ~ 3.59	5.7	24	80	2	2,500	7.51 ~ 7.59	9.5	30	110	3	3,100	11.51 ~ 11.59	9.5	40	160	3	4,900
3.61 ~ 3.69	5.7	24	80	2	2,500	7.61 ~ 7.69	9.5	30	110	3	3,100	11.61 ~ 11.69	9.5	40	160	3	4,900
3.71 ~ 3.79	5.7	24	80	2	2,500	7.71 ~ 7.79	9.5	30	110	3	3,100	11.71 ~ 11.79	9.5	40	160	3	4,900
3.81 ~ 3.89	5.7	24	80	2	2,500	7.81 ~ 7.89	9.5	30	110	3	3,100	11.81 ~ 11.89	9.5	40	160	3	4,900
3.91 ~ 3.99	6.55	24	80	2	2,500	7.91 ~ 7.99	9.5	35	125	3	3,100	11.91 ~ 11.99	9.5	40	160	3	4,900
4.01 ~ 4.09	7.6	24	80	2	2,290	8.01 ~ 8.09	9.5	35	125	3	2,910	12.01 ~ 12.09	9.5	40	160	3	4,900
4.11 ~ 4.19	7.6	24	80	2	2,500	8.11 ~ 8.19	9.5	35	125	3	3,100	12.11 ~ 12.19	9.5	40	160	3	4,900
4.21 ~ 4.29	7.6	24	80	2	2,500	8.21 ~ 8.29	9.5	35	125	3	3,100	12.21 ~ 12.29	9.5	40	160	3	4,900
4.31 ~ 4.39	7.6	24	80	2	2,500	8.31 ~ 8.39	9.5	35	125	3	3,100	12.31 ~ 12.39	9.5	40	160	3	4,900
4.41 ~ 4.49	7.6	25	90	2	2,500	8.41 ~ 8.49	9.5	35	125	3	3,100	12.41 ~ 12.49	9.5	45	165	3	4,900
4.51 ~ 4.59	7.6	25	90	2	2,500	8.51 ~ 8.59	9.5	35	135	3	3,300	12.51 ~ 12.59	9.5	45	165	3	5,300
4.61 ~ 4.69	7.6	25	90	2	2,500	8.61 ~ 8.69	9.5	35	135	3	3,300	12.61 ~ 12.69	9.5	45	165	3	5,300
4.71 ~ 4.79	7.6	25	90	2	2,500	8.71 ~ 8.79	9.5	35	135	3	3,300	12.71 ~ 12.79	9.5	45	165	3	5,300
4.81 ~ 4.89	7.6	25	90	2	2,500	8.81 ~ 8.89	9.5	35	135	3	3,300	12.81 ~ 12.89	9.5	45	165	3	5,300
4.91 ~ 4.99	7.6	25	90	2	2,500	8.91 ~ 8.99	9.5	35	135	3	3,300	12.91 ~ 12.99	9.5	45	165	3	5,300
5.01 ~ 5.09	7.6	25	90	2	2,290	9.01 ~ 9.09	9.5	35	135	3	3,300	13.01 ~ 13.09	9.5	45	165	3	5,300
5.11 ~ 5.19	7.6	25	90	2	2,500	9.11 ~ 9.19	9.5	35	135	3	3,300	13.11 ~ 13.19	9.5	45	165	3	5,300
5.21 ~ 5.29	7.6	25	90	2	2,500	9.21 ~ 9.29	9.5	35	135	3	3,300	13.21 ~ 13.29	9.5	45	165	3	5,300
5.31 ~ 5.39	7.6	25	90	2	2,500	9.31 ~ 9.39	9.5	35	135	3	3,300	13.31 ~ 13.39	9.5	45	165	3	5,300
5.41 ~ 5.49	7.6	30	100	2	2,500	9.41 ~ 9.49	9.5	40	150	3	3,300	13.41 ~ 13.49	9.5	45	170	3	5,300
5.51 ~ 5.59	7.6	30	100	2	2,500	9.51 ~ 9.59	9.5	40	150	3	3,700	13.51 ~ 13.59	9.5	45	170	3	5,700
5.61 ~ 5.69	7.6	30	100	2	2,500	9.61 ~ 9.69	9.5	40	150	3	3,700	13.61 ~ 13.69	9.5	45	170	3	5,700
5.71 ~ 5.79	7.6	30	100	2	2,500	9.71 ~ 9.79	9.5	40	150	3	3,700	13.71 ~ 13.79	9.5	45	170	3	5,700
5.81 ~ 5.89	7.6	30	100	2	2,500	9.81 ~ 9.89	9.5	40	150	3	3,700	13.81 ~ 13.89	9.5	45	170	3	5,700
5.91 ~ 5.99	7.6	30	100	3	2,500	9.91 ~ 9.99	9.5	40	150	3	3,700	13.91 ~ 13.99	9.5	45	170	3	5,700



**HHHR - 10.01**  
型番 刃径 (D)



■数量スライド価格 (◎1円未満切捨て)

数量	1~4	5~9	10~49	50~99	100~
値引率	価格表	5%	10%	15%	

切前条件 P.996



**3** 日日出荷

お見積り

いつもの取引先の見積回答が遅い...そんな時は、  
VONAサポートセンターへ ☎0120-343-256

\*IP電話からお掛けの場合番号未定

- 在庫品は、ご希望によりPM6:00迄のご注文で当日出荷致します。
- 他社ブランド(ミスミ品以外)非在庫品の出荷日カウントは土日祝日を除きます。